
 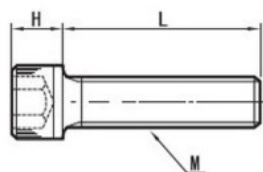


ポリイミド 六角穴付きボルト (キャップスクリュー)

K000API0

樹脂



M	M3	M4	M5	M6	M8
ピッチ	0.5	0.7	0.8	1	1.25
D×H	5.5×3	7×4	8.5×5	10×6	13×8
B	2.5	3	4	5	6

M3.0			M4.0			M5.0			M6.0			M8.0		
長さ	入り数	生地	長さ	入り数	生地	長さ	入り数	生地	長さ	入り数	生地	長さ	入り数	生地
6	10×33	●	6	10×33	●	8	10×33	●	10	10×33	●	10	10×33	●
8	10×33	●	8	10×33	●	10	10×33	●	12	10×33	●	12	10×33	●
10	10×33	●	10	10×33	●	12	10×33	●	16	10×33	●	16	10×33	●
12	10×33	●	12	10×33	●	16	10×33	●	20	10×33	●	20	10×33	●
16	10×33	●	16	10×33	●	20	10×33	●	25	10×33	●	25	10×33	●
20	10×33	●	20	10×33	●	25	10×33	●	30	10×33	●	30	10×33	●
25	10×33	●	25	10×33	●	30	10×33	●	35	10×33	●	35	10×33	●
30	10×33	●	30	10×33	●	35	10×33	●	40	10×33	●	40	10×33	●
35	10×33	●	35	10×33	●	40	10×33	●						
40	10×33	●	40	10×33	●									

ポリイミド 丸ワッシャー

K000WPI0

樹脂

呼び	入り数	生地
3×7×0.5	10×33	●
4×9×0.8	10×33	●
5×10×1.0	10×33	●
6×12.5×1.6	10×33	●
8×17×1.6	10×33	●

CNRゴム 丸ワッシャー

K000WD00

樹脂

呼び	入り数	生地
4×10×1.5	500×20	●
5×12×2.0	500×20	●
6×13×2.0	500×20	●
8×20×2.0	500×14	●
10×22×2.0	500×10	●
12×24×3.0	350×10	●

