


鉄 端子ねじ ⊕ ⊖ ナベH形 (正方形角座 対辺線押さえ組込)



10000260

鉄

正方形角座（線押さえ 対辺方向）組込です。

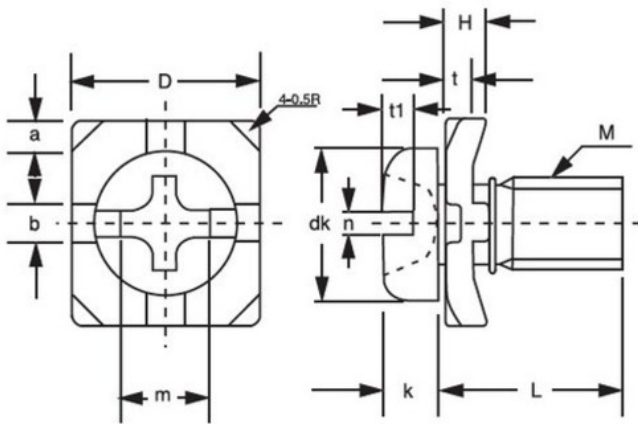

頭部寸法 (+)(-)ナベ頭

ねじの呼び M	十字穴の番号	dk		K		m	n (割幅)	t			
		基準寸法	許容差	基準寸法	許容差						
M2	1	3.5	0 -0.4	1.3	±0.1	2.2	0.60	0.70			
M2.3		4		1.5		2.4					
M2.5		4.5		1.7		2.6					
M2.6		4.5		1.7		2.6					
M3	2	5.5	0 -0.5	2.0	±0.15	3.6	0.80	1.10			
M3.5		6		2.3		3.9					
M4		7		2.6		4.2					
M5		9		0 -0.6		3.3			4.9	1.20	1.80

H形 角座 寸法

ねじの呼び	角座番号	D	t	H	a	b	
M2.5	H2.5-0	4.8	0.8	1.1	1.4	1.2	
M3.0	H3-0	5.8	1.0	1.4	1.2	1.2	
	H3-1	6.1	0.8	1.2	1.2	1.2	
	H3-2	6.1	1.0	1.2	1.2	1.2	
	H3-3	6.2	1.2	1.4	1.2	1.2	
	H3-4	6.8	1.0	1.4	1.2	1.2	
	H3-5	7.0	1.0	1.4	+0.2 0	1.0	1.0
	H3-6	7.4	1.0	1.4	1.2	1.6	
	H3-7	7.8	1.0	1.5	1.2	1.6	
	H3-8	8.1	1.0	1.4	1.2	1.5	
	H3-9	8.7	1.0	1.6	1.6	1.6	
M3.5	H3.5-0	6.0	1.2	1.6	1.2	1.2	
	H3.5-1	6.4	1.2	1.6	0.8	1.0	
	H3.5-2	6.5	1.2	1.7	+0.3 0	0.8	1.2
	H3.5-3	6.7	1.0	1.4	1.2	1.2	
	H3.5-4	7.0	1.0	1.4	1.2	1.2	
	H3.5-5	7.1	1.2	1.6	0.8	1.2	
	H3.5-6	7.4	1.2	1.6	1.2	1.6	
	H3.5-7	7.8	1.0	1.5	+0.2 0	1.2	1.6
	H3.5-8	8.8	1.2	1.8	1.6	1.6	
	H3.5-9	8.4	1.2	1.8	1.6	1.6	
M4.0	H4-0	7.8	1.0	1.4	1.2	1.6	
	H4-1	8.3	1.5	2.1	+0.3 0	2.0	1.5
	H4-2	8.4	1.2	1.8	1.6	1.6	
	H4-3	8.8	1.2	1.8	1.6	1.6	
	H4-4	9.2	1.2	1.7	1.6	1.6	
	H4-5	9.5	1.2	1.7	+0.2 0	1.5	1.5
M5.0	H5-0	10.4	1.6	2.2	1.8	1.8	
	5-1H	12.0	1.6	2.2	2.0	1.5	

端子・関連製品
 発條品
 リベット・鉚
 ビンキー
 POP製品
 寸切・長ねじ
 バック製品
 金具類
 工具類
 トロコギ
 ばね
 端子・関連製品
 アシヤスター製品
 キヤター
 便利品