


# ⊕ バインド小ねじ



00000004	00010004	00020004	00120004	00170004	00090004
鉄	黄銅	ステンレス	SUS 316L	SUS 430	チタン

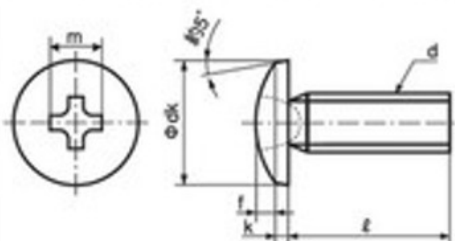

ねじの呼び (d)	ピッチ P	十字穴の番号	dk		k		f		k+f		m	q(十字穴深さ)		
			基準寸法	許容差	基準寸法	許容差	基準寸法	許容差	基準寸法	許容差		参考	最大	最小
M2	0.4	1	4.3	0 -0.4	0.85	0.35	±0.1	1.2	1.4	±0.15	2.2	1.01	0.65	
M2.3	0.4		4.9		1	0.4					1.4	2.4	1.21	0.85
M2.5	0.45		5.3		1	0.5					1.5	2.5	1.32	0.95
M2.6	0.45		5.5		1.1	0.5					1.6	2.6	1.42	1.05
M3	0.5	2	6.3	0 -0.5	1.3	0.6	±0.15	1.9	2.2	±0.2	3.7	1.53	1.01	
M3.5	0.6		7.3		1.5	0.7					2.2	4	1.83	1.30
M4	0.7		8.3		1.7	0.8					2.5	4.3	2.13	1.60
M5	0.8		10.3		2.1	1					3.1	5.0	2.83	2.29
M6	1.0	3	12.4	0 -0.7	2.4	1.3	±0.2	3.7	4.8	±0.3	6.3	2.86	2.31	
M8	1.25		16.4		3.1	1.7					7.8	4.36	3.78	

		M2.0											
長さ	入り数	鉄						黄銅		ステンレス			
		全長	1/2	3/4	1	1 1/4	1 1/2	全長	1/2	3/4	1	1 1/4	1 1/2
2	10000×20	●	●	●	●	●	●	●	●	●	●	●	●
2	10000×24												●
3	10000×18												●
3	10000×20	●	●	●	●	●	●	●	●	●	●	●	●
4	10000×18												●
4	8000×20	●	●	●	●	●	●	●	●	●	●	●	●
5	7000×20	●	●	●	●	●	●	●	●	●	●	●	●
5	8000×18												●
6	6000×20	●	●	●	●	●	●	●	●	●	●	●	●
6	7000×20												●
6	8000×18												●
8	5000×20	●	●	●	●	●	●	●	●	●	●	●	●
8	6000×18												●
10	4000×20	●	●	●	●	●	●	●	●	●	●	●	●
10	5000×18												●
11	3500×20												●
12	3500×20	●	●	●	●	●	●	●	●	●	●	●	●
12	4000×18												●
14	2500×20	●	●	●	●	●	●	●	●	●	●	●	●
14	3000×18												●
15	2500×20	●	●	●	●	●	●	●	●	●	●	●	●
15	3000×18												●
16	2200×20	●	●	●	●	●	●	●	●	●	●	●	●
16	3000×18												●
18	2000×20	●	●	●	●	●	●	●	●	●	●	●	●
18	3000×18												●
20	1800×20	●	●	●	●	●	●	●	●	●	●	●	●
20	2500×18												●

		M2.3											
長さ	入り数	鉄						黄銅		ステンレス			
		全長	1/2	3/4	1	1 1/4	1 1/2	全長	1/2	3/4	1	1 1/4	1 1/2
3	6000×20	●	●	●	●	●	●	●	●	●	●	●	●
3	7000×20												●
3	8000×18												●
4	6000×20	●	●	●	●	●	●	●	●	●	●	●	●
4	8000×18												●
5	5000×20	●	●	●	●	●	●	●	●	●	●	●	●
5	6000×18												●
6	5000×18												●
6	5000×20	●	●	●	●	●	●	●	●	●	●	●	●
8	4000×20	●	●	●	●	●	●	●	●	●	●	●	●
8	5000×18												●
10	3000×20	●	●	●	●	●	●	●	●	●	●	●	●
10	3500×20												●
12	2000×20	●	●	●	●	●	●	●	●	●	●	●	●
12	3000×20												●
14	2000×20	●	●	●	●	●	●	●	●	●	●	●	●
15	2000×20	●	●	●	●	●	●	●	●	●	●	●	●
16	1800×20	●	●	●	●	●	●	●	●	●	●	●	●