


⊕ ナベ P=1 (JIS W組込)

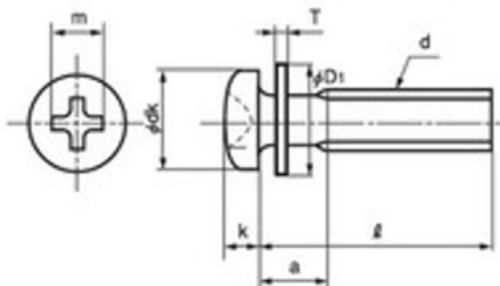

小ねじ
メッシュロボねじ
組込みねじ
タビロねじ
タングタイト
ハイテックねじ
いたすら防止ねじ
建材用スクリーン
ボルト
キャップボルト
ドリルねじ
座金
つまみねじ
ナット
樹脂製品
アンカーボルト

10000001 鉄	10010001 黄銅	10020001 ステンレス	10120001 SUS 316L
---------------	----------------	-------------------	----------------------



ねじの呼び	小ねじ本体					平座金 D1×T	a
	dk	k	十字穴				
			十字穴番号	m (参考)			
M2	3.5 0 -0.4	1.3±0.1	1	2.2	6×0.4	1.2	
M2.3	4 0 -0.4	1.5±0.1	1	2.4	7×0.5	1.3	
M2.6	4.5 0 -0.4	1.7±0.1	1	2.6	7.5×0.5	1.4	
M3	5.5 0 -0.5	2±0.15	2	3.6	8×0.5	1.5	
M3.5	6 0 -0.5	2.3±0.15	2	3.9	9×0.5	1.7	
M4	7 0 -0.5	2.6±0.15	2	4.2	10×0.8	2.3	
M5	9 0 -0.6	3.3±0.15	2	4.9	12×0.8	2.5	
M6	10.5 0 -0.7	3.9±0.2	3	6.3	13×1.0	3.1	
M8	14 0 -0.8	5.2±0.2	3	7.8	18×1.6	4.2	

M2.0													
長さ	入り数	鉄										黄銅	ステンレス
		標準	ロボ	ターボ	ターボ	ターボ	ターボ	ターボ	ターボ	ターボ	ターボ		
4	4000×20	●	●	●	●	●	●	●	●	●	●	●	●
4	5000×20	●	●	●	●	●	●	●	●	●	●	●	●
5	3500×20	●	●	●	●	●	●	●	●	●	●	●	●
5	5000×20	●	●	●	●	●	●	●	●	●	●	●	●
6	3500×20	●	●	●	●	●	●	●	●	●	●	●	●
8	3000×20	●	●	●	●	●	●	●	●	●	●	●	●
10	2500×20	●	●	●	●	●	●	●	●	●	●	●	●
12	2000×20	●	●	●	●	●	●	●	●	●	●	●	●
12	2200×20	●	●	●	●	●	●	●	●	●	●	●	●
14	2000×20	●	●	●	●	●	●	●	●	●	●	●	●
15	2000×20	●	●	●	●	●	●	●	●	●	●	●	●
16	2000×20	●	●	●	●	●	●	●	●	●	●	●	●
20	1500×20	●	●	●	●	●	●	●	●	●	●	●	●

M2.3				
長さ	入り数	鉄	黄銅	ステンレス
5	3000×20	●	●	●

M2.6													
長さ	入り数	鉄										黄銅	ステンレス
		標準	ロボ	ターボ	ターボ	ターボ	ターボ	ターボ	ターボ	ターボ	ターボ		
4	2500×20	●	●	●	●	●	●	●	●	●	●	●	●
5	2000×20	●	●	●	●	●	●	●	●	●	●	●	●
6	2000×20	●	●	●	●	●	●	●	●	●	●	●	●
7	1800×20	●	●	●	●	●	●	●	●	●	●	●	●
8	1500×20	●	●	●	●	●	●	●	●	●	●	●	●
8	1800×20	●	●	●	●	●	●	●	●	●	●	●	●
10	1500×20	●	●	●	●	●	●	●	●	●	●	●	●
12	1000×20	●	●	●	●	●	●	●	●	●	●	●	●
12	1400×20	●	●	●	●	●	●	●	●	●	●	●	●
14	1000×20	●	●	●	●	●	●	●	●	●	●	●	●
16	1000×20	●	●	●	●	●	●	●	●	●	●	●	●
20	800×20	●	●	●	●	●	●	●	●	●	●	●	●

M3.0															
長さ	入り数	鉄										黄銅		ステンレス	
		標準	ロボ	ターボ	ターボ	ターボ	ターボ	ターボ	ターボ	ターボ	ターボ	ターボ	ターボ	ターボ	ターボ
4	1800×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●
4	2000×18	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5	1800×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5	2000×18	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5	3000×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6	1500×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6	2000×18	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6	2500×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●
7	1500×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	1500×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	2000×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	2000×18	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	1000×24	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	1200×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	2000×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●
11	1600×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	1000×24	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	1500×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	1600×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●
14	1000×24	●	●	●	●	●	●	●	●	●	●	●	●	●	●
14	1500×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●