


ナベ PK=1 (JIS小形W組込)



10000007 鉄
10010007 黄銅
10020007 ステンレス

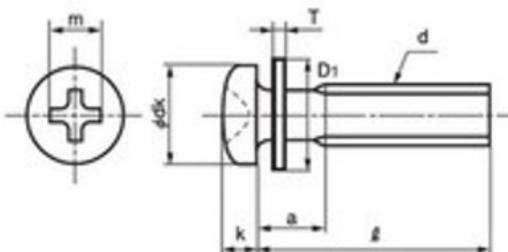

ねじの呼び	小ねじ本体			平座金 D1×T	a
	dk	k	十字穴		
			十字穴番号		
M2	3.5	0 —0.4	1.3±0.1	1	2.2
M2.3	4	0 —0.4	1.5±0.1	1	2.4
M2.6	4.5	0 —0.4	1.7±0.1	1	2.6
M3	5.5	0 —0.5	2±0.15	2	3.6
M3.5	6	0 —0.5	2.3±0.15	2	3.9
M4	7	0 —0.5	2.6±0.15	2	4.2
M5	9	0 —0.6	3.3±0.15	2	4.9
M6	10.5	0 —0.7	3.9±0.2	3	6.3
M8	14	0 —0.8	5.2±0.2	3	7.8

M2.0						
規格	入り数	鉄				規格
		生地	ドリップ	クロム	黒	
4	7000×20	●	●	●	●	
5	5000×20	●	●	●	●	
6	5000×20	●	●	●	●	
8	4000×20	●	●	●	●	
10	3000×20	●	●	●	●	
12	2500×20	●	●	●	●	
14	2500×20	●	●	●	●	
15	2000×20	●	●	●	●	
18	1800×20	●	●	●	●	
20	1800×20	●	●	●	●	

M2.3						
規格	入り数	鉄				規格
		生地	ドリップ	クロム	黒	
12	2000×20	●	●	●	●	
14	1500×20	●	●	●	●	
16	1500×20	●	●	●	●	
18	1200×20	●	●	●	●	

M2.6						
規格	入り数	鉄				規格
		生地	ドリップ	クロム	黒	
4	3500×20					●
4	4000×20	●	●	●	●	
5	3000×20					●
5	4000×20	●	●	●	●	
6	3000×20					●
6	3500×20	●	●	●	●	
8	2500×20					●
8	3000×20	●	●	●	●	
10	2000×20					●
10	2500×20	●	●	●	●	
12	1500×20					●
12	2000×20	●	●	●	●	
14	1500×20	●	●	●	●	
16	1500×20	●	●	●	●	
18	1200×20	●	●	●	●	
35	500×14	●	●	●	●	

M3.0						
規格	入り数	鉄				規格
		生地	ドリップ	クロム	黒	
4	2500×20	●	●	●	●	
4	4000×20					● ●
5	2000×24					● ●
5	2500×20	●	●	●	●	
5	4000×14					● ●
6	2000×24					● ●
6	2500×20	●	●	●	●	
6	3500×14					● ●
8	2000×18					● ●
8	2000×20	●	●	●	●	
8	2500×14					● ●
10	1800×20	●	●	●	●	
10	2000×18					● ●
10	2500×14					● ●
12	1000×24					● ●
12	2000×14					● ●
12	2500×14	●	●	●	●	
14	1000×24					● ●
14	2000×14	●	●	●	●	
15	1000×18					● ●
15	1800×14	●	●	●	●	
16	1000×18					● ●
16	1500×14					● ●
16	1800×14	●	●	●	●	

小ねじ
マイクロねじ
組込みねじ
タッピングねじ
ハイスクローネジ
いたずら防止ねじ
建材用スクリュー
ボルト
キャンナーホロー
ドリルねじ
座金
つまみねじ
ナット
機器製品
アンカーボルト