

六角トリーマ I=3 (SW+ISO W組込)




11000013

鉄

11020013

ステンレス

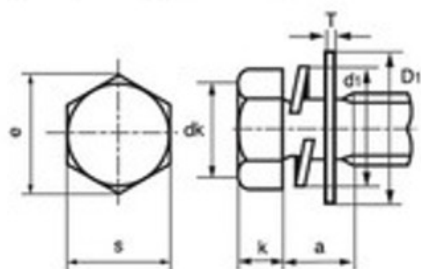

ねじの呼び (d)	k		s		e (約)	dk (約)	平座金 D1×T	ばね座金 d1 (最大)	a
	基準寸法	許容差	基準寸法	許容差					
M4	2.8	±0.1	7	0	8.1	6.8	9×0.8	7	4.4
M5	3.5	±0.15	8	-0.2	9.2	7.8	10×1.0	8.5	5.4
M6	4		10	0	11.5	9.8	12.5×1.6	11.5	6.9
M8	5.5		13	-0.25	15.0	12.6	17×1.6	14.5	8.4
M12	8	±0.2	19	-0.35	21.9	18	24×2.5	20.5	12.5

M3.0		鉄						ステンレス	
長さ	入り数	普通	ステンレス	ステンレス	ステンレス	ステンレス	ステンレス	ステンレス	ステンレス
6	1500×20	●	●	●	●	●	●	●	●
8	1200×20	●	●	●	●	●	●	●	●
10	1000×20	●	●	●	●	●	●	●	●
10	1000×24	●	●	●	●	●	●	●	●
12	1500×14	●	●	●	●	●	●	●	●

M4.0		鉄						ステンレス			
長さ	入り数	普通	ステンレス	ステンレス	ステンレス	ステンレス	ステンレス	ステンレス	ステンレス	ステンレス	ステンレス
8	1000×14	●	●	●	●	●	●	●	●	●	●
8	500×24	●	●	●	●	●	●	●	●	●	●
10	500×24	●	●	●	●	●	●	●	●	●	●
10	800×14	●	●	●	●	●	●	●	●	●	●
12	500×24	●	●	●	●	●	●	●	●	●	●
12	800×14	●	●	●	●	●	●	●	●	●	●
14	500×18	●	●	●	●	●	●	●	●	●	●
14	700×14	●	●	●	●	●	●	●	●	●	●
15	500×18	●	●	●	●	●	●	●	●	●	●
15	700×14	●	●	●	●	●	●	●	●	●	●
16	500×18	●	●	●	●	●	●	●	●	●	●
16	700×14	●	●	●	●	●	●	●	●	●	●
18	500×18	●	●	●	●	●	●	●	●	●	●
20	500×14	●	●	●	●	●	●	●	●	●	●
20	500×18	●	●	●	●	●	●	●	●	●	●
25	200×24	●	●	●	●	●	●	●	●	●	●
25	500×14	●	●	●	●	●	●	●	●	●	●
30	200×24	●	●	●	●	●	●	●	●	●	●
30	400×14	●	●	●	●	●	●	●	●	●	●

M5.0		鉄						ステンレス			
長さ	入り数	普通	ステンレス	ステンレス	ステンレス	ステンレス	ステンレス	ステンレス	ステンレス	ステンレス	ステンレス
8	500×18	●	●	●	●	●	●	●	●	●	●
8	600×14	●	●	●	●	●	●	●	●	●	●
10	500×18	●	●	●	●	●	●	●	●	●	●
10	600×14	●	●	●	●	●	●	●	●	●	●
12	500×14	●	●	●	●	●	●	●	●	●	●
14	500×14	●	●	●	●	●	●	●	●	●	●
15	450×14	●	●	●	●	●	●	●	●	●	●
15	500×14	●	●	●	●	●	●	●	●	●	●
16	450×14	●	●	●	●	●	●	●	●	●	●
16	500×14	●	●	●	●	●	●	●	●	●	●
18	200×24	●	●	●	●	●	●	●	●	●	●
20	200×24	●	●	●	●	●	●	●	●	●	●
20	400×14	●	●	●	●	●	●	●	●	●	●
25	200×24	●	●	●	●	●	●	●	●	●	●
25	500×10	●	●	●	●	●	●	●	●	●	●
30	200×18	●	●	●	●	●	●	●	●	●	●
30	400×10	●	●	●	●	●	●	●	●	●	●
35	200×18	●	●	●	●	●	●	●	●	●	●
35	350×10	●	●	●	●	●	●	●	●	●	●
40	100×24	●	●	●	●	●	●	●	●	●	●
40	300×10	●	●	●	●	●	●	●	●	●	●
45	100×24	●	●	●	●	●	●	●	●	●	●
50	200×10	●	●	●	●	●	●	●	●	●	●

M6.0		鉄						ステンレス			
長さ	入り数	普通	ステンレス	ステンレス	ステンレス	ステンレス	ステンレス	ステンレス	ステンレス	ステンレス	ステンレス
10	200×24	●	●	●	●	●	●	●	●	●	●
10	350×14	●	●	●	●	●	●	●	●	●	●
12	200×24	●	●	●	●	●	●	●	●	●	●
12	350×14	●	●	●	●	●	●	●	●	●	●
14	200×18	●	●	●	●	●	●	●	●	●	●
14	300×14	●	●	●	●	●	●	●	●	●	●
15	200×18	●	●	●	●	●	●	●	●	●	●
15	300×14	●	●	●	●	●	●	●	●	●	●
16	200×18	●	●	●	●	●	●	●	●	●	●
16	300×14	●	●	●	●	●	●	●	●	●	●
18	200×18	●	●	●	●	●	●	●	●	●	●
18	250×14	●	●	●	●	●	●	●	●	●	●
20	200×18	●	●	●	●	●	●	●	●	●	●
20	250×14	●	●	●	●	●	●	●	●	●	●
22	200×14	●	●	●	●	●	●	●	●	●	●
25	200×14	●	●	●	●	●	●	●	●	●	●
25	300×10	●	●	●	●	●	●	●	●	●	●
30	100×24	●	●	●	●	●	●	●	●	●	●
35	100×24	●	●	●	●	●	●	●	●	●	●
35	250×10	●	●	●	●	●	●	●	●	●	●
40	100×18	●	●	●	●	●	●	●	●	●	●
45	100×18	●	●	●	●	●	●	●	●	●	●
50	100×18	●	●	●	●	●	●	●	●	●	●
50	150×10	●	●	●	●	●	●	●	●	●	●
55	150×10	●	●	●	●	●	●	●	●	●	●

M8.0		鉄						ステンレス			
長さ	入り数	普通	ステンレス	ステンレス	ステンレス	ステンレス	ステンレス	ステンレス	ステンレス	ステンレス	ステンレス
12	100×24	●	●	●	●	●	●	●	●	●	●
12	150×14	●	●	●	●	●	●	●	●	●	●
14	100×18	●	●	●	●	●	●	●	●	●	●
14	150×14	●	●	●	●	●	●	●	●	●	●
15	100×18	●	●	●	●	●	●	●	●	●	●
15	150×14	●	●	●	●	●	●	●	●	●	●
16	100×18	●	●	●	●	●	●	●	●	●	●
16	130×14	●	●	●	●	●	●	●	●	●	●
18	100×18	●	●	●	●	●	●	●	●	●	●
20	100×18	●	●	●	●	●	●	●	●	●	●
20	120×14	●	●	●	●	●	●	●	●	●	●
22	100×14	●	●	●	●	●	●	●	●	●	●
25	100×14	●	●	●	●	●	●	●	●	●	●
25	150×10	●	●	●	●	●	●	●	●	●	●
30	100×14	●	●	●	●	●	●	●	●	●	●
30	150×10	●	●	●	●	●	●	●	●	●	●
35	130×10	●	●	●	●	●	●	●	●	●	●
35	50×18	●	●	●	●	●	●	●	●	●	●
40	100×10	●	●	●	●	●	●	●	●	●	●
40	50×18	●	●	●	●	●	●	●	●	●	●
45	50×18	●	●	●	●	●	●	●	●	●	●
50	50×18	●	●	●	●	●	●	●	●	●	●
60	70×10	●	●	●	●	●	●	●	●	●	●