

⊕ 皿タップピンねじ (2種溝付き B-1形)



小ねじ

マメスクリねじ

組込みねじ

タッピングねじ

タフタフねじ

いたすら防止ねじ

建材用スクリーナー

ボルト

キャップボルト

ドリルねじ

座金


つまみねじ

ナット

樹脂製品

アンカーボルト

21000001 鉄	21020001 ステンレス	21030001 SUS 410	21090001 チタン
---------------	-------------------	---------------------	-----------------

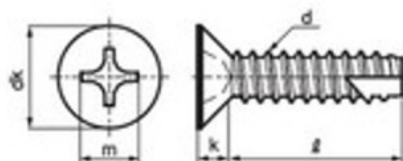

呼び径		2	2.3	2.5	2.6	3	3.5	4	4.5	5	6	
dk	基準寸法	4.0	4.6	5.0	5.2	6.0	7.0	8.0	9.0	10.0	12.0	
	許容差	0 -0.4				0 -0.5			0 -0.6		0 -0.7	
k	基準寸法	1.20	1.35	1.45	1.50	1.75	2.00	2.30	2.55	2.80	3.40	
	許容差	0 -0.2				0 -0.3					0 -0.4	
十字穴	m	参考	2.2	2.4	2.6	2.6	3.6	4.1	4.5	4.9	5.1	6.7
	Q	最大	1.01	1.21	1.42	1.42	1.43	1.93	2.33	2.73	2.93	3.26
		最小	0.65	0.85	1.05	1.05	0.91	1.40	1.79	2.19	2.38	2.70
		十字穴の番号	1				2				3	
d	最大	2.00	2.30	2.50	2.60	3.00	3.50	4.00	4.50	5.00	6.00	
	最大	1.90	2.20	2.40	2.50	2.90	3.40	3.85	4.35	4.85	5.85	
ねじの山数25.4mmに付き		40	32	28	28	24	20	18	16	16	14	

2.0		鉄													ステンレス	
長さ	入り数	1300	1500	1800	2000	2500	3000	3500	4000	5000	6000	7000	8000	10000		12000
4	12000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5	10000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5	10000×24															●
6	10000×18															●
6	9000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	7000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	8000×18															●
10	5000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	6000×18															●
12	4000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	6000×18															●
14	3500×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16	2500×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

2.3		鉄													ステンレス	
長さ	入り数	1300	1500	1800	2000	2500	3000	3500	4000	5000	6000	7000	8000	10000		12000
6	6000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	5000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	4000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	3000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
14	2200×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16	2000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
18	2000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
20	1500×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
25	1000×20															●

2.5		鉄													ステンレス	
長さ	入り数	1300	1500	1800	2000	2500	3000	3500	4000	5000	6000	7000	8000	10000		12000
6	5000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	4000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	3000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	2500×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

2.6		鉄													ステンレス	
長さ	入り数	1300	1500	1800	2000	2500	3000	3500	4000	5000	6000	7000	8000	10000		12000
5	5000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6	5000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6	6000×18															●
8	4000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	6000×18															●
10	3000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	4000×18															●
12	2500×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	3000×18															●
14	2000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16	1800×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16	3000×18															●
18	1600×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
20	1500×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●