


# 鉄 ⊕ ブレジャータッピンねじ (2種溝付き B-1形)



2100000E

鉄

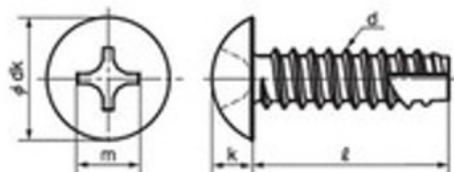

呼び径		2	2.5	3	3.5	4	4.5	5	6	
dk	基準寸法	4.2	5.5	6.4	7.4	8.5	9.5	10.6	12.5	
	許容差	0 -0.4		0 -0.5			0 -0.6		0 -0.7	
k	基準寸法	1.5	2	2.45	2.6	2.7	3.05	3.4	4.1	
	許容差	±0.1			±0.15				±0.2	
十字穴	m	参考	2.2	2.6	3.7	3.8	4.0	4.4	6.2	
	Q	最大	1.01	1.42	1.63	1.73	1.93	2.33	2.73	2.86
		最小	0.63	1.00	1.06	1.16	1.35	1.74	2.14	2.26
	十字穴の番号		1			2				3
d	最大	2.00	2.50	3.00	3.50	4.00	4.50	5.00	6.00	
	最小	1.90	2.40	2.90	3.40	3.85	4.35	4.85	5.85	
ねじの山数25.4mmに付き		40	28	24	20	18	16	16	14	

2.0										
長さ	入り数	亜鉛めっき	2クロム	3クロム	4クロム	5クロム	6クロム	7クロム	8クロム	9クロム
5	7000×20	●	●	●	●	●	●	●	●	●

3.0										
長さ	入り数	亜鉛めっき	2クロム	3クロム	4クロム	5クロム	6クロム	7クロム	8クロム	9クロム
5	2500×20	●	●	●	●	●	●	●	●	●
6	2200×20	●	●	●	●	●	●	●	●	●
8	1800×20	●	●	●	●	●	●	●	●	●
10	1800×20	●	●	●	●	●	●	●	●	●
12	2200×14	●	●	●	●	●	●	●	●	●
14	2000×14	●	●	●	●	●	●	●	●	●
16	1800×14	●	●	●	●	●	●	●	●	●
18	1500×14	●	●	●	●	●	●	●	●	●
20	1400×14	●	●	●	●	●	●	●	●	●

4.0										
長さ	入り数	亜鉛めっき	2クロム	3クロム	4クロム	5クロム	6クロム	7クロム	8クロム	9クロム
6	1500×14	●	●	●	●	●	●	●	●	●
8	1500×14	●	●	●	●	●	●	●	●	●
10	1300×14	●	●	●	●	●	●	●	●	●
12	1200×14	●	●	●	●	●	●	●	●	●
14	1000×14	●	●	●	●	●	●	●	●	●
16	900×14	●	●	●	●	●	●	●	●	●
18	800×14	●	●	●	●	●	●	●	●	●
20	800×14	●	●	●	●	●	●	●	●	●
25	600×14	●	●	●	●	●	●	●	●	●

# 鉄 ⊕ ナベワッシャーヘッドタッピンねじ (2種溝付き B-1形)




2100000W

鉄

2102000W

ステンレス

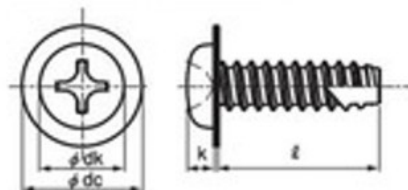

呼び径		3	3.5	4	5	
dk	基準寸法	5.5	6.0	7.0	9.0	
	許容差	0 -0.5		0 -0.6		
dc	基準寸法	8.0	9.0	10.0	12.0	
	許容差	0 -0.5				
k	基準寸法	2.2	2.5	3	3.5	
	許容差	±0.2		±0.3		
十字穴	m	参考	3.6	3.9	4.2	4.9
	Q	最大	1.43	1.73	2.03	2.73
		最小	0.86	1.15	1.45	2.14
	十字穴の番号		2			
d	最大	3.0	3.5	4.0	5.0	
	最小	2.90	3.40	3.85	4.85	
ねじの山数25.4mmに付き		24	20	18	16	

2.3										
長さ	入り数	亜鉛めっき	2クロム	3クロム	4クロム	5クロム	6クロム	7クロム	8クロム	9クロム
6	3000×20	●	●	●	●	●	●	●	●	●
8	2500×20	●	●	●	●	●	●	●	●	●
10	2500×20	●	●	●	●	●	●	●	●	●
12	2000×20	●	●	●	●	●	●	●	●	●
16	1500×20	●	●	●	●	●	●	●	●	●

2.6										
長さ	入り数	亜鉛めっき	2クロム	3クロム	4クロム	5クロム	6クロム	7クロム	8クロム	9クロム
6	2500×20	●	●	●	●	●	●	●	●	●
8	2500×20	●	●	●	●	●	●	●	●	●
10	2500×20	●	●	●	●	●	●	●	●	●
12	2000×20	●	●	●	●	●	●	●	●	●
16	1500×20	●	●	●	●	●	●	●	●	●
20	1200×20	●	●	●	●	●	●	●	●	●