

⊕ ナベタップピンねじ(3種溝付き C-1形)

		5.0													ステンレス			
長さ	入り数	鉄													DIN9130	DIN9132	A2-70	
		標準	DIN1174	7-17	7-17	7-17	7-17	7-17	7-17	7-17	7-17	7-17	7-17	7-17				7-17
6	1000×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	1000×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	1000×18															●	●	●
10	500×24															●	●	●
10	900×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	500×24															●	●	●
12	800×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
14	500×24															●	●	●
14	800×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
15	700×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16	500×18															●	●	●
16	700×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
20	500×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
20	500×18															●	●	●
25	400×18															●	●	●
25	700×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
30	200×24															●	●	●
30	600×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
35	200×24															●	●	●
35	500×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
40	200×18															●	●	●
40	400×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
45	350×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
50	300×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●


		6.0													ステンレス			
長さ	入り数	鉄													DIN9130	DIN9132	A2-70	
		標準	DIN1174	7-17	7-17	7-17	7-17	7-17	7-17	7-17	7-17	7-17	7-17	7-17				7-17
10	600×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	500×18															●	●	●
12	600×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
14	500×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
14	500×18															●	●	●
15	500×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16	200×24															●	●	●
16	450×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
18	200×24															●	●	●
20	200×24															●	●	●
20	350×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
25	200×24															●	●	●
25	500×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
30	200×18															●	●	●
30	400×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
35	200×18															●	●	●
35	300×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
40	100×24															●	●	●
40	300×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
45	250×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
50	200×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
55	200×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
60	180×10														●	●	●	●
70	120×10														●	●	●	●
150	130×8	●																
170	90×10	●																

		8.0			
長さ	入り数	鉄			
		標準	7-17	7-17	7-17
30	200×10	●	●	●	●

⊕ 皿タップピンねじ(3種溝付き C-1形)



22000001	22020001
鉄	ステンレス

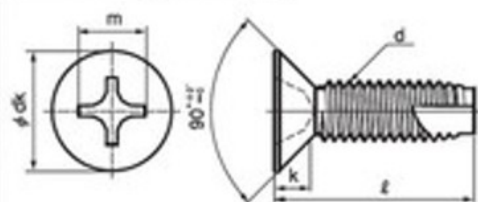

呼び径		2	2.3	2.5	2.6	3	3.5	4	4.5	5	6	8	
dk	基準寸法	4.0	4.6	5.0	5.2	6.0	7.0	8.0	9.0	10.0	12.0	16.0	
	許容差	0 -0.4				0 -0.5			0 -0.6		0 -0.7		0 -0.8
k	基準寸法	1.20	1.35	1.45	1.50	1.75	2.00	2.30	2.55	2.80	3.40	4.40	
	許容差	0 -0.2				0 -0.3					0 -0.4		
十字穴	m	参考	2.2	2.4	2.6	2.6	3.6	4.1	4.5	4.9	5.1	6.7	8.4
	Q	最大	1.01	1.21	1.42	1.42	1.43	1.93	2.33	2.73	2.93	3.26	4.96
	最小	0.85	0.85	1.05	1.05	0.91	1.40	1.79	2.19	2.38	2.70	4.36	
十字穴の番号		1					2					3	
d	最大	1.98	2.28	2.48	2.58	2.98	3.47	3.97	4.47	4.97	5.97	7.96	
	最小	1.89	2.19	2.38	2.48	2.87	3.36	3.84	4.34	4.84	5.82	7.79	
P(ピッチ)		0.4	0.4	0.45	0.45	0.5	0.6	0.7	0.75	0.8	1.0	1.25	