


# 六角穴付き止めねじ(ホーローセット) (くぼみ先)豊栄鉄工製

A000500H

A002500H

鉄

ステンレス

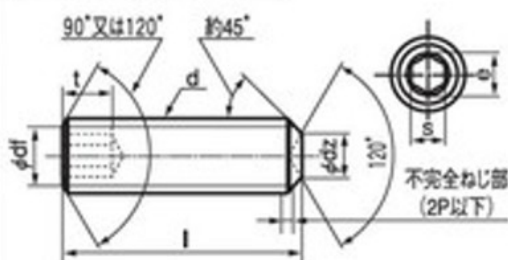

(mm)

ねじの呼び(d)		M1.6	M2	M2.5(2.6)	M3	M4	M5	M6	
ピッチ(P)		0.35	0.4	0.45	0.5	0.7	0.8	1.0	
dz	最大(基準寸法)	0.8	1.0	1.2	1.4	2.0	2.5	3.0	
	最小	0.55	0.75	0.95	1.15	1.75	2.25	2.75	
df	約	おねじの管径							
e	最小	0.803	1.003	1.427	1.73	2.30	2.87	3.44	
s	呼び(基準寸法)	0.7	0.9	1.3	1.5	2.0	2.5	3.0	
	最小	0.711	0.889	1.270	1.520	2.020	2.520	3.020	
	最大	0.724	0.902	1.295	1.545	2.045	2.560	3.080	
t	最小	1個	0.7	0.8	1.2	1.2	1.5	2.0	2.0
		2個	1.5	1.7	2.0	2.0	2.5	3.0	3.5

1.6			
長さ	入り数	鉄	ステンレス
2	2000×20	●	●
3	2000×20	●	●
4	2000×20	●	●
5	2000×20	●	●

2.0			
長さ	入り数	鉄	ステンレス
2	2000×20	●	●
3	2000×20	●	●
4	2000×20	●	●
5	2000×20	●	●
6	2000×20	●	●
8	2000×20	●	●
10	2000×20	●	●

2.5			
長さ	入り数	鉄	ステンレス
3	2000×20	●	●
4	2000×20	●	●
5	2000×20	●	●
6	2000×20	●	●
8	2000×20	●	●

2.6			
長さ	入り数	鉄	ステンレス
3	2000×20	●	●
4	2000×20	●	●
5	2000×20	●	●
6	2000×20	●	●
8	2000×20	●	●

3.0			
長さ	入り数	鉄	ステンレス
3	2000×20	●	●
4	2000×20	●	●
5	2000×20	●	●
6	2000×20	●	●
8	2000×20	●	●
10	2000×10	●	●

4.0			
長さ	入り数	鉄	ステンレス
4	2000×20	●	●
5	2000×20	●	●
6	2000×20	●	●
8	2000×10	●	●
10	2000×10	●	●
12	1000×10	●	●

5.0			
長さ	入り数	鉄	ステンレス
5	2000×10	●	●
6	2000×10	●	●
8	2000×10	●	●
10	1000×10	●	●
12	1000×10	●	●
15	1000×10	●	●

6.0			
長さ	入り数	鉄	ステンレス
6	2000×10	●	●
8	1000×10	●	●
10	500×10	●	●
12	500×10	●	●
15	500×10	●	●
16	500×10	●	●