

ステンレス 六角穴付きボルト (キャップスクリュー) シールワッシャー組込

A002901S

ステンレス

M10.0

長さ	入り数	注記
12	100×10	●

ローヘッドキャップ




A000L000

鉄

A002L000

ステンレス

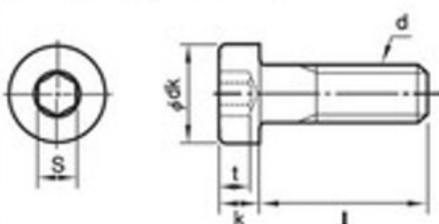

呼び径(d)	M2	M2.5	M3	M4	M5	M6	M8	M10	M12	M16	M20	M24
頭径(dk)	3.8	4.5	5.5	7	8.5	10	13	16	18	24	30	36
頭高さ(k)	1.3	1.6	2	2.8	3.5	4	5	6	7	9	11	13
六角平径(s)	1.3	1.5	2	2.5	3	4	5	6(7)*	8	12	14	17
穴深さ(t)	0.7	1.0	1.5	2.3	2.7	3	3.8	4.5	5	5.5	7.5	8

*M10の長さが60ミリ以上は、平径が7になります。

長さ	入り数	鉄	ステンレス
4	100×20	●	●
5	100×20	●	●
6	100×20	●	●
8	100×20	●	●
10	100×20	●	●
12	100×20	●	●

長さ	入り数	鉄											ステンレス	
		標準	ドリル	ドリル	ドリル	ドリル	ドリル	ドリル	ドリル	ドリル	ドリル	ドリル		
4	500×39													●
5	500×39	●	●	●	●	●	●	●	●	●	●	●	●	●
6	500×39	●	●	●	●	●	●	●	●	●	●	●	●	●
8	1000×24	●	●	●	●	●	●	●	●	●	●	●	●	●
8	500×39													●
10	1000×24	●	●	●	●	●	●	●	●	●	●	●	●	●
10	500×39													●
12	1000×24	●	●	●	●	●	●	●	●	●	●	●	●	●
12	500×39													●
14	1000×24	●	●	●	●	●	●	●	●	●	●	●	●	●
14	500×27													●
15	1000×24	●	●	●	●	●	●	●	●	●	●	●	●	●
15	500×30													●
16	1000×24	●	●	●	●	●	●	●	●	●	●	●	●	●
16	500×27													●
20	1000×18	●	●	●	●	●	●	●	●	●	●	●	●	●
20	500×27													●
25	200×39													●
25	500×24	●	●	●	●	●	●	●	●	●	●	●	●	●
30	500×24	●	●	●	●	●	●	●	●	●	●	●	●	●

長さ	入り数	鉄											ステンレス	
		標準	ドリル	ドリル	ドリル	ドリル	ドリル	ドリル	ドリル	ドリル	ドリル	ドリル		
5	500×30													●
6	100×20	●	●	●	●	●	●	●	●	●	●	●	●	●
6	500×27													●
8	1000×15	●	●	●	●	●	●	●	●	●	●	●	●	●
8	500×27													●
10	1000×15	●	●	●	●	●	●	●	●	●	●	●	●	●
10	500×27													●
12	1000×12	●	●	●	●	●	●	●	●	●	●	●	●	●
12	500×15													●
14	1000×12	●	●	●	●	●	●	●	●	●	●	●	●	●
14	500×15													●
15	1000×12	●	●	●	●	●	●	●	●	●	●	●	●	●
15	500×15													●
16	1000×12	●	●	●	●	●	●	●	●	●	●	●	●	●
16	500×15													●
20	500×15													●
20	500×18	●	●	●	●	●	●	●	●	●	●	●	●	●
25	200×27													●
25	500×18	●	●	●	●	●	●	●	●	●	●	●	●	●
30	100×20													●
30	400×15	●	●	●	●	●	●	●	●	●	●	●	●	●
35	400×15	●	●	●	●	●	●	●	●	●	●	●	●	●