

ピアspanワッシャー




50001004

鉄

50031004

SUS 410

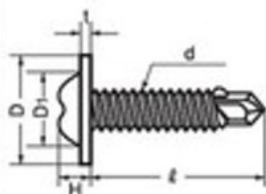

d	4	5
D ₁	7.5	8.5
D	10.0	12.5
H	3.0	3.5
t	1.0	1.0

4.0					
径 φ	入り 数	鉄		SUS 410	
		六角 ナット	六角 ボルト	六角 ナット	六角 ボルト
13	800×10	●	●	●	●
16	600×10	●	●	●	●
19	500×10	●	●	●	●
25	500×10	●	●	●	●
30	400×10	●	●	●	●


5.0					
径 φ	入り 数	鉄		SUS 410	
		六角 ナット	六角 ボルト	六角 ナット	六角 ボルト
13	500×10	●	●	●	●
16	1000×4	●	●	●	●
16	1500×4	●	●	●	●
19	1000×4	●	●	●	●
25	800×4	●	●	●	●
35	500×4	●	●	●	●
45	500×4	●	●	●	●

鉄ピアステンキャップ HEX



50001005

鉄

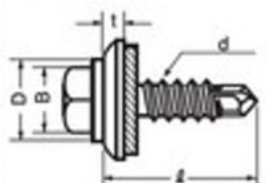

d	5	6
D	13.5	17.0
B	8.0	9.5
t	2.5	3.0

5.0			
径 φ	入り 数	六角 ボルト	六角 ナット
19	750×4	●	●
25	650×4	●	●
35	450×4	●	●
45	350×4	●	●

6.0			
径 φ	入り 数	六角 ボルト	六角 ナット
19	400×4	●	●
25	300×4	●	●
35	250×4	●	●
45	200×4	●	●
50	200×4	●	●
60	150×4	●	●
70	150×4	●	●
90	125×4	●	●
105	125×4	●	●
115	100×4	●	●
135	100×4	●	●
150	80×4	●	●