


SUS410 ピアス皿 小頭(D=7)



50031022

SUS 410

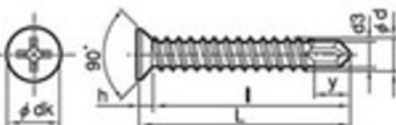

サイズ	L	l(ネジ部)	ϕdk	h	十字穴	ϕd	d3	y	適用板厚
4×10	10±0.8	全ネジ	7.0	2.0	#2	4.2	3.2	3.7	0.9~3.6
4×13	13±0.8	全ネジ	7.0	2.0	#2	4.2	3.4	4.5	0.9~3.6
4×16	16±0.8	全ネジ	7.0	2.0	#2	4.2	3.4	4.5	0.9~3.6
4×19	19±0.8	全ネジ	7.0	2.0	#2	4.2	3.4	4.5	0.9~3.6
4×25	25±0.8	全ネジ	7.0	2.0	#2	4.2	3.4	4.5	0.9~3.6
4×30	30±1.2	全ネジ	7.0	2.0	#2	4.2	3.4	4.5	0.9~3.6
4×35	35±1.2	全ネジ	7.0	2.0	#2	4.2	3.4	4.5	0.9~3.6

4.0


規格	入り数	標準	0x0.5x0.5	0.5x0.5x0.5	0.5x0.5x0.5	0.5x0.5x0.5	0.5x0.5x0.5	0.5x0.5x0.5
10	1500×10	●	●	●	●	●	●	●
13	1000×10	●	●	●	●	●	●	●
16	1000×10	●	●	●	●	●	●	●
19	1000×10	●	●	●	●	●	●	●
25	500×10	●	●	●	●	●	●	●
30	500×10	●	●	●	●	●	●	●
35	400×10	●	●	●	●	●	●	●

SUS410 ピアス皿 小頭(D=7)(細目)



50031023

SUS 410

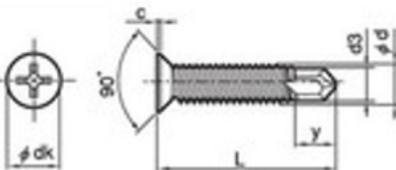

サイズ	L	l(ネジ部)	ϕdk	h	十字穴	ϕd	d3	y	適用板厚
4×10	10±0.8	全ネジ	7.0	2.0	#2	4.2	3.2	3.7	0.9~3.6
4×13	13±0.8	全ネジ	7.0	2.0	#2	4.2	3.4	4.5	0.9~3.6
4×16	16±0.8	全ネジ	7.0	2.0	#2	4.2	3.4	4.5	0.9~3.6
4×19	19±0.8	全ネジ	7.0	2.0	#2	4.2	3.4	4.5	0.9~3.6
4×25	25±0.8	全ネジ	7.0	2.0	#2	4.2	3.4	4.5	0.9~3.6
4×30	30±1.2	全ネジ	7.0	2.0	#2	4.2	3.4	4.5	0.9~3.6
4×35	35±1.2	全ネジ	7.0	2.0	#2	4.2	3.4	4.5	0.9~3.6

4.0

規格	入り数	標準	0x0.5x0.5	0.5x0.5x0.5	0.5x0.5x0.5	0.5x0.5x0.5	0.5x0.5x0.5	0.5x0.5x0.5
10	1500×10	●	●	●	●	●	●	●
13	1000×10	●	●	●	●	●	●	●
16	1000×10	●	●	●	●	●	●	●
19	1000×10	●	●	●	●	●	●	●
25	500×10	●	●	●	●	●	●	●
30	500×10	●	●	●	●	●	●	●
35	400×10	●	●	●	●	●	●	●