


鉄 フィットナット



N0000F00

鉄

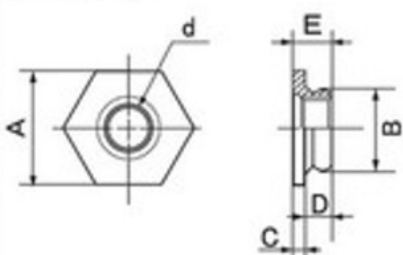

	FM3 ^o	FM4	FM5	FM6	FM8 ^o
A	8.0	9.0	12.0	15.0	17.0
B	3.8	5.0	6.0	7.5	10.0
C	0.8	1.0	1.2	1.6	2.0
D	1.0	1.6	2.0	2.8	3.2
E	1.8	2.6	3.2	4.4	5.2
d	M3-p0.5	M4-p0.7	M5-p0.8	M6-p1.0	M8-p1.25
保証質量(N)	(1,000)	2,300	3,850	6,900	(9,000)


呼び	入り数	2 ク ラ ス ト	非 導 電 性 の ア ン テ ナ
FM3	1000×20	●	●
FM4	1000×20	●	●
FM5	1000×14	●	●
FM6	500×14	●	●
FM8	250×14	●	●

鉄 溶接用 丸ボス



N0000J71

鉄

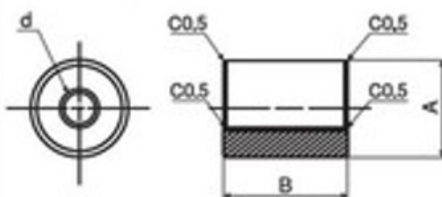

寸法		
d	A	B
M5	φ15	10
	φ15	15
M6	φ15	10
	φ15	15
M8	φ15	20
	φ15	15
	φ15	20
	φ19	15
	φ19	18
	φ19	20
M10	φ20	15
	φ20	20
	φ20	30
	φ20	30

呼び	入り数	非 導 電 性 の ア ン テ ナ	2 ク ラ ス ト
M4×10×10	400×10	●	
M5×15×10	300×10	●	
M5×15×15	250×10	●	
M6×15×10	300×10	●	●
M6×15×15	250×10	●	
M6×15×20	200×10	●	
M8×15×15	250×10	●	
M8×15×20	200×10	●	
M8×19×15	100×10	●	
M8×19×18	100×10	●	●
M8×19×20	100×10	●	
M8×20×15	100×10	●	
M8×20×20	100×10	●	
M8×20×30	50×10	●	
M10×20×15	100×10	●	
M10×20×20	100×10	●	
M10×20×30	50×10	●	

(SS400 相当品)