


ピーク六角ボルト



K000B200

樹脂

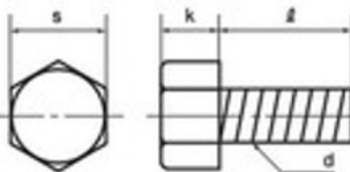

| 呼び径 | ピッチ | s | k |
|-----|------|-----|-----|
| M4 | 0.7 | 7.0 | 2.8 |
| M5 | 0.8 | 8.0 | 3.5 |
| M6 | 1.0 | 10 | 4 |
| M8 | 1.25 | 13 | 5.5 |
| M10 | 1.5 | 17 | 7 |
| M12 | 1.75 | 19 | 8 |

| M4.0 | | |
|------|--------|----|
| 長さ | 入り数 | 定地 |
| 8 | 100×20 | ● |
| 10 | 100×20 | ● |
| 12 | 100×20 | ● |
| 15 | 100×20 | ● |
| 20 | 100×20 | ● |
| 25 | 100×20 | ● |
| 30 | 100×20 | ● |

| M5.0 | | |
|------|--------|----|
| 長さ | 入り数 | 定地 |
| 10 | 100×20 | ● |
| 12 | 100×20 | ● |
| 15 | 100×20 | ● |
| 20 | 100×20 | ● |
| 25 | 100×20 | ● |
| 30 | 100×20 | ● |

| M6.0 | | |
|------|--------|----|
| 長さ | 入り数 | 定地 |
| 10 | 100×20 | ● |
| 12 | 100×20 | ● |
| 15 | 100×20 | ● |
| 20 | 100×20 | ● |
| 25 | 100×20 | ● |
| 30 | 100×20 | ● |
| 35 | 100×20 | ● |
| 40 | 100×20 | ● |
| 45 | 100×20 | ● |
| 50 | 100×20 | ● |

| M8.0 | | |
|------|--------|----|
| 長さ | 入り数 | 定地 |
| 10 | 100×20 | ● |
| 15 | 100×20 | ● |
| 20 | 100×20 | ● |
| 25 | 100×14 | ● |
| 30 | 100×14 | ● |
| 35 | 100×14 | ● |
| 40 | 100×10 | ● |
| 45 | 100×10 | ● |
| 50 | 50×10 | ● |

| M10.0 | | |
|-------|-------|----|
| 長さ | 入り数 | 定地 |
| 20 | 50×20 | ● |
| 25 | 50×20 | ● |
| 30 | 50×14 | ● |
| 35 | 50×14 | ● |
| 40 | 50×14 | ● |
| 45 | 50×14 | ● |
| 50 | 50×10 | ● |

| M12.0 | | |
|-------|-------|----|
| 長さ | 入り数 | 定地 |
| 20 | 50×14 | ● |
| 25 | 50×14 | ● |
| 30 | 50×10 | ● |
| 35 | 50×10 | ● |
| 40 | 50×10 | ● |
| 45 | 50×10 | ● |
| 50 | 50×10 | ● |
| 70 | 25×14 | ● |

ピーク 六角ボルト



K000B210

樹脂

| M4.0 | | |
|------|--------|----|
| 長さ | 入り数 | 定地 |
| 8 | 100×20 | ● |
| 10 | 100×20 | ● |
| 12 | 100×20 | ● |
| 15 | 100×20 | ● |
| 20 | 100×20 | ● |
| 25 | 100×20 | ● |

| M5.0 | | |
|------|--------|----|
| 長さ | 入り数 | 定地 |
| 10 | 100×20 | ● |
| 12 | 100×20 | ● |
| 15 | 100×20 | ● |
| 20 | 100×20 | ● |
| 25 | 100×20 | ● |


| M6.0 | | |
|------|--------|----|
| 長さ | 入り数 | 定地 |
| 10 | 100×20 | ● |
| 12 | 100×20 | ● |
| 15 | 100×20 | ● |
| 20 | 100×20 | ● |
| 25 | 100×20 | ● |

ピーク 六角ナット



K000N200

樹脂

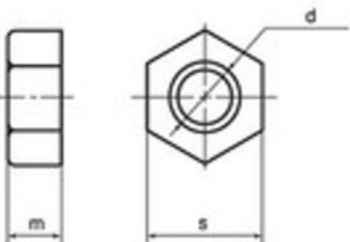

| 呼び | m | s |
|------|------|------|
| M2 | 1.6 | 4.0 |
| M2.6 | 2.0 | 5.0 |
| M3 | 2.4 | 5.5 |
| M4 | 3.2 | 7.0 |
| M5 | 4.0 | 8.0 |
| M6 | 5.0 | 10.0 |
| M8 | 6.5 | 13.0 |
| M10 | 8.0 | 17.0 |
| M12 | 10.0 | 19.0 |

| 呼び | 入り数 | 定地 |
|------|--------|----|
| M2 | 100×20 | ● |
| M2.6 | 100×20 | ● |
| M3 | 100×20 | ● |
| M4 | 100×20 | ● |
| M5 | 100×20 | ● |
| M6 | 100×20 | ● |
| M8 | 100×20 | ● |
| M10 | 100×14 | ● |
| M12 | 100×14 | ● |