



コロターンプライム 旋削加工用チップ

Aタイプチップ

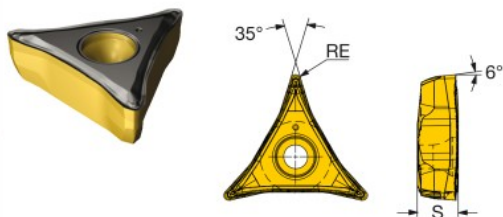

仕 寸 種 別	SSC	S	REEQ	RE	ISO	P	
						4415	4425
L5	CP-A	6.00	0.4	0.40	CP-A1104-L5	★	☆
		.236	.016	.016			
		6.00	0.8	0.79	CP-A1108-L5	★	☆
		.236	.031	.031			
L5W	CP-A	6.00	0.8	0.80	CP-A1108-L5W	★	☆
		.236	.031	.031			
L3	CP-A	6.00		0.79	CP-A1108-L3	★	☆
		.236		.031			
L3WX	CP-A	6.00	0.8	0.80	CP-A1108-L3WX	★	☆
		.236	.031	.031			

Bタイプチップ

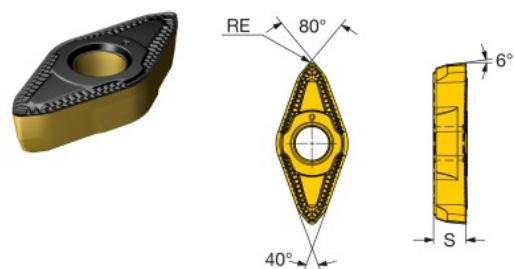

仕 寸 種 別	SSC	S	REEQ	RE	ISO	P	
						4425	
L4	CP-B	5.00	0.8	0.80	CP-B1108-L4	★	
		.197	.031	.031			
L4W	CP-B	5.00	0.8	0.80	CP-B1108-L4W	★	
		.197	.031	.031			
M5	CP-B	5.00	0.8	0.80	CP-B1108-M5	★	
		.197	.031	.031			
M5W	CP-B	5.00	0.8	0.80	CP-B1108-M5W	★	
		.197	.031	.031			
H3W	CP-B	5.00	0.8	0.80	CP-B1108-H3W	★	
		.197	.031	.031			
H3	CP-B	5.00	0.8	0.80	CP-B1108-H3	★	
		.197	.031	.031			

SSC = バイトのSSC (シートサイズ) に合わせてください。

