

CoroDrill 870 3 - 5 x DC



ドリルヘッド径 10.00 - 33.00 mm
円筒シャンク

ISO 9766 準拠
内部給油

3×DC



5×DC

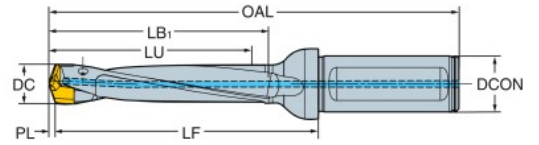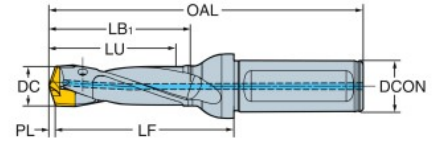

ドリル径 DC, mm 10.00 - 18.00 18.01 - 29.99 30.00 - 33.00
加工公差の目安, mm +0.043/0 (H9) +0.052/0 (H9) +0.062/0 (H9)

LPR = 突出し長さ

ドリルヘッド径, mm		ヘッド 取付サイズ	型番	寸法, mm							
DCN	DCX			DCON	LF	PL	OAL	LB ₁	LU		
10.00	10.49	6	870-1000-6L16-3	16	46.4	1.6	96	35	33.09	0.1	
10.50	10.99	7	870-1050-7L16-3	16	47.31	1.69	97	36	34.67	0.1	
11.00	11.49	8	870-1100-8L16-3	16	49.25	1.75	99	38	36.23	0.1	
11.50	11.99	9	870-1150-9L16-3	16	51.17	1.83	101	40	37.82	0.1	
12.00	12.49	10	870-1200-10L16-3	16	53.1	1.9	103	42	39.38	0.2	
12.50	12.99	11	870-1250-11L16-3	16	54.02	1.98	104	43	40.97	0.2	
13.00	13.49	12	870-1300-12L16-3	16	55.94	2.06	106	45	42.54	0.2	
13.50	13.99	13	870-1350-13L16-3	16	57.86	2.14	108	47	44.13	0.2	
14.00	14.99	14	870-1400-14L20-3	20	63.72	2.28	116	50	47.27	0.2	
15.00	15.99	15	870-1500-15L20-3	20	66.56	2.44	119	53	50.42	0.2	
16.00	16.99	16	870-1600-16L20-3	20	69.42	2.58	122	56	53.56	0.2	
17.00	17.99	17	870-1700-17L20-3	20	73.27	2.73	126	59	56.71	0.2	
18.00	18.99	18	870-1800-18L20-3	20	76.13	2.87	129	62	59.86	0.2	
19.00	19.99	19	870-1900-19L25-3	25	82.98	3.02	142	66	63.01	0.4	
20.00	20.99	20	870-2000-20L25-3	25	86.83	3.17	146	69	66.16	0.4	
21.00	21.99	21	870-2100-21L25-3	25	89.68	3.32	149	72	69.3	0.4	
22.00	22.99	22	870-2200-22L25-3	25	93.53	3.47	153	76	72.45	0.5	
23.00	23.99	23	870-2300-23L25-3	25	97.39	3.61	157	79	75.59	0.5	
24.00	24.99	24	870-2400-24L32-3	32	104.23	3.77	168	82	78.75	0.8	
25.00	25.99	25	870-2500-25L32-3	32	107.09	3.91	171	85	81.9	0.8	
26.00	26.99	26	870-2600-26L32-3	32	111.97	4.03	176	89	85.05	0.8	
27.00	27.99	27	870-2700-27L32-3	32	113.86	4.14	178	92	88.21	0.9	
28.00	28.99	28	870-2800-28L32-3	32	116.68	4.32	181	95	91.36	0.9	
29.00	29.99	29	870-2900-29L32-3	32	119.52	4.48	184	98	94.5	0.9	
30.00	30.99	30	870-3000-30L32-3	32	123.4	4.6	188	102	97.65	1.0	
31.00	33.00	31	870-3100-31L32-3	32	128.92	5.08	194	108	104.09	1.0	

ドリル径 DC, mm 10.00 - 18.00 18.01 - 29.99 30.00 - 33.00
加工公差の目安, mm +0.043/0 (H9) +0.052/0 (H9) +0.062/0 (H9)

ドリルヘッド径, mm		ヘッド 取付サイズ	型番	寸法, mm							
DCN	DCX			DCON	LF	PL	OAL	LB ₁	LU		
10.00	10.49	6	870-1000-6L16-5	16	67.4	1.6	117	56	54.07	0.1	
10.50	10.99	7	870-1050-7L16-5	16	69.31	1.69	119	58	56.65	0.1	
11.00	11.49	8	870-1100-8L16-5	16	72.25	1.75	122	61	59.21	0.1	
11.50	11.99	9	870-1150-9L16-5	16	75.17	1.83	125	64	61.8	0.2	
12.00	12.49	10	870-1200-10L16-5	16	77.1	1.9	127	66	64.36	0.2	
12.50	12.99	11	870-1250-11L16-5	16	80.02	1.98	130	69	66.95	0.2	
13.00	13.49	12	870-1300-12L16-5	16	82.94	2.06	133	72	69.52	0.2	
13.50	13.99	13	870-1350-13L16-5	16	84.86	2.14	135	74	72.11	0.2	
14.00	14.99	14	870-1400-14L20-5	20	93.72	2.28	146	80	77.25	0.2	
15.00	15.99	15	870-1500-15L20-5	20	98.56	2.44	151	85	82.4	0.2	
16.00	16.99	16	870-1600-16L20-5	20	103.42	2.58	156	90	87.54	0.2	
17.00	17.99	17	870-1700-17L20-5	20	109.27	2.73	162	95	92.69	0.2	
18.00	18.99	18	870-1800-18L20-5	20	113.13	2.87	166	100	97.84	0.2	
19.00	19.99	19	870-1900-19L25-5	25	122.98	3.02	182	106	102.99	0.4	
20.00	20.99	20	870-2000-20L25-5	25	128.83	3.17	188	111	108.14	0.4	
21.00	21.99	21	870-2100-21L25-5	25	133.68	3.32	193	116	113.28	0.5	
22.00	22.99	22	870-2200-22L25-5	25	139.53	3.47	199	122	118.43	0.6	
23.00	23.99	23	870-2300-23L25-5	25	145.39	3.61	205	127	123.57	0.6	
24.00	24.99	24	870-2400-24L32-5	32	155.23	3.77	219	132	128.73	0.9	
25.00	25.99	25	870-2500-25L32-5	32	159.09	3.91	223	137	133.88	0.9	
26.00	26.99	26	870-2600-26L32-5	32	165.97	4.03	230	143	139.03	1.0	
27.00	27.99	27	870-2700-27L32-5	32	170.86	4.14	235	148	144.19	1.0	
28.00	28.99	28	870-2800-28L32-5	32	174.68	4.32	239	153	149.34	1.1	
29.00	29.99	29	870-2900-29L32-5	32	180.52	4.48	245	158	154.48	1.1	
30.00	30.99	30	870-3000-30L32-5	32	186.4	4.6	251	164	159.63	1.2	
31.00	33.00	31	870-3100-31L32-5	32	194.92	5.08	260	174	170.09	1.2	



標準品以外の製品はテーラーメイドにて
広範囲に対応しています。