


CoroDrill 870 鋼用ドリルヘッド -PM

ヘッド径 10.00 - 33.00 mm

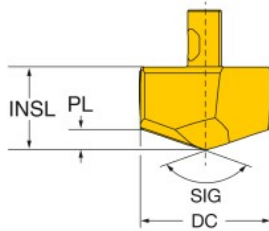

Tailor Made

標準品以外の製品はテーラーメイドにて
広範囲に対応しています。

P

ドリルヘッド径 mm	ヘッド 取付サイズ	型番	GC	寸法, mm		
				4334	PL	INSL
DC						
10.00	6	870-1000-6-PM	●	1.5	6.20	142°
10.10		870-1010-6-PM	●	1.6	6.20	142°
10.20		870-1020-6-PM	●	1.6	6.20	142°
10.30		870-1030-6-PM	●	1.6	6.20	142°
10.40		870-1040-6-PM	●	1.6	6.20	142°
10.50	7	870-1050-7-PM	●	1.6	6.20	142°
10.60		870-1060-7-PM	●	1.6	6.20	142°
10.70		870-1070-7-PM	●	1.7	6.20	142°
10.80		870-1080-7-PM	●	1.7	6.20	142°
10.90		870-1090-7-PM	●	1.7	6.20	142°
11.00	8	870-1100-8-PM	●	1.7	6.90	142°
11.10		870-1110-8-PM	●	1.7	6.90	142°
11.11		870-1111-8-PM	●	1.7	6.90	142°
11.20		870-1120-8-PM	●	1.7	6.90	142°
11.30		870-1130-8-PM	●	1.7	6.90	142°
11.40		870-1140-8-PM	●	1.8	6.90	142°
11.50	9	870-1150-9-PM	●	1.8	6.90	142°
11.60		870-1160-9-PM	●	1.8	6.90	142°
11.70		870-1170-9-PM	●	1.8	6.90	142°
11.80		870-1180-9-PM	●	1.8	6.90	142°
11.90		870-1190-9-PM	●	1.8	6.90	142°
12.00	10	870-1200-10-PM	●	1.8	7.50	142°
12.10		870-1210-10-PM	●	1.9	7.50	142°
12.20		870-1220-10-PM	●	1.9	7.50	142°
12.30		870-1230-10-PM	●	1.9	7.50	142°
12.40		870-1240-10-PM	●	1.9	7.50	142°
12.50	11	870-1250-11-PM	●	1.9	7.50	142°
12.60		870-1260-11-PM	●	1.9	7.50	142°
12.70		870-1270-11-PM	●	2.0	7.50	142°
12.80		870-1280-11-PM	●	2.0	7.50	142°
12.90		870-1290-11-PM	●	2.0	7.50	142°
13.00	12	870-1300-12-PM	●	2.0	8.00	142°
13.10		870-1310-12-PM	●	2.0	8.00	142°
13.20		870-1320-12-PM	●	2.0	8.00	142°
13.30		870-1330-12-PM	●	2.0	8.00	142°
13.40		870-1340-12-PM	●	2.1	8.00	142°
13.50	13	870-1350-13-PM	●	2.1	8.00	142°
13.60		870-1360-13-PM	●	2.1	8.00	142°
13.70		870-1370-13-PM	●	2.1	8.00	142°
13.80		870-1380-13-PM	●	2.1	8.00	142°
13.90		870-1390-13-PM	●	2.1	8.00	142°
14.00	14	870-1400-14-PM	●	2.1	8.70	142°
14.10		870-1410-14-PM	●	2.2	8.70	142°
14.20		870-1420-14-PM	●	2.2	8.70	142°
14.29		870-1429-14-PM	●	2.2	8.70	142°
14.30		870-1430-14-PM	●	2.2	8.70	142°
14.40		870-1440-14-PM	●	2.2	8.70	142°
14.50		870-1450-14-PM	●	2.2	8.70	142°
14.60		870-1460-14-PM	●	2.2	8.70	142°
14.70		870-1470-14-PM	●	2.3	8.70	142°
14.80		870-1480-14-PM	●	2.3	8.70	142°
14.90		870-1490-14-PM	●	2.3	8.70	142°

※2個単位で注文可能です

ドリルヘッド径 mm	ヘッド 取付サイズ	型番	GC	寸法, mm		
				4334	PL	INSL
DC						
15.00	15	870-1500-15-PM	●	2.3	9.30	142°
15.10		870-1510-15-PM	●	2.3	9.30	142°
15.20		870-1520-15-PM	●	2.3	9.30	142°
15.30		870-1530-15-PM	●	2.3	9.30	142°
15.40		870-1540-15-PM	●	2.4	9.30	142°
15.50		870-1550-15-PM	●	2.4	9.30	142°
15.60		870-1560-15-PM	●	2.4	9.30	142°
15.70		870-1570-15-PM	●	2.4	9.30	142°
15.80		870-1580-15-PM	●	2.4	9.30	142°
15.88		870-1588-15-PM	●	2.4	9.30	142°
15.90		870-1590-15-PM	●	2.4	9.30	142°
16.00	16	870-1600-16-PM	●	2.4	10.00	142°
16.10		870-1610-16-PM	●	2.4	10.00	142°
16.13		870-1613-16-PM	●	2.5	10.00	142°
16.20		870-1620-16-PM	●	2.5	10.00	142°
16.30		870-1630-16-PM	●	2.5	10.00	142°
16.40		870-1640-16-PM	●	2.5	10.00	142°
16.50		870-1650-16-PM	●	2.5	10.00	142°
16.60		870-1660-16-PM	●	2.5	10.00	142°
16.70		870-1670-16-PM	●	2.5	10.00	142°
16.80		870-1680-16-PM	●	2.6	10.00	142°
16.90		870-1690-16-PM	●	2.6	10.00	142°
17.00	17	870-1700-17-PM	●	2.6	10.60	142°
17.10		870-1710-17-PM	●	2.6	10.60	142°
17.20		870-1720-17-PM	●	2.6	10.60	142°
17.30		870-1730-17-PM	●	2.6	10.60	142°
17.40		870-1740-17-PM	●	2.7	10.60	142°
17.46		870-1746-17-PM	●	2.7	10.60	142°
17.50		870-1750-17-PM	●	2.7	10.60	142°
17.60		870-1760-17-PM	●	2.7	10.60	142°
17.70		870-1770-17-PM	●	2.7	10.60	142°
17.80		870-1780-17-PM	●	2.7	10.60	142°
17.90		870-1790-17-PM	●	2.7	10.60	142°
18.00	18	870-1800-18-PM	●	2.7	11.30	142°
18.10		870-1810-18-PM	●	2.7	11.30	142°
18.20		870-1820-18-PM	●	2.8	11.30	142°
18.30		870-1830-18-PM	●	2.8	11.30	142°
18.40		870-1840-18-PM	●	2.8	11.30	142°
18.50		870-1850-18-PM	●	2.8	11.30	142°
18.60		870-1860-18-PM	●	2.8	11.30	142°
18.70		870-1870-18-PM	●	2.8	11.30	142°
18.80		870-1880-18-PM	●	2.9	11.30	142°
18.90		870-1890-18-PM	●	2.9	11.30	142°
19.00	19	870-1900-19-PM	●	2.9	11.90	142°
19.05		870-1905-19-PM	●	2.9	11.90	142°
19.10		870-1910-19-PM	●	2.9	11.90	142°
19.20		870-1920-19-PM	●	2.9	11.90	142°
19.25		870-1925-19-PM	●	2.9	11.90	142°
19.30		870-1930-19-PM	●	2.9	11.90	142°
19.40		870-1940-19-PM	●	2.9	11.90	142°
19.50		870-1950-19-PM	●	3.0	11.90	142°
19.60		870-1960-19-PM	●	3.0	11.90	142°
19.70		870-1970-19-PM	●	3.0	11.90	142°
19.80		870-1980-19-PM	●	3.0	11.90	142°
19.90		870-1990-19-PM	●	3.0	11.90	142°

※2個単位で注文可能です

●=標準在庫