


すくい角	半径方向 軸方向	-12.5°~16.5° -8°	1.5mm 17°
------	-------------	---------------------	--------------

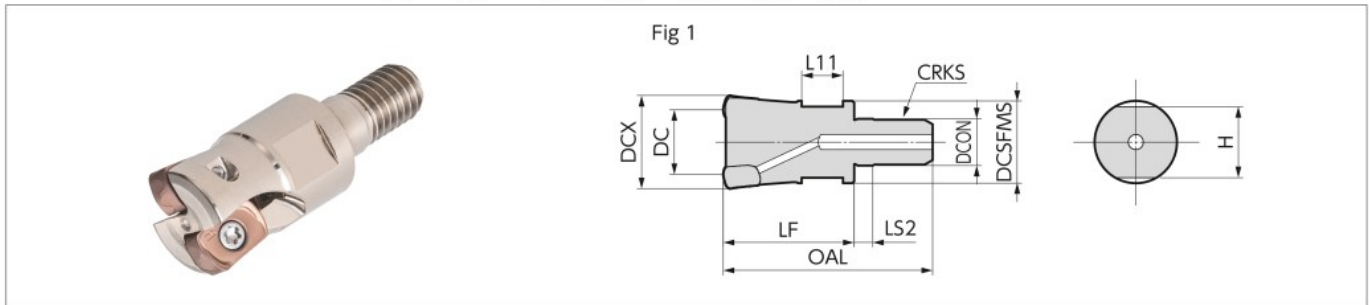

## ■ ヘッド

寸法(mm)

型番	在庫	最大刃径 DCX	刃径 DC	ボス DCSFMS	取付部径 DCON	ねじ CRKS	全長 OAL	有効長さ LF	長さ LS2	平取 L11	幅 H	刃数	重量 (kg)	Fig
DMSL 06016M08Z2	●	16	8.4	14.5	8.5	M8	42	25	5	8	13	2	0.03	1
06018M08Z2	●	18	10.4	14.5	8.5	M8	42	25	5	8	13	2	0.03	1
06020M10Z3	●	20	12.4	18	10.5	M10	49	30	5	10	15	3	0.05	1
06020M10Z4	●	20	12.4	18	10.5	M10	49	30	5	10	15	4	0.05	1
06022M10Z3	●	22	14.3	18	10.5	M10	49	30	5	10	15	3	0.06	1
06022M10Z4	●	22	14.3	18	10.5	M10	49	30	5	10	15	4	0.06	1
06025M12Z4	●	25	17.3	22	12.5	M12	56	35	5	11	19	4	0.10	1
06025M12Z5	●	25	17.3	22	12.5	M12	56	35	5	11	19	5	0.10	1
06026M12Z4	●	26	18.3	22	12.5	M12	56	35	5	11	19	4	0.10	1
06028M12Z4	●	28	20.3	22	12.5	M12	56	35	5	11	19	4	0.11	1
06028M12Z5	●	28	20.3	22	12.5	M12	56	35	5	11	19	5	0.11	1
06030M16Z5	●	30	22.3	28.5	17	M16	63	40	5	12	24	5	0.18	1
06032M16Z5	●	32	24.3	28.5	17	M16	63	40	5	12	24	5	0.20	1
06032M16Z6	●	32	24.3	28.5	17	M16	63	40	5	12	24	6	0.20	1
06035M16Z5	●	35	27.3	28.5	17	M16	63	40	5	12	24	5	0.21	1
06035M16Z6	●	35	27.3	28.5	17	M16	63	40	5	12	24	6	0.21	1
06040M16Z6	●	40	32.3	28.5	17	M16	63	40	5	12	24	6	0.25	1
06042M16Z6	●	42	34.3	28.5	17	M16	63	40	5	12	24	6	0.26	1
06042M16Z7	●	42	34.3	28.5	17	M16	63	40	5	12	24	7	0.26	1

本体にインサートは組み込んでありません。

## ■ 型番の呼び方

# DMSL 06 025 M12 Z4

型式記号

インサート  
サイズ

最大刃径

取り付けねじ  
サイズ

刃数

## ■ 部品

インサート用皿ねじ	一体型レンチ	焼付防止剤
BFTX02507IP	2.0 TRDR08IP	SUMI-P