

ネクシオMDE-H型(内部給油式)

炭素合金
~0.28%炭素合金
0.29%~調質
鋼高硬度鋼
~45
HRCステン
レス鋼

Ti合金

耐熱
鋼

鋳鉄

ダクタイル
鋳鉄アルミニウム
合金

銅合金

New

NX
コート

油穴付き


3D

5D

8D

※ h6, h8 公差は N38 参照

Fig 1 (ダブルマージン)

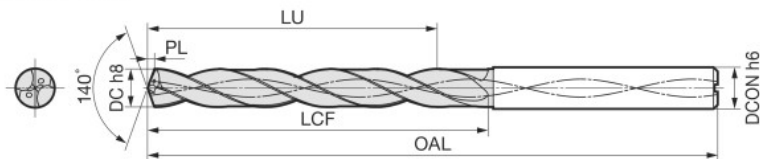

本体 刃径φ1.0~2.7mm

寸法(mm)

刃径 DC	穴深さ (L/D)	在庫	型番	有効長 LU	フルート長 LCF	全長 OAL	先端 PL	シャンク径 DCON	Fig
1.0	3	●	MDE 0100S03H03	6.7	8.2	57.2			1
	5	●	0100S03H05	8.7	10.2	59.2	0.2	3.0	1
	8	●	0100S03H08	11.7	13.2	62.2			1
1.1	3	●	MDE 0110S03H03	6.6	8.2	57.2			1
	5	●	0110S03H05	8.6	10.2	59.2	0.2	3.0	1
	8	●	0110S03H08	12.6	14.2	62.2			1
1.2	3	●	MDE 0120S03H03	7.4	9.2	57.2			1
	5	●	0120S03H05	9.4	11.2	59.2	0.2	3.0	1
	8	●	0120S03H08	13.4	15.2	62.2			1
1.3	3	●	MDE 0130S03H03	7.3	9.2	57.2			1
	5	●	0130S03H05	10.3	12.2	59.2	0.2	3.0	1
	8	●	0130S03H08	14.3	16.2	62.2			1
1.4	3	●	MDE 0140S03H03	8.2	10.3	57.3			1
	5	●	0140S03H05	11.2	13.3	59.3	0.3	3.0	1
	8	●	0140S03H08	15.2	17.3	62.3			1
1.5	3	●	MDE 0150S03H03	9.1	11.3	57.3			1
	5	●	0150S03H05	12.1	14.3	59.3	0.3	3.0	1
	8	●	0150S03H08	16.1	18.3	62.3			1
1.6	3	●	MDE 0160S03H03	8.9	11.3	59.3			1
	5	●	0160S03H05	11.9	14.3	62.3	0.3	3.0	1
	8	●	0160S03H08	16.9	19.3	67.3			1
1.7	3	●	MDE 0170S03H03	9.8	12.3	59.3			1
	5	●	0170S03H05	12.8	15.3	62.3	0.3	3.0	1
	8	●	0170S03H08	17.8	20.3	67.3			1
1.8	3	●	MDE 0180S03H03	9.6	12.3	59.3			1
	5	●	0180S03H05	13.6	16.3	62.3	0.3	3.0	1
	8	●	0180S03H08	18.6	21.3	67.3			1
1.9	3	●	MDE 0190S03H03	10.5	13.3	59.3			1
	5	●	0190S03H05	14.5	17.3	62.3	0.3	3.0	1
	8	●	0190S03H08	19.5	22.3	70.3			1
2.0	3	●	MDE 0200S03H03	11.4	14.4	59.4			1
	5	●	0200S03H05	15.4	18.4	62.4	0.4	3.0	1
	8	●	0200S03H08	21.4	24.4	70.4			1
2.1	3	●	MDE 0210S03H03	11.3	14.4	59.4			1
	5	●	0210S03H05	15.3	18.4	62.4	0.4	3.0	1
	8	●	0210S03H08	22.3	25.4	70.4			1
2.2	3	●	MDE 0220S03H03	12.1	15.4	59.4			1
	5	●	0220S03H05	16.1	19.4	62.4	0.4	3.0	1
	8	●	0220S03H08	23.1	26.4	70.4			1
2.3	3	●	MDE 0230S03H03	12.0	15.4	63.4			1
	5	●	0230S03H05	17.0	20.4	68.4	0.4	3.0	1
	8	●	0230S03H08	24.0	27.4	75.4			1
2.4	3	●	MDE 0240S03H03	12.8	16.4	63.4			1
	5	●	0240S03H05	17.8	21.4	68.4	0.4	3.0	1
	8	●	0240S03H08	24.8	28.4	75.4			1
2.5	3	●	MDE 0250S03H03	13.8	17.5	63.5			1
	5	●	0250S03H05	18.8	22.5	68.5	0.5	3.0	1
	8	●	0250S03H08	25.8	29.5	75.5			1
2.6	3	●	MDE 0260S03H03	13.6	17.5	63.5			1
	5	●	0260S03H05	18.6	22.5	68.5	0.5	3.0	1
	8	●	0260S03H08	26.6	30.5	75.5			1
2.7	3	●	MDE 0270S03H03	14.5	18.5	68.5			1
	5	●	0270S03H05	19.5	23.5	78.5	0.5	3.0	1
	8	●	0270S03H08	27.5	31.5	81.5			1

材種 ACT100

本体 刃径φ2.76~4.3mm

寸法(mm)

刃径 DC	穴深さ (L/D)	在庫	型番	有効長 LU	フルート長 LCF	全長 OAL	先端 PL	シャンク径 DCON	Fig
2.76	5	●	MDE0276S03H05	20.3	24.5	78.5	0.5	3.0	1
2.78	5	●	0278S03H05	20.3	24.5	78.5	0.5	3.0	1
2.8	3	●	MDE 0280S03H03	14.3	18.5	68.5			1
	5	●	0280S03H05	20.3	24.5	78.5	0.5	3.0	1
	8	●	0280S03H08	28.3	32.5	81.5			1
2.9	3	●	MDE 0290S03H03	15.2	19.5	68.5			1
	5	●	0290S03H05	21.2	25.5	78.5	0.5	3.0	1
	8	●	0290S03H08	29.2	33.5	81.5			1
3.0	3	●	MDE 0300S03H03	14.0	18.5	68.5			1
	5	●	0300S03H05	24.0	28.5	78.5	0.5	3.0	1
	8	●	0300S03H08	29.0	33.5	81.5			1
3.1	3	●	MDE 0310S04H03	16.0	20.6	72.6			1
	5	●	0310S04H05	28.0	32.6	86.6	0.6	4.0	1
	8	●	0310S04H08	34.5	39.1	92.6			1
3.2	3	●	MDE 0320S04H03	15.8	20.6	72.6			1
	5	●	0320S04H05	27.8	32.6	86.6	0.6	4.0	1
	8	●	0320S04H08	34.3	39.1	92.6			1
3.3	3	●	MDE 0330S04H03	15.7	20.6	72.6			1
	5	●	0330S04H05	27.7	32.6	86.6	0.6	4.0	1
	8	●	0330S04H08	34.2	39.1	92.6			1
3.4	3	●	MDE 0340S04H03	15.5	20.6	72.6			1
	5	●	0340S04H05	27.5	32.6	86.6	0.6	4.0	1
	8	●	0340S04H08	34.0	39.1	92.6			1
3.5	3	●	MDE 0350S04H03	15.4	20.6	72.6			1
	5	●	0350S04H05	27.4	32.6	86.6	0.6	4.0	1
	8	●	0350S04H08	33.9	39.1	92.6			1
3.6	3	●	MDE 0360S04H03	17.8	23.2	72.7			1
	5	●	0360S04H05	31.3	36.7	86.7	0.7	4.0	1
	8	●	0360S04H08	39.3	44.7	92.7			1
3.66	5	●	MDE 0366S04H05	31.2	36.7	86.7	0.7	4.0	1
3.68	5	●	0368S04H05	31.2	36.7	86.7	0.7	4.0	1
3.7	3	●	MDE 0370S04H03	17.7	23.2	72.7			1
	5	●	0370S04H05	31.2	36.7	86.7	0.7	4.0	1
	8	●	0370S04H08	39.2	44.7	92.7			1
3.8	3	●	MDE 0380S04H03	17.5	23.2	72.7			1
	5	●	0380S04H05	31.0	36.7	86.7	0.7	4.0	1
	8	●	0380S04H08	39.0	44.7	92.7			1
3.9	3	●	MDE 0390S04H03	17.4	23.2	72.7			1
	5	●	0390S04H05	30.9	36.7	86.7	0.7	4.0	1
	8	●	0390S04H08	38.9	44.7	92.7			1
4.0	3	●	MDE 0400S04H03	17.2	23.2	72.7			1
	5	●	0400S04H05	30.7	36.7	86.7	0.7	4.0	1
	8	●	0400S04H08	38.7	44.7	92.7			1
4.1	3	●	MDE 0410S05H03	19.6	25.7	80.7			1
	5	●	0410S05H05	34.6	40.7	98.7	0.7	5.0	1
	8	●	0410S05H08	44.1	50.2	105.7			1
4.2	3	●	MDE 0420S05H03	19.5	25.8	80.8			1
	5	●	0420S05H05	34.5	40.8	98.8	0.8	5.0	1
	8	●	0420S05H08	44.0	50.3	105.8			1
4.3	3	●	MDE 0430S05H03	19.4	25.8	80.8			1
	5	●	0430S05H05	34.4	40.8	98.8	0.8	5.0	1
	8	●	0430S05H08	43.9	50.3	105.8			1

材種 ACT100