

MDM型(内部給油式)

炭素合金鋼
~0.28%

炭素合金鋼
0.29%~

ステン
レス鋼

Ti合金

耐熱
鋼

鋳鉄

ダクタイル
鋳鉄

New NX
コート

3D 5D

※ h6, h8 公差は N38 参照

Fig 1 (刃径φ4.1未満)


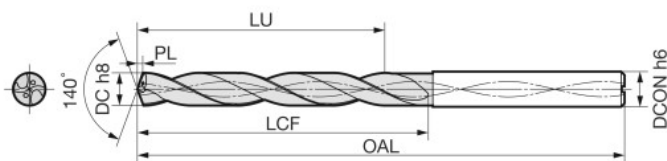


Fig 2 (刃径φ4.1以上)

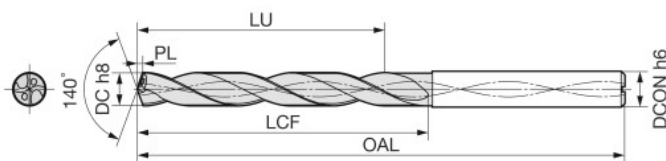

本体 刃径φ3.0 ~ 5.6mm

寸法(mm)

刃径 DC	穴深さ (L/D)	在庫	型番	有効長 LU	フルート長 LCF	全長 OAL	先端 PL	シャンク径 DCON	Fig
3.0	3	●	MDM 0300S03H03	14.0	18.5	68.5	0.5	3.0	1
	5	●	0300S03H05	24.0	28.5	78.5			1
3.1	3	●	MDM 0310S04H03	16.0	20.6	72.6	0.6	4.0	1
	5	●	0310S04H05	28.0	32.6	86.6			1
3.2	3	●	MDM 0320S04H03	15.8	20.6	72.6	0.6	4.0	1
	5	●	0320S04H05	27.8	32.6	86.6			1
3.3	3	●	MDM 0330S04H03	15.7	20.6	72.6	0.6	4.0	1
	5	●	0330S04H05	27.7	32.6	86.6			1
3.4	3	●	MDM 0340S04H03	15.5	20.6	72.6	0.6	4.0	1
	5	●	0340S04H05	27.5	32.6	86.6			1
3.5	3	●	MDM 0350S04H03	15.4	20.6	72.6	0.6	4.0	1
	5	●	0350S04H05	27.4	32.6	86.6			1
3.6	3	●	MDM 0360S04H03	17.8	23.2	72.7	0.7	4.0	1
	5	●	0360S04H05	31.3	36.7	86.7			1
3.7	3	●	MDM 0370S04H03	17.7	23.2	72.7	0.7	4.0	1
	5	●	0370S04H05	31.2	36.7	86.7			1
3.8	3	●	MDM 0380S04H03	17.5	23.2	72.7	0.7	4.0	1
	5	●	0380S04H05	31.0	36.7	86.7			1
3.9	3	●	MDM 0390S04H03	17.4	23.2	72.7	0.7	4.0	1
	5	●	0390S04H05	30.9	36.7	86.7			1
4.0	3	●	MDM 0400S04H03	17.2	23.2	72.7	0.7	4.0	1
	5	●	0400S04H05	30.7	36.7	86.7			1
4.1	3	●	MDM 0410S05H03	19.6	25.7	80.7	0.7	5.0	2
	5	●	0410S05H05	34.6	40.7	98.7			2
4.2	3	●	MDM 0420S05H03	19.5	25.8	80.8	0.8	5.0	2
	5	●	0420S05H05	34.5	40.8	98.8			2
4.3	3	●	MDM 0430S05H03	19.4	25.8	80.8	0.8	5.0	2
	5	●	0430S05H05	34.4	40.8	98.8			2
4.4	3	●	MDM 0440S05H03	19.2	25.8	80.8	0.8	5.0	2
	5	●	0440S05H05	34.2	40.8	98.8			2
4.5	3	●	MDM 0450S05H03	19.1	25.8	80.8	0.8	5.0	2
	5	●	0450S05H05	34.1	40.8	98.8			2
4.6	3	●	MDM 0460S05H03	21.4	28.3	80.8	0.8	5.0	2
	5	●	0460S05H05	37.9	44.8	98.8			2
4.7	3	●	MDM 0470S05H03	21.4	28.4	80.9	0.9	5.0	2
	5	●	0470S05H05	37.9	44.9	98.9			2
4.8	3	●	MDM 0480S05H03	21.2	28.4	80.9	0.9	5.0	2
	5	●	0480S05H05	37.7	44.9	98.9			2
4.9	3	●	MDM 0490S05H03	21.1	28.4	80.9	0.9	5.0	2
	5	●	0490S05H05	37.6	44.9	98.9			2
5.0	3	●	MDM 0500S05H03	20.9	28.4	80.9	0.9	5.0	2
	5	●	0500S05H05	37.4	44.9	98.9			2
5.1	3	●	MDM 0510S06H03	20.8	28.4	82.9	0.9	6.0	2
	5	●	0510S06H05	37.3	44.9	100.9			2
5.2	3	●	MDM 0520S06H03	20.6	28.4	82.9	0.9	6.0	2
	5	●	0520S06H05	37.1	44.9	100.9			2
5.3	3	●	MDM 0530S06H03	20.6	28.5	83.0	1.0	6.0	2
	5	●	0530S06H05	37.1	45.0	101.0			2
5.4	3	●	MDM 0540S06H03	20.4	28.5	83.0	1.0	6.0	2
	5	●	0540S06H05	36.9	45.0	101.0			2
5.5	3	●	MDM 0550S06H03	20.3	28.5	83.0	1.0	6.0	2
	5	●	0550S06H05	36.8	45.0	101.0			2
5.6	3	●	MDM 0560S06H03	22.6	31.0	83.0	1.0	6.0	2
	5	●	0560S06H05	40.6	49.0	101.0			2

材種 ACT70

本体 刃径φ5.7 ~ 8.3mm

寸法(mm)

刃径 DC	穴深さ (L/D)	在庫	型番	有効長 LU	フルート長 LCF	全長 OAL	先端 PL	シャンク径 DCON	Fig
5.7	3	●	MDM 0570S06H03	22.5	31.0	83.0	1.0	6.0	2
	5	●	0570S06H05	40.5	49.0	101.0			2
5.8	3	●	MDM 0580S06H03	22.4	31.1	83.1	1.1	6.0	2
	5	●	0580S06H05	40.4	49.1	101.1			2
5.9	3	●	MDM 0590S06H03	22.3	31.1	83.1	1.1	6.0	2
	5	●	0590S06H05	40.3	49.1	101.1			2
6.0	3	●	MDM 0600S06H03	22.1	31.1	83.1	1.1	6.0	2
	5	●	0600S06H05	40.1	49.1	101.1			2
6.1	3	●	MDM 0610S07H03	24.5	33.6	89.1	1.1	7.0	2
	5	●	0610S07H05	44.0	53.1	110.1			2
6.2	3	●	MDM 0620S07H03	24.3	33.6	89.1	1.1	7.0	2
	5	●	0620S07H05	43.8	53.1	110.1			2
6.3	3	●	MDM 0630S07H03	24.2	33.6	89.1	1.1	7.0	2
	5	●	0630S07H05	43.7	53.1	110.1			2
6.4	3	●	MDM 0640S07H03	24.1	33.7	89.2	1.2	7.0	2
	5	●	0640S07H05	43.6	53.2	110.2			2
6.5	3	●	MDM 0650S07H03	24.0	33.7	89.2	1.2	7.0	2
	5	●	0650S07H05	43.5	53.2	110.2			2
6.6	3	●	MDM 0660S07H03	26.3	36.2	89.2	1.2	7.0	2
	5	●	0660S07H05	47.3	57.2	110.2			2
6.7	3	●	MDM 0670S07H03	26.2	36.2	89.2	1.2	7.0	2
	5	●	0670S07H05	47.2	57.2	110.2			2
6.8	3	●	MDM 0680S07H03	26.0	36.2	89.2	1.2	7.0	2
	5	●	0680S07H05	47.0	57.2	110.2			2
6.9	3	●	MDM 0690S07H03	26.0	36.3	89.3	1.3	7.0	2
	5	●	0690S07H05	47.0	57.3	110.3			2
7.0	3	●	MDM 0700S07H03	25.8	36.3	89.3	1.3	7.0	2
	5	●	0700S07H05	46.8	57.3	110.3			2
7.1	3	●	MDM 0710S08H03	28.2	38.8	95.3	1.3	8.0	2
	5	●	0710S08H05	50.7	61.3	119.3			2
7.2	3	●	MDM 0720S08H03	28.0	38.8	95.3	1.3	8.0	2
	5	●	0720S08H05	50.5	61.3	119.3			2
7.3	3	●	MDM 0730S08H03	27.9	38.8	95.3	1.3	8.0	2
	5	●	0730S08H05	50.4	61.3	119.3			2
7.4	3	●	MDM 0740S08H03	27.7	38.8	95.3	1.3	8.0	2
	5	●	0740S08H05	50.2	61.3	119.3			2
7.5	3	●	MDM 0750S08H03	27.7	38.9	95.4	1.4	8.0	2
	5	●	0750S08H05	50.2	61.4	119.4			2
7.6	3	●	MDM 0760S08H03	30.0	41.4	95.4	1.4	8.0	2
	5	●	0760S08H05	54.0	65.4	119.4			2
7.7	3	●	MDM 0770S08H03	29.9	41.4	95.4	1.4	8.0	2
	5	●	0770S08H05	53.9	65.4	119.4			2
7.8	3	●	MDM 0780S08H03	29.7	41.4	95.4	1.4	8.0	2
	5	●	0780S08H05	53.7	65.4	119.4			2
7.9	3	●	MDM 0790S08H03	29.6	41.4	95.4	1.4	8.0	2
	5	●	0790S08H05	53.6	65.4	119.4			2
8.0	3	●	MDM 0800S08H03	29.5	41.5	95.5	1.5	8.0	2
	5	●	0800S08H05	53.5	65.5	119.5			2
8.1	3	●	MDM 0810S09H03	31.9	44.0	101.5	1.5	9.0	2
	5	●	0810S09H05	57.4	69.5	128.5			2
8.2	3	●	MDM 0820S09H03	31.7	44.0	101.5	1.5	9.0	2
	5	●	0820S09H05	57.2	69.5	128.5			2
8.3	3	●	MDM 0830S09H03	31.6	44.0	101.5	1.5	9.0	2
	5	●	0830S09H05	57.1	69.5	128.5			2

材種 ACT70