

MLDH-L型/MLDH-P型(内部給油式)

- 炭素合金鋼 ~0.28%
- 炭素合金鋼 0.29%~
- 調質鋼
- 高硬度鋼 ~45 HRC
- ステンレス鋼
- Ti合金
- 耐熱鋼
- 鋳鉄
- ダクタイル鋳鉄
- アルミニウム合金

PVDコート 油穴付き 5D 12D 20D 30D Pilot 2D

Fig 1 (MLDH-P型)


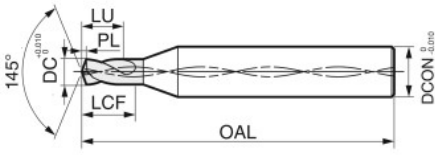


Fig 2 (MLDH-L型)

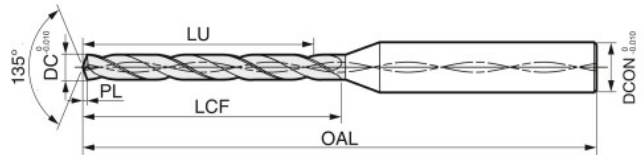

本体 刃径φ0.80 ~ 0.90mm

寸法(mm)

刃径 DC	穴深さ (LD)	在庫	型番	有効長 LU	フルート長 LCF	全長 OAL	先端 PL	シャンク径 DCON	Fig
0.80	2	●	MLDH 0800P	2.0	3.2	45	0.1	3.0	1
	5	●	0800L5	6.8	8	50.0	0.2		2
	12	●	0800L12	12.8	14	55			2
	20	●	0800L20	17.8	19	60			2
	30	●	0800L30	26.8	28	70			2
0.81	2	●	MLDH 0810P	2.0	3.2	45	0.1	3.0	1
	5	●	0810L5	7.8	9	50.0	0.2		2
	12	●	0810L12	12.8	14	55			2
	20	●	0810L20	17.8	19	60			2
	30	●	0810L30	26.8	28	70			2
0.82	2	●	MLDH 0820P	2.1	3.3	45	0.1	3.0	1
	5	●	0820L5	7.8	9	50.0	0.2		2
	12	●	0820L12	12.8	14	55			2
	20	●	0820L20	18.8	20	60			2
	30	●	0820L30	26.8	28	70			2
0.83	2	●	MLDH 0830P	2.1	3.3	45	0.1	3.0	1
	5	●	0830L5	7.8	9	50.0	0.2		2
	12	●	0830L12	12.8	14	55			2
	20	●	0830L20	18.8	20	60			2
	30	●	0830L30	26.8	28	70			2
0.84	2	●	MLDH 0840P	2.1	3.4	45	0.1	3.0	1
	5	●	0840L5	7.7	9	50.0	0.2		2
	12	●	0840L12	12.7	14	55			2
	20	●	0840L20	18.7	20	60			2
	30	●	0840L30	27.7	29	70			2
0.85	2	●	MLDH 0850P	2.1	3.4	45	0.1	3.0	1
	5	●	0850L5	7.7	9	50.0	0.2		2
	12	●	0850L12	12.7	14	55			2
	20	●	0850L20	18.7	20	60			2
	30	●	0850L30	27.7	29	70			2
0.86	2	●	MLDH 0860P	2.1	3.4	45	0.1	3.0	1
	5	●	0860L5	7.7	9	50.0	0.2		2
	12	●	0860L12	13.7	15	55			2
	20	●	0860L20	19.7	21	65			2
	30	●	0860L30	27.7	29	70			2
0.87	2	●	MLDH 0870P	2.2	3.5	45	0.1	3.0	1
	5	●	0870L5	7.7	9	50.0	0.2		2
	12	●	0870L12	13.7	15	55			2
	20	●	0870L20	19.7	21	65			2
	30	●	0870L30	28.7	30	70			2
0.88	2	●	MLDH 0880P	2.2	3.5	45	0.1	3.0	1
	5	●	0880L5	7.7	9	50.0	0.2		2
	12	●	0880L12	13.7	15	55			2
	20	●	0880L20	19.7	21	65			2
	30	●	0880L30	28.7	30	70			2
0.89	2	●	MLDH 0890P	2.3	3.6	45	0.1	3.0	1
	5	●	0890L5	7.7	9	50.0	0.2		2
	12	●	0890L12	13.7	15	55			2
	20	●	0890L20	19.7	21	65			2
	30	●	0890L30	28.7	30	70			2
0.90	2	●	MLDH 0900P	2.3	3.6	45	0.1	3.0	1
	5	●	0900L5	7.7	10	50.0	0.2		2
	12	●	0900L12	13.7	15	55			2
	20	●	0900L20	20.7	22	65			2
	30	●	0900L30	29.7	31	75			2

型番末尾P:ガイド穴用
材種 ACV70

本体 刃径φ0.91 ~ 1.05mm

寸法(mm)

刃径 DC	穴深さ (LD)	在庫	型番	有効長 LU	フルート長 LCF	全長 OAL	先端 PL	シャンク径 DCON	Fig
0.91	2	●	MLDH 0910P	2.2	3.6	45	0.1	3.0	1
	5	●	0910L5	8.6	10	50.0	0.2		2
	12	●	0910L12	13.6	15	55			2
	20	●	0910L20	20.6	22	65			2
	30	●	0910L30	29.6	31	75			2
0.92	2	●	MLDH 0920P	2.3	3.7	45	0.1	3.0	1
	5	●	0920L5	8.6	10	50.0	0.2		2
	12	●	0920L12	14.6	16	60			2
	20	●	0920L20	20.6	22	65			2
	30	●	0920L30	29.6	31	75			2
0.93	2	●	MLDH 0930P	2.3	3.7	45	0.1	3.0	1
	5	●	0930L5	8.6	10	50.0	0.2		2
	12	●	0930L12	14.6	16	60			2
	20	●	0930L20	20.6	22	65			2
	30	●	0930L30	30.6	32	75			2
0.94	2	●	MLDH 0940P	2.4	3.8	45	0.1	3.0	1
	5	●	0940L5	8.6	10	50.0	0.2		2
	12	●	0940L12	14.6	16	60			2
	20	●	0940L20	21.6	23	65			2
	30	●	0940L30	30.6	32	75			2
0.95	2	●	MLDH 0950P	2.4	3.8	45	0.1	3.0	1
	5	●	0950L5	8.6	10	50.0	0.2		2
	12	●	0950L12	14.6	16	60			2
	20	●	0950L20	21.6	23	65			2
	30	●	0950L30	30.6	32	75			2
0.96	2	●	MLDH 0960P	2.4	3.8	45	0.1	3.0	1
	5	●	0960L5	8.6	10	50.0	0.2		2
	12	●	0960L12	14.6	16	60			2
	20	●	0960L20	21.6	23	65			2
	30	●	0960L30	31.6	33	75			2
0.97	2	●	MLDH 0970P	2.4	3.9	45	0.1	3.0	1
	5	●	0970L5	8.5	10	50.0	0.2		2
	12	●	0970L12	14.5	16	60			2
	20	●	0970L20	21.5	23	65			2
	30	●	0970L30	31.5	33	75			2
0.98	2	●	MLDH 0980P	2.4	3.9	45	0.1	3.0	1
	5	●	0980L5	8.5	10	50.0	0.2		2
	12	●	0980L12	15.5	17	60			2
	20	●	0980L20	22.5	24	65			2
	30	●	0980L30	31.5	33	75			2
0.99	2	●	MLDH 0990P	2.5	4	45	0.1	3.0	1
	5	●	0990L5	8.5	10	50.0	0.2		2
	12	●	0990L12	15.5	17	60			2
	20	●	0990L20	22.5	24	65			2
	30	●	0990L30	32.5	34	75			2
1.00	2	●	MLDH 1000P	2.5	4	45	0.1	3.0	1
	5	●	1000L5	8.5	10	50.0	0.2		2
	12	●	1000L12	15.5	17	60			2
	20	●	1000L20	22.5	24	65			2
	30	●	1000L30	32.5	34	75			2
1.05	2	●	MLDH 1050P	2.6	4.2	45	0.1	3.0	1
	5	●	1050L5	10.4	12	55.0	0.2		2
	12	●	1050L12	16.4	18	60			2
	20	●	1050L20	23.4	25	65			2
	30	●	1050L30	34.4	36	80			2

型番末尾P:ガイド穴用
材種 ACV70

受注生産対応 上記寸法・在庫一覧以外の刃径及び長さについての製作は別途ご相談ください。