


はめあい寸法公差は総合カタログ[N章 一般資料編]をご参照ください。

Fig 1

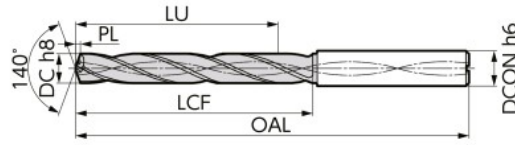

■ 刃径 φ3.0~4.3mm

寸法(mm)

刃径 DC	穴深さ (L/D)	在庫	型番	有効長 LU	フルート長 LCF	全長 OAL	先端 PL	シャンク径 DCON	Fig
3.0	3	●	MDH 0300S04H03	16.1	20.6	72.6	0.6	4.0	1
3.0	5	●	0300S04H05	28.1	32.6	86.6	0.6	4.0	1
3.0	8	●	0300S04H08	31.1	35.6	92.6	0.6	4.0	1
3.1	3	●	MDH 0310S04H03	16.0	20.6	72.6	0.6	4.0	1
3.1	5	●	0310S04H05	28.0	32.6	86.6	0.6	4.0	1
3.1	8	●	0310S04H08	31.0	35.6	92.6	0.6	4.0	1
3.2	3	●	MDH 0320S04H03	15.8	20.6	72.6	0.6	4.0	1
3.2	5	●	0320S04H05	27.8	32.6	86.6	0.6	4.0	1
3.2	8	●	0320S04H08	30.8	35.6	92.6	0.6	4.0	1
3.3	3	●	MDH 0330S04H03	15.7	20.6	72.6	0.6	4.0	1
3.3	5	●	0330S04H05	27.7	32.6	86.6	0.6	4.0	1
3.3	8	●	0330S04H08	30.7	35.6	92.6	0.6	4.0	1
3.4	3	●	MDH 0340S04H03	15.5	20.6	72.6	0.6	4.0	1
3.4	5	●	0340S04H05	27.5	32.6	86.6	0.6	4.0	1
3.4	8	●	0340S04H08	30.5	35.6	92.6	0.6	4.0	1
3.5	3	●	MDH 0350S04H03	15.4	20.6	72.6	0.6	4.0	1
3.5	5	●	0350S04H05	27.4	32.6	86.6	0.6	4.0	1
3.5	8	●	0350S04H08	30.4	35.6	92.6	0.6	4.0	1
3.6	3	●	MDH 0360S04H03	17.8	23.2	72.7	0.7	4.0	1
3.6	5	●	0360S04H05	31.3	36.7	86.7	0.7	4.0	1
3.6	8	●	0360S04H08	37.3	42.7	92.7	0.7	4.0	1
3.7	3	●	MDH 0370S04H03	17.7	23.2	72.7	0.7	4.0	1
3.7	5	●	0370S04H05	31.2	36.7	86.7	0.7	4.0	1
3.7	8	●	0370S04H08	37.2	42.7	92.7	0.7	4.0	1
3.8	3	●	MDH 0380S04H03	17.5	23.2	72.7	0.7	4.0	1
3.8	5	●	0380S04H05	31.0	36.7	86.7	0.7	4.0	1
3.8	8	●	0380S04H08	37.0	42.7	92.7	0.7	4.0	1
3.9	3	●	MDH 0390S04H03	17.4	23.2	72.7	0.7	4.0	1
3.9	5	●	0390S04H05	30.9	36.7	86.7	0.7	4.0	1
3.9	8	●	0390S04H08	36.9	42.7	92.7	0.7	4.0	1
4.0	3	●	MDH 0400S04H03	17.2	23.2	72.7	0.7	4.0	1
4.0	5	●	0400S04H05	30.7	36.7	86.7	0.7	4.0	1
4.0	8	●	0400S04H08	36.7	42.7	92.7	0.7	4.0	1
4.1	3	●	MDH 0410S06H03	19.7	25.8	80.8	0.8	6.0	1
4.1	5	●	0410S06H05	34.7	40.8	98.8	0.8	6.0	1
4.1	8	●	0410S06H08	41.7	47.8	105.8	0.8	6.0	1
4.2	3	●	MDH 0420S06H03	19.5	25.8	80.8	0.8	6.0	1
4.2	5	●	0420S06H05	34.5	40.8	98.8	0.8	6.0	1
4.2	8	●	0420S06H08	41.5	47.8	105.8	0.8	6.0	1
4.3	3	●	MDH 0430S06H03	19.4	25.8	80.8	0.8	6.0	1
4.3	5	●	0430S06H05	34.4	40.8	98.8	0.8	6.0	1
4.3	8	●	0430S06H08	41.4	47.8	105.8	0.8	6.0	1

材種 ACH70

■ 刃径 φ4.4~5.7mm

寸法(mm)

刃径 DC	穴深さ (L/D)	在庫	型番	有効長 LU	フルート長 LCF	全長 OAL	先端 PL	シャンク径 DCON	Fig
4.4	3	●	MDH 0440S06H03	19.2	25.8	80.8	0.8	6.0	1
4.4	5	●	0440S06H05	34.2	40.8	98.8	0.8	6.0	1
4.4	8	●	0440S06H08	41.2	47.8	105.8	0.8	6.0	1
4.5	3	●	MDH 0450S06H03	19.1	25.8	80.8	0.8	6.0	1
4.5	5	●	0450S06H05	34.1	40.8	98.8	0.8	6.0	1
4.5	8	●	0450S06H08	41.1	47.8	105.8	0.8	6.0	1
4.6	3	●	MDH 0460S06H03	21.0	27.9	80.9	0.9	6.0	1
4.6	5	●	0460S06H05	38.0	44.9	98.9	0.9	6.0	1
4.6	8	●	0460S06H08	46.0	52.9	105.9	0.9	6.0	1
4.7	3	●	MDH 0470S06H03	20.9	27.9	80.9	0.9	6.0	1
4.7	5	●	0470S06H05	37.9	44.9	98.9	0.9	6.0	1
4.7	8	●	0470S06H08	45.9	52.9	105.9	0.9	6.0	1
4.8	3	●	MDH 0480S06H03	20.7	27.9	80.9	0.9	6.0	1
4.8	5	●	0480S06H05	37.7	44.9	98.9	0.9	6.0	1
4.8	8	●	0480S06H08	45.7	52.9	105.9	0.9	6.0	1
4.9	3	●	MDH 0490S06H03	20.6	27.9	80.9	0.9	6.0	1
4.9	5	●	0490S06H05	37.6	44.9	98.9	0.9	6.0	1
4.9	8	●	0490S06H08	45.6	52.9	105.9	0.9	6.0	1
5.0	3	●	MDH 0500S06H03	20.4	27.9	80.9	0.9	6.0	1
5.0	5	●	0500S06H05	37.4	44.9	98.9	0.9	6.0	1
5.0	8	●	0500S06H08	45.4	52.9	105.9	0.9	6.0	1
5.1	3	●	MDH 0510S06H03	20.9	28.5	83.0	1.0	6.0	1
5.1	5	●	0510S06H05	37.4	45.0	101.0	1.0	6.0	1
5.1	8	●	0510S06H08	52.4	60.0	119.0	1.0	6.0	1
5.2	3	●	MDH 0520S06H03	20.7	28.5	83.0	1.0	6.0	1
5.2	5	●	0520S06H05	37.2	45.0	101.0	1.0	6.0	1
5.2	8	●	0520S06H08	52.2	60.0	119.0	1.0	6.0	1
5.3	3	●	MDH 0530S06H03	20.6	28.5	83.0	1.0	6.0	1
5.3	5	●	0530S06H05	37.1	45.0	101.0	1.0	6.0	1
5.3	8	●	0530S06H08	52.1	60.0	119.0	1.0	6.0	1
5.4	3	●	MDH 0540S06H03	20.4	28.5	83.0	1.0	6.0	1
5.4	5	●	0540S06H05	36.9	45.0	101.0	1.0	6.0	1
5.4	8	●	0540S06H08	51.9	60.0	119.0	1.0	6.0	1
5.5	3	●	MDH 0550S06H03	20.3	28.5	83.0	1.0	6.0	1
5.5	5	●	0550S06H05	36.8	45.0	101.0	1.0	6.0	1
5.5	8	●	0550S06H08	51.8	60.0	119.0	1.0	6.0	1
5.6	3	●	MDH 0560S06H03	22.7	31.1	83.1	1.1	6.0	1
5.6	5	●	0560S06H05	40.7	49.1	101.1	1.1	6.0	1
5.6	8	●	0560S06H08	58.7	67.1	119.1	1.1	6.0	1
5.7	3	●	MDH 0570S06H03	22.6	31.1	83.1	1.1	6.0	1
5.7	5	●	0570S06H05	40.6	49.1	101.1	1.1	6.0	1
5.7	8	●	0570S06H08	58.6	67.1	119.1	1.1	6.0	1

材種 ACH70