


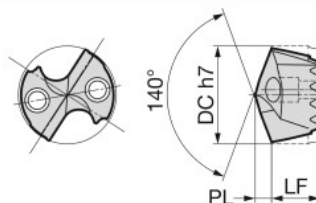

*h7公差は総合カタログN章一般資料編をご覧ください。

刃先交換ヘッド

Fig 1



■ 刃先交換ヘッド MSL型 刃径φ22.8~28.1mm 寸法(mm)

刃径 DC	在庫	型番	肩部長 LF	先端 PL	適用ホルダ	Fig
22.8	○	SMDT 2280 MSL	11.0	4.1	SMDH220□	1
22.9	○	SMDT 2290 MSL				1
23.0	○	SMDT 2300 MSL				1
23.1	○	SMDT 2310 MSL		4.2		1
23.2	○	SMDT 2320 MSL				1
23.3	○	SMDT 2330 MSL				1
23.4	○	SMDT 2340 MSL	11.0		SMDH230□	1
23.5	○	SMDT 2350 MSL				1
23.6	○	SMDT 2360 MSL		4.3		1
23.7	○	SMDT 2370 MSL				1
23.8	○	SMDT 2380 MSL				1
23.9	○	SMDT 2390 MSL		4.3		1
24.0	○	SMDT 2400 MSL				1
24.1	○	SMDT 2410 MSL				1
24.2	○	SMDT 2420 MSL		4.4		1
24.3	○	SMDT 2430 MSL	11.0		SMDH240□	1
24.4	○	SMDT 2440 MSL				1
24.5	○	SMDT 2450 MSL				1
24.6	○	SMDT 2460 MSL		4.5		1
24.7	○	SMDT 2470 MSL				1
24.8	○	SMDT 2480 MSL				1
24.9	○	SMDT 2490 MSL		4.5		1
25.0	○	SMDT 2500 MSL				1
25.1	○	SMDT 2510 MSL				1
25.2	○	SMDT 2520 MSL				1
25.3	○	SMDT 2530 MSL		4.6		1
25.4	○	SMDT 2540 MSL	11.3		SMDH250□	1
25.5	○	SMDT 2550 MSL				1
25.6	○	SMDT 2560 MSL				1
25.7	○	SMDT 2570 MSL		4.7		1
25.8	○	SMDT 2580 MSL				1
25.9	○	SMDT 2590 MSL		4.7		1
26.0	○	SMDT 2600 MSL				1
26.1	○	SMDT 2610 MSL				1
26.2	○	SMDT 2620 MSL				1
26.3	○	SMDT 2630 MSL	11.7	4.8	SMDH260□	1
26.4	○	SMDT 2640 MSL				1
26.5	○	SMDT 2650 MSL				1
26.6	○	SMDT 2660 MSL				1
26.7	○	SMDT 2670 MSL		4.9		1
26.8	○	SMDT 2680 MSL				1
26.9	○	SMDT 2690 MSL				1
27.0	○	SMDT 2700 MSL		4.9		1
27.1	○	SMDT 2710 MSL				1
27.2	○	SMDT 2720 MSL				1
27.3	○	SMDT 2730 MSL				1
27.4	○	SMDT 2740 MSL	12.2		SMDH270□	1
27.5	○	SMDT 2750 MSL		5.0		1
27.6	○	SMDT 2760 MSL				1
27.7	○	SMDT 2770 MSL				1
27.8	○	SMDT 2780 MSL		5.1		1
27.9	○	SMDT 2790 MSL				1
28.0	○	SMDT 2800 MSL	12.6	5.1	SMDH280□	1
28.1	○	SMDT 2810 MSL				1

材種 ACT100 推奨切削条件 適用ホルダ

■ 刃先交換ヘッド MSL型 刃径φ28.2~30.8mm 寸法(mm)

刃径 DC	在庫	型番	肩部長 LF	先端 PL	適用ホルダ	Fig
28.2	○	SMDT 2820 MSL		5.1		1
28.3	○	SMDT 2830 MSL				1
28.4	○	SMDT 2840 MSL				1
28.5	○	SMDT 2850 MSL	12.6	5.2	SMDH280□	1
28.6	○	SMDT 2860 MSL				1
28.7	○	SMDT 2870 MSL				1
28.8	○	SMDT 2880 MSL				1
28.9	○	SMDT 2890 MSL				1
29.0	○	SMDT 2900 MSL		5.3		1
29.1	○	SMDT 2910 MSL				1
29.2	○	SMDT 2920 MSL				1
29.3	○	SMDT 2930 MSL	13.1		SMDH290□	1
29.4	○	SMDT 2940 MSL				1
29.5	○	SMDT 2950 MSL		5.4		1
29.6	○	SMDT 2960 MSL				1
29.7	○	SMDT 2970 MSL				1
29.8	○	SMDT 2980 MSL				1
29.9	○	SMDT 2990 MSL		5.4		1
30.0	○	SMDT 3000 MSL				1
30.1	○	SMDT 3010 MSL				1
30.2	○	SMDT 3020 MSL		5.5		1
30.3	○	SMDT 3030 MSL	13.5		SMDH300□	1
30.4	○	SMDT 3040 MSL				1
30.5	○	SMDT 3050 MSL				1
30.6	○	SMDT 3060 MSL		5.6		1
30.7	○	SMDT 3070 MSL				1
30.8	○	SMDT 3080 MSL				1

材種 ACT100 推奨切削条件 適用ホルダ