


# MDUS型/MDSS型(外部給油式/小径タイプ)

MDUS 炭素合金鋼 ~0.28% 低合金鋼 0.23%~ ステンレス鋼 アルミニウム合金 銅合金

MDSS 炭素合金鋼 ~0.28% 低合金鋼 0.23%~ 調質鋼 高硬度鋼 ~45 HRC 高硬度鋼 46HRC~ ステンレス鋼 耐熱鋼 鋳鉄 ガクタイト 鋳鉄 アルミニウム合金

PVD コート FB コート 10D

※ h6 公差は N38 参照

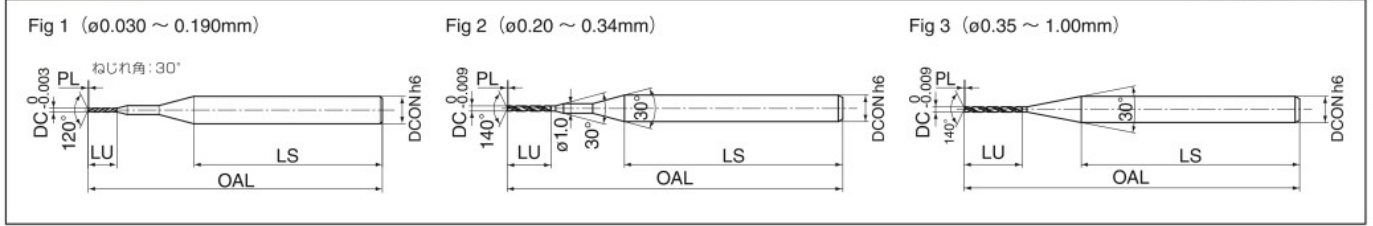

## 本体 刃径 ø0.030 ~ 0.49mm

寸法(mm)

刃径 DC	穴深さ (L/D)	在庫	型番	有効長 LU	全長 OAL	先端 PL	シャンク径 LS	シャンク径 DCON	Fig
0.030	10	●	MDUS 0030-30C	0.26					1
0.035		●	0035-30C	0.35					1
0.040		●	0040-30C	0.34	38.0	0.01	28	3.0	1
0.045		●	0045-30C	0.46					1
0.050		●	0050-30C	0.45					1
0.055	10	●	MDUS 0055-30C	0.55					1
0.060		●	0060-30C	0.54					1
0.065		●	0065-30C	0.64					1
0.070		●	0070-30C	0.63	38.0	0.02	28	3.0	1
0.075		●	0075-30C	0.73					1
0.080	10	●	0080-30C	0.72					1
0.085		●	0085-30C	0.92					1
0.090		●	MDUS 0090-30C	0.91					1
0.095		●	0095-30C	0.91					1
0.100		●	0100-30C	0.90	38.0	0.03	28	3.0	1
0.110	10	●	0110-30C	1.09					1
0.120		●	0120-30C	1.08					1
0.130		●	MDUS 0130-30C	1.37					1
0.140		●	0140-30C	1.36	38.0	0.04	28	3.0	1
0.150		●	0150-30C	1.35					1
0.160	10	●	MDUS 0160-30C	1.64					1
0.170		●	0170-30C	1.63	38.0	0.05	28	3.0	1
0.180		●	0180-30C	1.62					1
0.190		●	0190-30C	1.71					1
0.20		10	●	MDSS 0020	2.25				
0.21	●		0021	2.24					2
0.22	●		0022	2.23	38	0.04	28	3.0	2
0.23	●		0023	2.21					2
0.24	●		0024	2.20					2
0.25	10	●	MDSS 0025	2.19					2
0.26		●	0026	2.18					2
0.27		●	0027	2.16	38	0.05	28	3.0	2
0.28		●	0028	2.15					2
0.29		●	0029	2.14					2
0.30	10	●	0030	2.6					2
0.31		●	MDSS 0031	2.6					2
0.32		●	0032	2.6					2
0.33		●	0033	2.6	38	0.06	28	3.0	2
0.34		●	0034	2.6					2
0.35	10	●	0035	3.6					3
0.36		●	MDSS 0036	3.6					3
0.37		●	0037	3.5					3
0.38		●	0038	3.5	38	0.07	28	3.0	3
0.39		●	0039	3.5					3
0.40	10	●	0040	4.5					3
0.41		●	0041	4.5					3
0.42		●	MDSS 0042	4.5					3
0.43		●	0043	4.5					3
0.44		●	0044	4.5	38	0.08	28	3.0	3
0.45	10	●	0045	4.4					3
0.46		●	0046	4.4					3
0.47		●	MDSS 0047	4.4					3
0.48		●	0048	4.4	38	0.09	28	3.0	3
0.49		●	0049	4.4					3

材種 MDUS型 KP011 / MDSS型 ACF40B

## 本体 刃径 ø0.50 ~ 1.00mm

寸法(mm)

刃径 DC	穴深さ (L/D)	在庫	型番	有効長 LU	全長 OAL	先端 PL	シャンク径 LS	シャンク径 DCON	Fig
0.50	10	●	MDSS 0050	5.4					3
0.51		●	0051	5.4	38	0.09	27	3.0	3
0.52		●	0052	5.4					3
0.53		●	MDSS 0053	5.3					3
0.54		●	0054	5.3					3
0.55	10	●	0055	5.3	38	0.10	27	3.0	3
0.56		●	0056	5.3					3
0.57		●	0057	5.3					3
0.58		●	MDSS 0058	5.3					3
0.59		●	0059	5.3			27		3
0.60	10	●	0060	6.3	38	0.11		3.0	3
0.61		●	0061	6.2					3
0.62		●	0062	6.2			26		3
0.63		●	0063	6.2					3
0.64		●	MDSS 0064	6.2					3
0.65	10	●	0065	6.2					3
0.66		●	0066	6.2	38	0.12	26	3.0	3
0.67		●	0067	6.2					3
0.68		●	0068	6.2					3
0.69		●	MDSS 0069	6.1			26		3
0.70	10	●	0070	8.1					3
0.71		●	0071	8.1	38	0.13	24	3.0	3
0.72		●	0072	8.1					3
0.73		●	0073	8.1					3
0.74		●	0074	8.1					3
0.75	10	●	MDSS 0075	8.1					3
0.76		●	0076	8.1					3
0.77		●	0077	8.0	38	0.14	24	3.0	3
0.78		●	0078	8.0					3
0.79		●	0079	8.0					3
0.80	10	●	MDSS 0080	9.0					3
0.81		●	0081	9.0					3
0.82		●	0082	9.0	38	0.15	23	3.0	3
0.83		●	0083	9.0					3
0.84		●	0084	9.0					3
0.85	10	●	0085	8.9					3
0.86		●	MDSS 0086	8.9					3
0.87		●	0087	8.9					3
0.88		●	0088	8.9	38	0.16	23	3.0	3
0.89		●	0089	8.9					3
0.90	10	●	0090	9.9					3
0.91		●	MDSS 0091	9.9					3
0.92		●	0092	9.9					3
0.93		●	0093	9.8	38	0.17	22	3.0	3
0.94		●	0094	9.8					3
0.95	10	●	0095	9.8					3
0.96		●	0096	9.8					3
0.97		●	MDSS 0097	9.8					3
0.98		●	0098	9.8	38	0.18	22	3.0	3
0.99		●	0099	9.8					3
1.00	●	0100	10.8			21		3	

材種 MDUS型 KP011 / MDSS型 ACF40B

穴あけ

J

ドリル

交換式

交換式

リマ

取り付け

その他