


LQ3 Series

外形寸法図

フィメールコネクタ：LQ3H-F

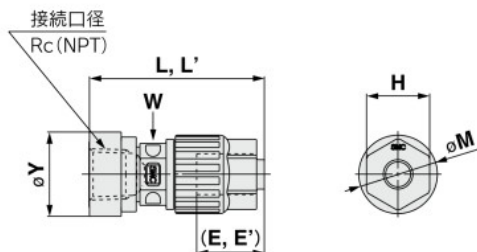

(E, E')はナット端面からの必要チューブ挿入
代参考寸法です。
(E'), L'はナット材質：PVDFの寸法です。
Wは対辺寸法です。

ミリサイズ

型式	適用 チューブ 外径	接続ねじ Rc・NPT	E	E'	H	L	L'	M	最小 穴径	W	Y
LQ3H11-F□	φ4	1/8"	10	9	11	35	34	14	2.5	10	18.5
LQ3H12-F□	φ3	1/8"							2		
LQ3H21-F□	φ6	1/8"	17	16	16	40	39	20	4	14	18.5
LQ3H22-F□		1/4"				45	44				21.5
LQ3H31-F□	φ10	1/8"	22.5	19.5	21	50.5	47.5	25	7.5	18	18.5
LQ3H32-F□	φ8								6.4		
LQ3H33-F□	φ10	1/4"				55	52		7.5		
LQ3H34-F□	φ8								6.4		
LQ3H35-F□	φ10	3/8"				55.5	52.5		7.5		25
LQ3H36-F□	φ8								6.4		
LQ3H41-F□	φ12	1/4"	24	22	24	55.5	53	29	9.5	22	21.5
LQ3H42-F□		3/8"				58	56				25
LQ3H43-F□		1/2"				66	64				29.5
LQ3H51-F□	φ19	3/8"	26.5	24	32	67	64.5	37	14	30	25
LQ3H52-F□		1/2"				72	69.5		16		29.5
LQ3H53-F□		3/4"				73.5	71		36		
LQ3H61-F□	φ25	1/2"	30	26	41	81.5	77.5	49	17.5	36	29.5
LQ3H62-F□		3/4"				83	79		22		36
LQ3H63-F□		1"				90.5	86.5		44.5		

インチサイズ

型式	適用 チューブ 外径	接続ねじ Rc・NPT	E	E'	H	L	L'	M	最小 穴径	W	Y
LQ3H1A-F□	1/8"	1/8"	10	9	11	35	34	14	2	10	18.5
LQ3H2A-F□	1/4"	1/8"	17	16	16	40	39	20	4	14	18.5
LQ3H2B-F□		1/4"				45	44				21.5
LQ3H3A-F□	3/8"	1/8"	22.5	19.5	21	50.5	47.5	25	6.4	18	18.5
LQ3H3B-F□		1/4"				55	52				21.5
LQ3H3C-F□		3/8"				55.5	52.5				25
LQ3H4A-F□	1/2"	1/4"	24.5	22.5	24	55.5	53	29	9.5	22	21.5
LQ3H4B-F□		3/8"				58	56				25
LQ3H4C-F□		1/2"				66	64				29.5
LQ3H5A-F□	3/4"	3/8"	26.5	24	32	67	64.5	37	14	30	25
LQ3H5B-F□		1/2"				72	69.5		16		29.5
LQ3H5C-F□		3/4"				73.5	71		36		
LQ3H6A-F□	1"	1/2"	30	26	41	81.5	77.5	49	17.5	36	29.5
LQ3H6B-F□		3/4"				83	79		22		36
LQ3H6C-F□		1"				90.5	86.5		44.5		