


LQ3 Series

外形寸法図

フィメールエルボ : LQ3L-F

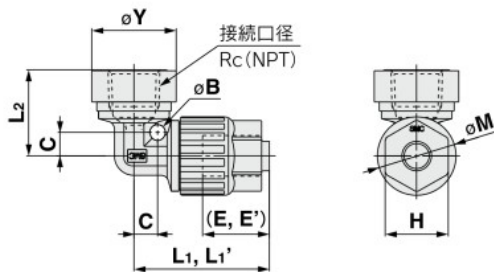

(E, E')はナット端面からの必要チューブ挿入
代参考寸法です。
(E'), L1' はナット材質 : PVDFの寸法です。

ミリサイズ

型式	適用 チューブ 外径	接続ねじ Rc・NPT	B	C	E	E'	H	L ₁	L ₁ '	L ₂	M	最小 穴径	Y
LQ3L11-F□	φ4	1/8"	3.5	4.8	10	9	11	28.5	27.5	19.5	14	2.5	18.5
LQ3L12-F□	φ3	1/8"								2			
LQ3L21-F□	φ6	1/8"	4	6	17	16	16	34.5	33.5	20	20	4	18.5
LQ3L22-F□		1/4"								22			21.5
LQ3L31-F□	φ10	1/8"	5	9	22.5	19.5	21	47.5	44.5	23	25	7.5	18.5
LQ3L32-F□	φ8	1/8"								6.4			
LQ3L33-F□	φ10	1/4"								7.5			
LQ3L34-F□	φ8	1/4"								24		6.4	21.5
LQ3L35-F□	φ10	1/4"										7.5	
LQ3L36-F□	φ8	3/8"								25.5		6.4	25
LQ3L41-F□	φ12	1/4"	6	10	24	22	24	52.5	50.5	23.5	29	9.5	21.5
LQ3L42-F□		3/8"								26			25
LQ3L43-F□		1/2"								30			29.5
LQ3L51-F□	φ19	3/8"	7	14	26.5	24	32	64	61.5	30.5	37	14	25
LQ3L52-F□		1/2"								35.5			29.5
LQ3L53-F□		3/4"								37			36
LQ3L61-F□	φ25	1/2"	8	18	30	26	41	78	74	41	49	17.5	29.5
LQ3L62-F□		3/4"								42.5			36
LQ3L63-F□		1"								46			44.5

インチサイズ

型式	適用 チューブ 外径	接続ねじ Rc・NPT	B	C	E	E'	H	L ₁	L ₁ '	L ₂	M	最小 穴径	Y
LQ3L1A-F□	1/8"	1/8"	3.5	4.8	10	9	11	28.5	27.5	19.5	14	2	18.5
LQ3L2A-F□	1/4"	1/8"	4	6	17	16	16	34.5	33.5	20	20	4	18.5
LQ3L2B-F□		1/4"								22			21.5
LQ3L3A-F□	3/8"	1/8"	5	9	22.5	19.5	21	47.5	44.5	23	25	6.4	18.5
LQ3L3B-F□		1/4"								24			21.5
LQ3L3C-F□		3/8"								25.5			25
LQ3L4A-F□	1/2"	1/4"	6	10	24.5	22.5	24	52.5	50.5	23.5	29	9.5	21.5
LQ3L4B-F□		3/8"								26			25
LQ3L4C-F□		1/2"								30			29.5
LQ3L5A-F□	3/4"	3/8"	7	14	26.5	24	32	64	61.5	30.5	37	14	25
LQ3L5B-F□		1/2"								35.5			29.5
LQ3L5C-F□		3/4"								37			36
LQ3L6A-F□	1"	1/2"	8	18	30	26	41	78	74	41	49	17.5	29.5
LQ3L6B-F□		3/4"								42.5			36
LQ3L6C-F□		1"								46			44.5