

KQB2 Series

適用チューブ: ミリサイズ 接続ねじ: M, R, Rc

外形寸法図

エルボユニオン: KQB2L



適用チューブ 外径mm	接続ねじ R, M	型式	H (六角対辺)	注1) øD	L1	L2	A*	M	注2) 有効断 面積mm ²	質量g
ø3.2	M5×0.8	KQB2L23-M5	8	8.3	13.1	14.8	16	12	2.6	6.5
	1/8	KQB2L23-01S	10		13.6	14.9	15.9		3	8
	1/4	KQB2L23-02S	14		13.6	18.7	18.1		3	16.6
ø4	M5×0.8	KQB2L04-M5	8	9.1	13.7	15.2	16.8	12.6	3.5	7
	1/8	KQB2L04-01S	10		14.4	15.3	16.7		4.2	8.6
	1/4	KQB2L04-02S	14		14.4	19.1	18.9		4.2	17.5
ø6	M5×0.8	KQB2L06-M5	8	11.4	14.7	16.3	19	13.6	3.5	9
	1/8	KQB2L06-01S	10		15.9	16.4	21.2		11.4	10.2
	1/4	KQB2L06-02S	14		15.9	20.2	21.2		11.4	19.1
	3/8	KQB2L06-03S	17		15.9	21.6	22.2		11.4	31.2
ø8	1/8	KQB2L08-01S	12	13.7	18.6	18.3	22	16.1	21.6	14.8
	1/4	KQB2L08-02S	14		19.1	21.5	23.6		21.6	20.8
	3/8	KQB2L08-03S	17		19.1	22.9	24.6		21.6	32.8
ø10	1/8	KQB2L10-01S	12	16.6	20	19.7	24.9	17	21.6	20.4
	1/4	KQB2L10-02S	14		21	22.9	26.5		35.2	23.7
	3/8	KQB2L10-03S	17		21	24.3	27.5		35.2	34.5
	1/2	KQB2L10-04S	22		21	28.5	30.4		35.2	62.6
ø12	1/4	KQB2L12-02S	14	18.7	22.6	24	28.6	18.6	50.2	27.4
	3/8	KQB2L12-03S	17		23.6	25.3	29.5		50.2	34.3
	1/2	KQB2L12-04S	22		23.6	29.5	32.4		50.2	60.8
ø16	3/8	KQB2L16-03S	19	24.6	26.3	28	34.5	20.8	71	47
	1/2	KQB2L16-04S	22		27.3	31.8	37		100	62.6


※Rねじはねじ込み後の参考寸法

注1) ø16のみリリースプッシュの外径寸法です。


注2) FEPチューブ使用時の値を示します。

ø16のみナイロンチューブ使用時の値を示します。

(M5の場合)

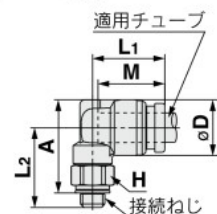

(Rの場合)

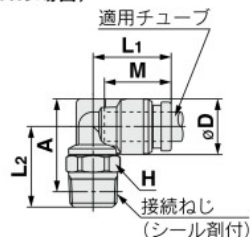

両口チーズユニオン: KQB2T



適用チューブ 外径mm	接続ねじ R, M	型式	H (六角対辺)	注1) øD	L1	L2	A*	M	注2) 有効断 面積mm ²	質量g
ø3.2	M5×0.8	KQB2T23-M5	8	8.3	13.1	14.8	16	12	3.2	8.2
	1/8	KQB2T23-01S	10		13.6	14.9	15.9		3.4	9.6
	1/4	KQB2T23-02S	14		13.6	18.7	18.1		3.4	18.4
ø4	M5×0.8	KQB2T04-M5	8	9.1	13.7	15.2	16.8	12.6	4.5	9.1
	1/8	KQB2T04-01S	10		14.4	15.3	16.7		6	10.6
	1/4	KQB2T04-02S	14		14.4	19.1	18.9		6	19.4
ø6	M5×0.8	KQB2T06-M5	8	11.4	14.7	16.3	19	13.6	4.5	12.1
	1/8	KQB2T06-01S	10		15.9	16.4	21.2		13.9	13.6
	1/4	KQB2T06-02S	14		15.9	20.2	21.2		13.9	22.5
	3/8	KQB2T06-03S	17		15.9	21.6	22.2		13.9	35
ø8	1/8	KQB2T08-01S	12	13.7	18.6	18.3	22	16.1	26.3	20
	1/4	KQB2T08-02S	14		19.1	21.5	23.6		26.3	26.1
	3/8	KQB2T08-03S	17		19.1	22.9	24.6		26.3	38
ø10	1/8	KQB2T10-01S	12	16.6	20	19.7	24.9	17	40.8	28.6
	1/4	KQB2T10-02S	14		21	22.9	26.5		40.8	31.5
	3/8	KQB2T10-03S	17		21	24.3	27.5		40.8	42.4
	1/2	KQB2T10-04S	22		21	28.5	30.4		40.8	70.4
ø12	1/4	KQB2T12-02S	14	18.7	22.6	24	28.6	18.6	57.2	38.1
	3/8	KQB2T12-03S	17		23.6	25.3	29.5		57.2	39.7
	1/2	KQB2T12-04S	22		23.6	29.5	32.4		57.2	70.8
ø16	3/8	KQB2T16-03S	19	24.6	26.3	28	34.5	20.8	71	64.4
	1/2	KQB2T16-04S	22		27.3	31.8	37		100	79


※Rねじはねじ込み後の参考寸法

注1) ø16のみリリースプッシュの外径寸法です。

注2) FEPチューブ使用時の値を示します。

ø16のみナイロンチューブ使用時の値を示します。

(M5の場合)

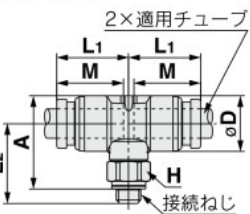

(Rの場合)

