



メスユニオン:KGF

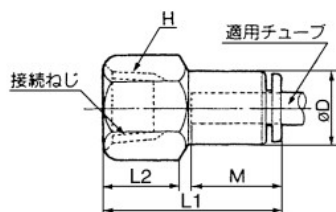


適用チューブ 外径mm	接続ねじ Rcねじ	型式	H (六角 対辺)	øD	L1	L2	M	有効断面積 mm ²		質量 g
								ナイロン	ウレタン	
4	1/8	KGF04-01	14	10	27	11	16	5.6	4	15
	1/4	KGF04-02	17		31	14				23
6	1/8	KGF06-01	14	12	27.5	11	17	13.1	10.4	15
	1/4	KGF06-02	17		31	13				22
	3/8	KGF06-03	19		33.5	15				25
8	1/8	KGF08-01	14	14	29	11	18.5	26.1	18.0	17
	1/4	KGF08-02	17		32.5	13				24
	3/8	KGF08-03	19		33.5	14				24
10	1/4	KGF10-02	17	17	34.5	14	21	41.5	29.5	27
	3/8	KGF10-03	19		36.5	15				30
12	1/4	KGF12-02	19	19	35	14	22	58.3	46.1	36
	3/8	KGF12-03	19		37					31
	1/2	KGF12-04	24		41	18				52

ストレート:KGH

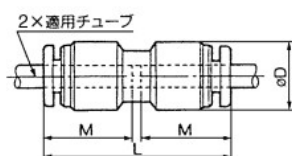

適用チューブ外径 mm	型式	øD	L	M	有効断面積 mm ²		質量 g
					ナイロン	ウレタン	
4	KGH04-00	10.4	32.5	16	5.6	4	3
6	KGH06-00	12.8	34.5	17	13.1	10.4	4
8	KGH08-00	15.2	38.5	18.5	26.1	18.0	6
10	KGH10-00	18.5	42.5	21	41.5	29.5	11
12	KGH12-00	20.9	44.5	22	58.3	46.1	14

異径ストレート:KGH

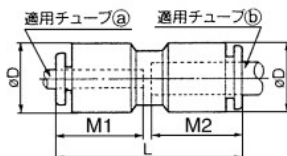


適用チューブ外径 mm		型式	øD	L	M1	M2	有効断面積 mm ²		質量 g
(a)	(b)						ナイロン	ウレタン	
4	6	KGH04-06	12.8	34.5	16	17	5.6	4	5
6	8	KGH06-08	15.2	38.5	17	18.5	13.1	10.4	6
8	10	KGH08-10	18.5	42	18.5	21	26.1	18.0	11
10	12	KGH10-12	20.9	44.5	21	22	41.5	29.5	14


エルボユニオン:KGL



〈M5の場合〉

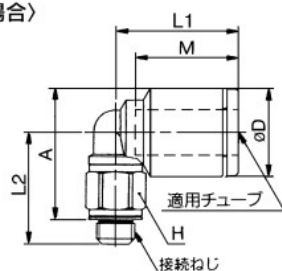

〈Rの場合〉

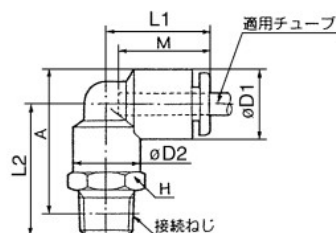

適用チューブ 外径mm	接続ねじ M R	型式	H (六角 対辺)	øD1	øD2	L1	L2	※A	M	注1)有効断面積 mm ²		質量 g
										ナイロン	ウレタン	
4	M5×0.8	KGL04-M5	7	9.3	—	15.6	13.7	15.3	12.7	3.5	3.5	2.7
	1/8	KGL04-01	10	10.4	10	18	21.1	23	16	4.2	4.2	10
	1/4	KGL04-02	14				25.5	25				19
6	M5×0.8	KGL06-M5	7	11.6	—	16.1	14.7	17.4	13.5	3.5	3.5	3.1
	1/8	KGL06-01	10	12.8	10	20	22.1	25.5	17	11.4	9.0	12
	1/4	KGL06-02	14				26.5	27.5				10
	3/8	KGL06-03	17				27.9	29				33
8	1/8	KGL08-01	12	15.2	12	23	23.6	28	18.5	21.6	14.9	13
	1/4	KGL08-02	14				28	30				21
	3/8	KGL08-03	17				29.4	31.5				35
10	1/8	KGL10-01	17	18.5	17	26.5	26.1	32	21	35.2	25.0	25
	1/4	KGL10-02					29.5	33				26
	3/8	KGL10-03					30.9	34.5				36
	1/2	KGL10-04	22				35.1	37				63
12	1/4	KGL12-02	17	20.9	17	28.5	30.5	35.5	22	50.2	39.7	28
	3/8	KGL12-03					31.9	37				38
	1/2	KGL12-04	22				36.1	39.5				65
16	3/8	KGL16-03	22	26.5	20.9	34	36.9	44.5	24	71	(71)	101
	1/2	KGL16-04					40.1	46				105

※Rねじのねじ込み後の参考寸法
注1) () 内寸法はソフトナイロンの場合