


外形寸法図

ハーフユニオン: **KFG2H**



適用チューブ サイズmm		接続 ねじ R	型式	六角対辺		L	M	ød	A*	有効 断面積 mm ²	質量g
外径	内径			H ₁	H ₂						
ø4	ø2.5	1/8	KFG2H0425-01	10	8	19.4	5	1.8	16.3	1.6	8
		1/4	KFG2H0425-02	14		23.8					
ø4	ø3	1/8	KFG2H0403-01	10	8	19.4	5	2.3	16.3	2.6	8
		1/4	KFG2H0403-02	14		23.8					
ø6	ø4	1/8	KFG2H0604-01	10	10	20.9	5.8	3.3	17.8	6	10
		1/4	KFG2H0604-02	14		25.3					
ø8	ø6	1/8	KFG2H0806-01	14	14	23.3	6.6	5.3	20.2	17	18
		1/4	KFG2H0806-02			26.7					
		3/8	KFG2H0806-03			28.1					
ø10	ø7.5	1/4	KFG2H1075-02	17	17	29.7	7.6	6.8	25	30	34
		3/8	KFG2H1075-03			30.1					
		1/2	KFG2H1075-04			33.5					
ø10	ø8	1/4	KFG2H1008-02	17	17	29.7	7.6	7.3	25	35	33
		3/8	KFG2H1008-03			30.1					
		1/2	KFG2H1008-04			33.5					
ø12	ø9	1/4	KFG2H1209-02	17	17	31.3	8.5	8	26.6	45	33
		3/8	KFG2H1209-03			31.7					
		1/2	KFG2H1209-04			35.1					
ø12	ø10	1/4	KFG2H1210-02	17	17	31.3	8.5	9	26.6	57	30
		3/8	KFG2H1210-03			31.7					
		1/2	KFG2H1210-04			35.1					
ø16	ø13	3/8	KFG2H1613-03	22	22	33.1	9.3	12	28	101	51
		1/2	KFG2H1613-04			36.3					

※Rねじのねじ込み後の参考寸法

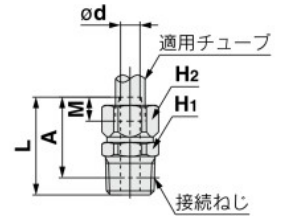


エルボユニオン: **KFG2L**



適用チューブ サイズmm		接続 ねじ R	型式	二面幅		六角対辺		M	ød	A*	有効 断面積 mm ²	質量g
外径	内径			H ₁	H ₂	L ₁	L ₂					
ø4	ø2.5	1/8	KFG2L0425-01	10	8	13.5	12.5	5	1.8	13.8	1.6	10
		1/4	KFG2L0425-02				15.9					
ø4	ø3	1/8	KFG2L0403-01	10	8	13.5	12.5	5	2.3	13.8	2.6	10
		1/4	KFG2L0403-02				15.9					
ø6	ø4	1/8	KFG2L0604-01	10	10	15	13.6	5.8	3.3	16	6	12
		1/4	KFG2L0604-02				17					
ø8	ø6	1/8	KFG2L0806-01	12	14	17.4	15.8	6.6	5.3	20.4	12	20
		1/4	KFG2L0806-02				19.2					
		3/8	KFG2L0806-03				19.6					
ø10	ø7.5	1/4	KFG2L1075-02	15	17	20.9	20.9	7.6	6.8	25.6	23	38
		3/8	KFG2L1075-03				21.3					
		1/2	KFG2L1075-04				24.5					
ø10	ø8	1/4	KFG2L1008-02	15	17	20.9	20.9	7.6	7.3	25.6	27	37
		3/8	KFG2L1008-03				21.3					
		1/2	KFG2L1008-04				24.5					
ø12	ø9	1/4	KFG2L1209-02	16	17	23.5	20.9	8.5	8	25.6	27	41
		3/8	KFG2L1209-03				21.3					
		1/2	KFG2L1209-04				24.5					
ø12	ø10	1/4	KFG2L1210-02	16	17	23.5	20.9	8.5	9	25.6	34	42
		3/8	KFG2L1210-03				21.3					
		1/2	KFG2L1210-04				24.5					
ø16	ø13	3/8	KFG2L1613-03	21	22	26.2	24	9.3	12	31	79	72
		1/2	KFG2L1613-04				27.2					

※Rねじのねじ込み後の参考寸法

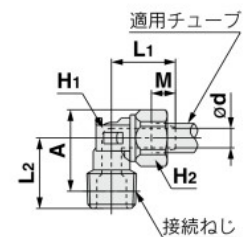

KQ2

KQB2

KS
KX

KM

KF

M

H/DL
L/LL

KC

KK

KK130

DM

KDM

KB

KR

KA

KQG2

KQ2-G

KG

KFG2

MS

KF□
KQ□

KQ
X1744

KKA

KP

LQ

MQR

T

IDK