


KPQ/KPG Series

外形寸法図

エルボ: KPQL, KPG




適用チューブ外径 mm	型式		øD	L	Q	M	有効断面積 mm ²		質量 g
							TPH	TPS	
4	KPQL04-00	KPGL04-00	10.4	19.7	4.5	17	3.5	3.5	3
6	KPQL06-00	KPGL06-00	12.8	21.8	5.3	18.5	9	9	7
8	KPQL08-00	KPGL08-00	15.2	25.3	6	20.5	22	15	11
10	KPQL10-00	KPGL10-00	18.5	28.4	6.8	23	35	25	16
12	KPQL12-00	KPGL12-00	20.9	30.4	7.5	24	50	40	20

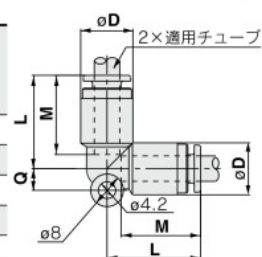

チーズ: KPQT, KPGT




適用チューブ外径 mm	型式		øD	L	Q	M	有効断面積 mm ²		質量 g
							TPH	TPS	
4	KPQT04-00	KPGT04-00	10.4	19.7	4.5	17	4	4	7
6	KPQT06-00	KPGT06-00	12.8	21.8	5.3	18.5	10	10	9
8	KPQT08-00	KPGT08-00	15.2	25.3	6	20.5	26	18	16
10	KPQT10-00	KPGT10-00	18.5	28.4	6.8	23	41	29	25
12	KPQT12-00	KPGT12-00	20.9	30.4	7.5	24	58	46	29

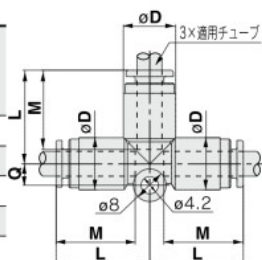

ユニオンワイ: KPQU, KPGU




適用チューブ外径 mm	型式		øD	L1	L2	P	Q	M	有効断面積 mm ²		質量 g
									TPH	TPS	
4	KPQU04-00	KPGU04-00	10.4	36.8	19.6	10.4	9.7	17	4	4	7
6	KPQU06-00	KPGU06-00	12.8	40.1	21.8	12.8	11.7	18.5	10	10	10
8	KPQU08-00	KPGU08-00	15.2	46.7	26.5	15.2	13.7	20.5	26	18	17
10	KPQU10-00	KPGU10-00	18.5	52	29.7	18.5	16.1	23	41	29	26
12	KPQU12-00	KPGU12-00	20.9	55.2	31.9	20.9	18.1	24	58	46	32

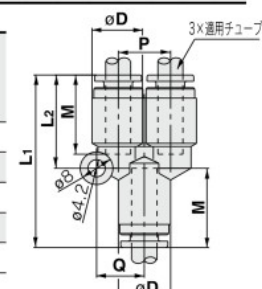

レジャーサ: KPQR, KPGR




適用チューブ外径 mm	適用管継手 サイズ ød	型式		øD	L	A	M	有効断面積 mm ²		質量 g
								TPH	TPS	
4	6	KPQR04-06	KPGR04-06	10.4	38.4	19.1	17	4	4	3
	8	KPQR04-08	KPGR04-08		40.9	19.2				4
6	8	KPQR06-08	KPGR06-08	12.8	41.5	19.8	18.5	10	10	4
	10	KPQR06-10	KPGR06-10		44	20.2				5
8	10	KPQR08-10	KPGR08-10	15.2	46	22.2	20.5	26	18	5
	12	KPQR08-12	KPGR08-12		47					6
10	12	KPQR10-12	KPGR10-12	18.5	49.5	24.7	23	41	29	9

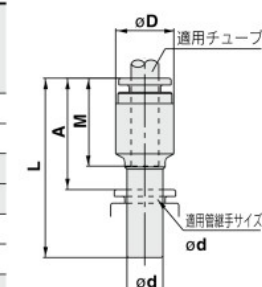

プラグ: KPP



適用管継手 サイズ ød	型式	øD	L	A	質量 g
4	KPP-04	6	32	13.8	0.4
6	KPP-06	8	35	15.7	0.7
8	KPP-08	10	39	17.3	1.1
10	KPP-10	12	43	19.2	1.7
12	KPP-12	14	45.5	20.7	2.5

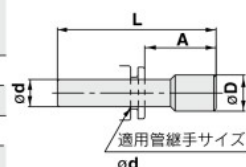

※プラグはKPQ,KPG,KPシリーズで共通です。