

KQ2 Series

適用チューブ：ミリサイズ 接続ねじ：M, R, Rc


外形寸法図

ユニバーサルメスエルボ：KQ2VF(ガスケットシール)



適用 チューブ 外径 mm	接続ねじ M	型式	H (六角 対辺)	øD1	øD2	L1	L2	L3	A	M	有効断面積mm ² ナイ ロン ウレ タン	最小 穴径	質量 g
ø4	M5×0.8	KQ2VF04-M5□	8	8.2	9.8	17.5	10.2	19.2	16.2	13.3	2.9	2.9	5.5
ø6	M5×0.8	KQ2VF06-M5□	8	10.4	9.8	18.3	10.2	19.2	16.2	13.3	3.8	3.8	5.8

□記号/A: 黄銅、N: 黄銅+無電解ニッケルめっき

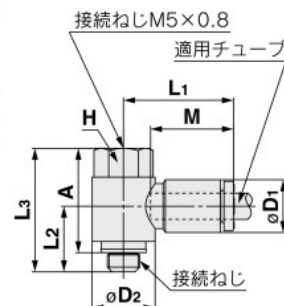

ユニバーサルメスエルボ：KQ2VF(シール剤)



適用 チューブ 外径 mm	接続ねじ R, Rc	型式	H (六角 対辺)	øD1	øD2	L1	L2	L3	A※	M	有効断面積mm ² ナイ ロン ウレ タン	最小 穴径	質量 g
ø4	1/8	KQ2VF04-01□S	14	8.2	13.4	19.3	14.4	28.5	25.4	13.3	2.9	2.9	17.3
	1/8	KQ2VF06-01□S	14	10.4	13.4	20.5	14.4	28.5	25.4	13.3	7.5	5.9	17.6
ø6	1/4	KQ2VF06-02□S	17	10.4	17.6	21.2	19.4	37.9	33.2	13.3	7.5	5.9	37
	1/8	KQ2VF08-01□S	17	13.2	17.6	23.5	15.5	30	26.9	14.2	16	11.2	27.5
ø8	1/4	KQ2VF08-02□S	17	13.2	17.6	23.5	18.9	37.9	33.2	14.2	16	11.2	38.1
	3/8	KQ2VF08-03□S	22	13.2	25.2	24.9	24	44	38.9	14.2	16	11.2	64.5
ø10	1/4	KQ2VF10-02□S	19	15.9	20.6	25.9	20.4	40.3	35.6	15.6	27	20.3	46.4
	3/8	KQ2VF10-03□S	22	15.9	25.2	26.3	23.2	44	38.9	15.6	27	20.3	65.3
ø12	3/8	KQ2VF12-03□S	22	18.5	25.2	28.5	22.5	44	38.9	17	39	30.8	67.2
	1/2	KQ2VF12-04□S	24	18.5	27	29.9	24.4	48.9	42.5	17	39	30.8	95.6

□記号/A: 黄銅、N: 黄銅+無電解ニッケルめっき

※Rねじのねじ込み後の参考寸法

