


N09

由任彎頭 Union Elbow

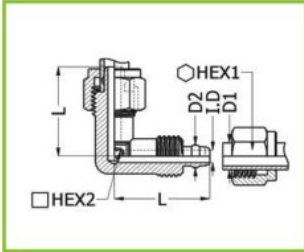


產品編號	適用管徑 D1	直牙	D2	L	HEX1	HEX2	I.D
PART NO.	TubeSize D1	Thread					
N09-L04	4	M7×1.0	3.7	20.2	9	8.5	1.8
N09-L06	6	M10-24	5.6	21.5	12	8.5	3
N09-L25	8	7/16-24	6.9	23	14	8.5	4.5
N09-L10	10	1/2-24	8.3	24	15	8.5	5.2
N09-L12	12	M17-24	10.3	29.5	19	12	7

產品編號	適用管徑 D1	直牙	D2	L	HEX1	HEX2	I.D
PART NO.	TubeSize D1	Thread					
N09-L2	1/4	M10-24	5.6	21.5	12	8.5	3
N09-L25	5/16	7/16-24	6.9	23	14	8.5	4.5
N09-L3	3/8	1/2-24	8.3	24	15	8.5	5.2
N09-L4	1/2	M17-24	11	29.5	19	12	8

N10

夾壁式由任接頭 Bulkhead Union

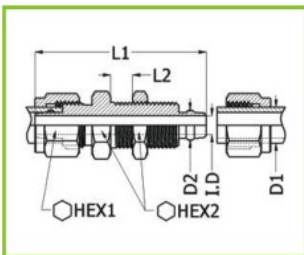

產品編號	適用管徑 D1	直牙	D2	L1	L2 最小 L2 min	L2 最大 L2 max	HEX1	HEX2	I.D
PART NO.	TubeSize D1	Thread							
N10-C06	6	M10-24	5.6	43.5	2	7	12	16	3
N10-C25	8	7/16-24	6.9	44.5	2	6	14	16	4.5
N10-C10	10	1/2-24	8.3	46.5	2	6.5	15	16	5.2

產品編號	適用管徑 D1	直牙	D2	L1	L2 最小 L2 min	L2 最大 L2 max	HEX1	HEX2	I.D
PART NO.	TubeSize D1	Thread							
N10-C2	1/4	M10-24	5.6	43.5	2	7	12	16	3
N10-C25	5/16	7/16-24	6.9	44.5	2	6	14	16	4.5
N10-C3	3/8	1/2-24	8.3	46.5	2	6.5	15	16	5.2

