
 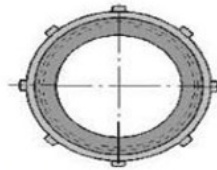


絶縁ブッシング 鋳鉄製

薄鋼用 電気亜鉛めっき
厚鋼用 溶融亜鉛めっき



薄鋼用 電気亜鉛めっき

絶縁部 オレンジ

品番	サイズ	d	H	重量g	梱包数	
					袋	大箱
IB19	19	14	9	20	50	500
IB25	25	19	10	25		400
IB31	31	24	12	40	50	250
IB39	39	30	13	50		200
IB51	51	42	15	100	30	90
IB63	63	53	17	125		80
IB75	75	62	20	205		50

HDZ


厚鋼用 溶融亜鉛めっき付着量300g/m²以上

絶縁部 グリーン

品番	サイズ	d	H	重量g	梱包数	
					袋	大箱
IBZ16	16	14	9	15	50	500
IBZ22	22	19	10	35		400
IBZ28	28	24	12	45	50	250
IBZ36	36	32	13	55		200
IBZ42	42	36	15	70	36	108
IBZ54	54	48	16	90	15	90
IBZ70	70	62	18	170		60
IBZ82	82	74	20	245		32
IBZ92	92	87	22	360		35
IBZ104	104	99	24	555		16

サドル 鋼板製

電気亜鉛めっき

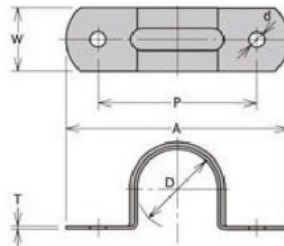

薄鋼用

品番	サイズ	A	P	W	D	d	T	重量g	梱包数	
									袋	大箱
S15	15	50	35	15	16.0	5.0	0.8	6.0	100	1500
S19	19	60	40		19.5			7.0		1000
S25	25	70	50	20	25.5	5.5	1.2	12.7	50	500
S31	31	85	60	32.0	27.8			300		
S39	39	95	70	25	38.5	6.5	1.6	32.5	25	200
S51	51	110	85		51.0			46.0		150
S63	63	130	105	30	64.0	6.5	85.4	62.0	100	
S75	75	150	120		76.5			85.4		

厚鋼用

品番	サイズ	A	P	W	D	d	T	重量g	梱包数	
									袋	大箱
S16	16	65	45	20	21.5	5.0	0.8	10	100	500
S22	22	75	55		27.0			14		50
S28	28	90	65	25	33.5	5.5	1.2	28	25	250
S36	36	100	75		42.0			35		200
S42	42	110	85	30	48.0	6.5	1.6	50	10	150
S54	54	125	100		60.0			68		
S70	70	150	120	35	75.5	6.5	1.6	91	100	
S82	82	165	135		88.5			117		
S92	92	180	150	40	102.0	6.5	1.6	132	10	
S104	104	200	170		115.0			140		80