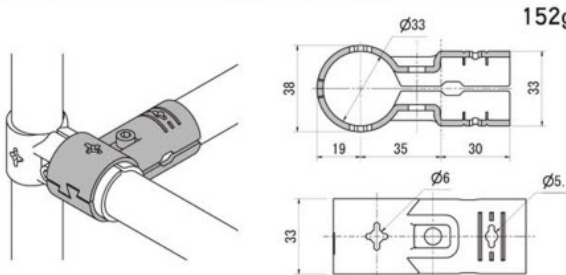
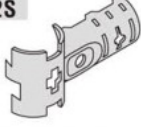
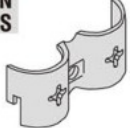
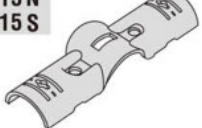


標準	NSJ-17	(NS-17×2個 ボルト・ナット×1組)
静電タイプ	NSJ-17 N	(NS-17N×2個 ボルト・ナット×1組)
3価タイプ	NSJ-17 S	(NS-17S×2個 ボルト・ナット×1組)
概略図面		

■メタルジョイント 構成部品

※品番の末尾Nはニッケルメッキタイプ、Sは3価クロメートメッキタイプです。

NS-1 NS-1N NS-1S  69g	NS-2 NS-2N NS-2S  95g	NS-3 NS-3N NS-3S  121g	NS-4 NS-4N NS-4S  106g
NS-5 NS-5N NS-5S  47g	NS-6 NS-6N NS-6S  59g	NS-7 NS-7N NS-7S  47g	NS-8 NS-8N NS-8S  91g
NS-9 NS-9N NS-9S  89g メネジ付き	NS-10 NS-10N  129g	NS-11 NS-11N  132g ナット付き	NS-12 NS-12N NS-12S  66g
NS-13 NS-13N NS-13S  52g	NS-14 NS-14N  65g	NS-15 NS-15N NS-15S  107g	NS-16 NS-16N NS-16S  105g
NS-17 NS-17N NS-17S  71g $\phi 33\text{mm}$	(ボルト) SJ-B (3価黒クロメート処理) SJ-BN (3価クロメート処理)  7.2g M6×25mm	(ナット) SJ-N (3価黒クロメート処理) SJ-NN (3価クロメート処理)  2.4g M6	
PJ-605  45mm NSJ-8, NSJ-8N, NSJ-8S, JB-152, JB-164, JB-166用 PE樹脂製(ホワイト)	PJ-608N  37mm NSJ-10, NSJ-10N, NSJ-10S, NSJ-15, NSJ-15N, NSJ-15S用 PE樹脂製(ホワイト)	PJ-609  77mm 37mm NSJ-10, NSJ-10N, NSJ-10S, NSJ-15, NSJ-15N, NSJ-15S用 PE樹脂製(ホワイト)	