


バルクヘッドメールコネクター

BULKHEAD MALE CONNECTOR (SBHW Type)

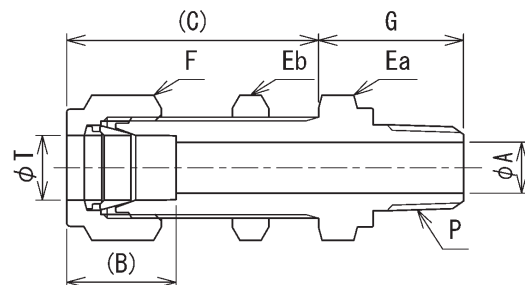

UNIT : mm

型 番	チューブ 外径	管用テーパ おねじ	最小穴径	差込深さ	組込長さ	六角対辺				パネル取付 穴径	最大取付幅
TYPE NO.	TUBE O.D.	PIPE THREAD	MIN. BORE	DEPTH	APPROX	WIDTH ACROSS HEX				PANEL HOLE DRILL	MAX. PANEL MOUNT THICKNESS
	T	P	A	B	C	Ea	Eb	F	G		

[ミリサイズチューブ用]

SBHW- 3M- 2R	3	R1/8	2.4	13	31.2	14	14	12	15	8.3	10.3
SBHW- 4M- 2R	4	R1/8	3	13.7	32	14	14	12	15.7	9.9	11
SBHW- 6M- 2R	6	R1/8	4.5	15.6	34.6	15.8	15.8	14	19.5	11.5	10.5
SBHW- 6M- 4R	6	R1/4	4.5	15.6	34.6	15.8	15.8	14	22	11.5	10.5
SBHW- 6M- 6R	6	R3/8	4.5	15.6	34.6	17.4	15.8	14	22.5	11.5	10.5
SBHW- 6M- 8R	6	R1/2	4.5	15.6	34.6	22	15.8	14	27.5	11.5	10.5
SBHW- 8M- 2R	8	R1/8	6	16.4	36.7	17.4	17.4	15.8	19.5	13	11.5
SBHW- 8M- 4R	8	R1/4	6	16.4	36.7	17.4	17.4	15.8	22	13	11.5
SBHW- 8M- 6R	8	R3/8	6	16.4	36.7	17.4	17.4	15.8	22.5	13	11.5
SBHW- 8M- 8R	8	R1/2	6	16.4	36.7	22	17.4	15.8	27.5	13	11.5
SBHW-10M- 4R	10	R1/4	8	17.2	37.7	22	22	19	22	16.3	11.5
SBHW-10M- 6R	10	R3/8	8	17.2	37.7	22	22	19	22.5	16.3	11.5
SBHW-10M- 8R	10	R1/2	8	17.2	37.7	22	22	19	27.5	16.3	11.5
SBHW-12M- 4R	12	R1/4	7.5	23.1	41.4	24	24	22	22.5	19.5	12.5
SBHW-12M- 6R	12	R3/8	10	23.1	41.4	24	24	22	23	19.5	12.5
SBHW-12M- 8R	12	R1/2	10	23.1	41.4	24	24	22	27.5	19.5	12.5

[インチサイズチューブ用] チューブ外径の () 内はインチ表示

SBHW- 2C- 2R	3.17(1/8")	R1/8	2.4	13	31.2	14	14	12	15	8.3	10.3
SBHW- 3C- 2R	4.76(3/16")	R1/8	3.2	13.7	32	14	14	14	15.7	9.9	11
SBHW- 4C- 2R	6.35(1/4")	R1/8	4.8	15.6	34.6	15.8	15.8	14	19.5	11.5	10.5
SBHW- 4C- 4R	6.35(1/4")	R1/4	4.8	15.6	34.6	15.8	15.8	14	22	11.5	10.5
SBHW- 4C- 6R	6.35(1/4")	R3/8	4.8	15.6	34.6	17.4	15.8	14	22.5	11.5	10.5
SBHW- 4C- 8R	6.35(1/4")	R1/2	4.8	15.6	34.6	22	15.8	14	27.5	11.5	10.5
SBHW- 6C- 4R	9.52(3/8")	R1/4	7.5	17.2	37.7	19	19	17.4	22	14.7	11.5
SBHW- 6C- 6R	9.52(3/8")	R3/8	7.5	17.2	37.7	19	19	17.4	22.5	14.7	11.5
SBHW- 6C- 8R	9.52(3/8")	R1/2	7.5	17.2	37.7	22	19	17.4	27.5	14.7	11.5
SBHW- 8C- 4R	12.7(1/2")	R1/4	7.5	23.1	41.4	24	24	22	22.5	19.5	12.5
SBHW- 8C- 6R	12.7(1/2")	R3/8	10.4	23.1	41.4	24	24	22	23	19.5	12.5
SBHW- 8C- 8R	12.7(1/2")	R1/2	10.4	23.1	41.4	24	24	22	27.5	19.5	12.5

◎A寸法はチューブ側とねじ側 (P側) で異なる場合があります。A寸法は最小穴寸法を表しています。

◎製品改良のため、形状及び寸法は、予告無く変更することがありますので、あらかじめご了承ください。

◎NPT (アメリカ管用テーパおねじ) をご注文の場合は、型番末尾の "R" を "N" に変えてご注文下さい。

例: SBHW-6M-4R ⇒ SBHW-6M-4N