


エルボータイプアダプター

- Material : Plated steel
- 材質 : SS(三価クロメートメッキ)


UL-45 (06)

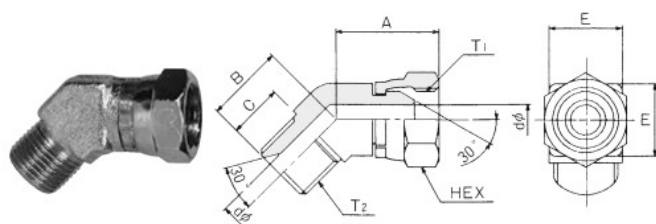

*印及びSUSは受注生産

呼び径	ねじT ₁	ねじT ₂	Amm	Bmm	Cmm	dφmm	Emm	HEXmm
6	G 1/4	R 1/4	24	19	13	5.5	17	19
9	G 3/8	R 3/8	27	22	15	7.0	19	22
12	G 1/2	R 1/2	34	26	18	10.0	24	27
19	G 3/4	R 3/4	41	30	20	16.0	30	36
25	G 1	R 1	46	34	22	22.0	36	41
* 32	G 1 1/4	R 1 1/4	53	38	24	28.0	45	50
* 38	G 1 1/2	R 1 1/2	58	40	24	34.0	50	60
* 50	G 2	R 2	64	48	28	45.0	63	70

UL-45 (0609)

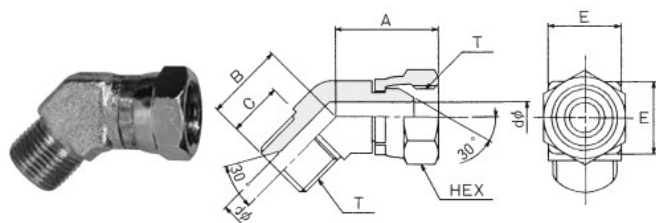


*印及びSUSは受注生産

呼び径	ねじT	Amm	Bmm	Cmm	dφmm	Emm	HEXmm
6	G 1/4	24	19	13	5.5	17	19
9	G 3/8	27	22	15	7.0	19	22
12	G 1/2	34	26	18	10.0	24	27
19	G 3/4	41	30	20	16.0	30	36
25	G 1	46	34	22	22.0	36	41
* 32	G 1 1/4	53	38	24	28.0	45	50
* 38	G 1 1/2	58	40	24	34.0	50	60
* 50	G 2	64	48	28	45.0	63	70

接続口金具 : SR-02・SR-05

UL-45 (0613)

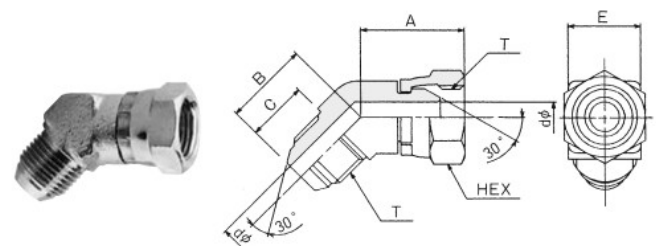

*印及びSUSは受注生産

呼び径	ねじT	Amm	Bmm	Cmm	dφmm	Emm	HEXmm
6	G 1/4	24	22.0	16.0	5.5	17	19
9	G 3/8	27	24.5	17.5	7.0	19	22
12	G 1/2	34	28.0	20.0	10.0	24	27
19	G 3/4	41	31.5	21.5	16.0	30	36
25	G 1	46	34.5	22.5	22.0	36	41
* 32	G 1 1/4	53	41.0	27.0	28.0	45	50
* 38	G 1 1/2	58	43.0	27.0	34.0	50	60
* 50	G 2	64	50.0	30.0	45.0	63	70

接続口金具 : SR-02・SR-04