


### 1.3.ステンレス鋼鍛鋼製差込溶接型JIS B2316 SCH80 SCH160

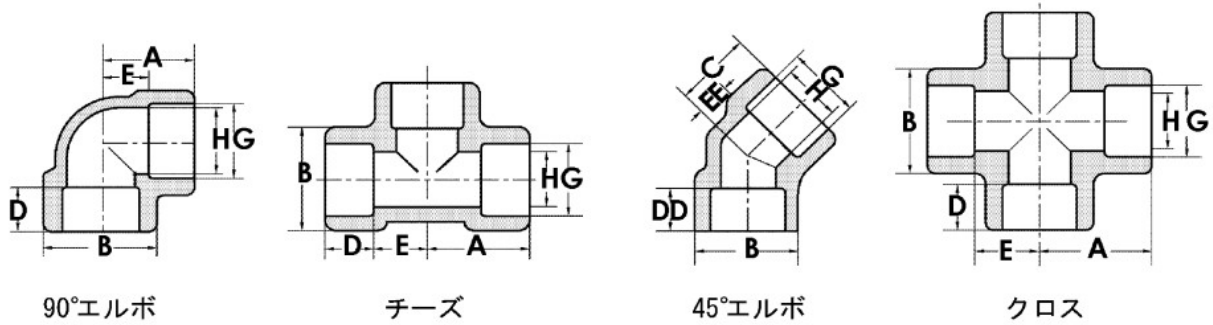

品番	90°エルボ	チーズ	45°エルボ	クロス
SCH 80	S301S	S303S	S302S	S305S
SCH 160	S601S	S603S	S602S	S605S

単位 mm

径の呼び	差し込み部の内径 G	穴径 H	差し込み部の深さ D DD		SCH 80										
					90°エルボ			チーズ		45°エルボ			クロス		
					A	B	E	C	B	EE	A	B	E		
1/8	11.0	7.1	10	10	21.1	23	11.1	17.9	23	7.9	21.1	23	11.1		
1/4	14.3	9.4	10	10	21.1	23	11.1	17.9	23	7.9	21.1	23	11.1		
3/8	17.8	12.7	12	11	25.5	27	13.5	18.9	27	7.9	25.5	27	13.5		
1/2	22.2	16.1	12	11	27.9	34	15.9	22.1	34	11.1	27.9	34	15.9		
3/4	27.7	21.4	14	13	33.1	39	19.1	25.7	39	12.7	33.1	39	19.1		
1	34.5	27.2	16	14	38.2	47	22.2	28.3	47	14.3	38.2	47	22.2		
1 1/4	43.2	35.5	18	15	45.0	56	27.0	33.5	56	17.5	45.0	56	27.0		
1 1/2	49.1	41.2	19	16	50.8	63	31.8	35.6	63	20.6	50.8	63	31.8		
2	61.1	52.7	22	17	60.1	76	38.1	42.4	76	25.4	60.1	76	38.1		
2 1/2	77.1	65.9	26	24	67.3	96	41.3	52.6	96	28.6	75.3	96	41.3		
3	90.0	78.1	29	32	86.2	110	57.2	63.8	110	31.8	86.2	110	57.2		
※ 4	115.4	102.3	36	35	102.7	138	66.7	76.3	138	41.3	102.7	138	66.7		

単位 mm

径の呼び	差し込み部の内径 G	穴径 H	差し込み部の深さ D DD		SCH 160										
					90°エルボ			チーズ		45°エルボ			クロス		
					A	B	E	C	B	EE	A	B	E		
※ 1/8	11.0	4.2	10	10	21.1	23	11.1	17.9	23	7.9	21.1	23	11.1		
※ 1/4	14.3	6.5	12	11	25.5	27	13.5	18.9	27	7.9	25.5	27	13.5		
※ 3/8	17.8	9.2	12	11	27.9	34	15.9	22.1	34	11.1	27.9	34	15.9		
1/2	22.2	12.3	14	13	33.1	39	19.1	25.7	39	12.7	33.1	39	19.1		
3/4	27.7	16.2	16	14	38.2	47	22.2	28.3	47	14.3	38.2	47	22.2		
1	34.5	21.2	18	15	45.0	56	27.0	33.5	56	17.5	45.0	56	27.0		
1 1/4	43.2	29.9	19	16	50.8	63	31.8	35.6	63	20.6	50.8	63	31.8		
1 1/2	49.1	34.4	22	15	60.1	76	38.1	42.4	76	25.4	60.1	76	38.1		
2	61.1	43.1	22	17	66.3	84	41.3	43.6	84	28.6	63.3	84	41.3		
2 1/2	77.1	57.3	25	21	82.2	102	57.2	52.8	102	31.8	82.2	102	57.2		
3	90.0	66.9	32	29	95.5	120	63.5	63.9	120	34.9	95.5	120	63.5		
※ 4	115.4	87.3	47	38	113.7	152	66.7	79.3	152	41.3	113.7	152	66.7		

※はJIS B2316規格に記載されていない為ANSI規格を参考にメーカー寸法で製作