



## 16.ステンレス鋼鍛鋼製捻込型・差込溶接型 SCH80 SCH160

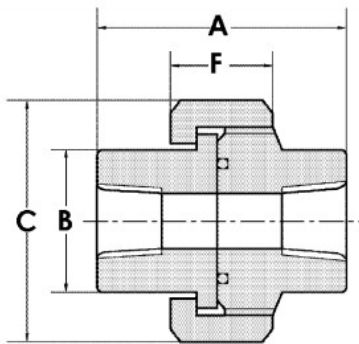

ユニオン捻込型

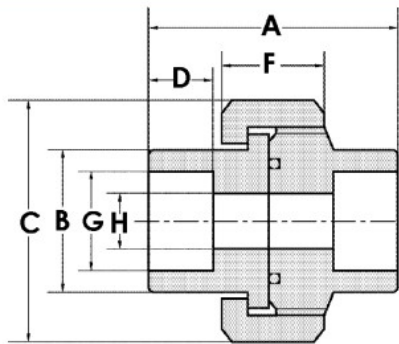

ユニオン差込溶接型

品番	ユニオン捻込型	ユニオン差込溶接型
SCH 80	S304T	S304S
SCH 160	S604T	S604S

単位 mm

径の呼び	SCH 80								リング
	G	H	D	A	B	C	F		
1/8	11.0	7.1	10	35	22	35	19	P 18	
1/4	14.3	9.4	10	35	22	35	19	P 18	
3/8	17.8	12.7	12	38	26	40	19	P 20	
1/2	22.2	16.1	12	44	32	46	20	G 25	
3/4	27.7	21.4	14	50	38	56	22	G 30	
1	34.5	27.2	16	62	45	65	25	G 40	
1 1/4	43.2	35.5	18	68	55	76	27	G 50	
1 1/2	49.1	41.2	19	76	63	87	28	G 55	
2	61.1	52.7	22	85	75	102	30	G 70	
2 1/2	77.1	65.9	26	103	93	124	37	G 85	
3	90.0	78.1	29	109	108	145	38	G 100	
4	115.4	102.3	36	130	135	180	58	G 125	

単位 mm

径の呼び	SCH160								リング
	G	H	D	A	B	C	F		
1/8	11.0	4.2	10	35	22	35	19	P 18	
1/4	14.3	6.5	12	41	26	40	19	P 20	
3/8	17.8	9.2	12	46	32	46	20	P 22	
1/2	22.2	12.3	14	50	38	56	22	G 30	
3/4	27.7	16.2	16	62	45	65	25	G 35	
1	34.5	21.2	18	68	55	76	27	G 40	
1 1/4	43.2	29.9	19	76	63	87	28	G 50	
1 1/2	49.1	34.4	22	85	75	102	30	G 60	
2	61.1	43.1	25	91	85	113	36	G 70	
2 1/2	77.1	57.3	29	105	100	131	37	G 85	
3	90.0	66.9	31	111	120	158	40	G 100	
4	115.4	87.3	48	132	150	194	60	G 125	