


RXE3000 RXH3000 (複式内管固定ネジ取付式)

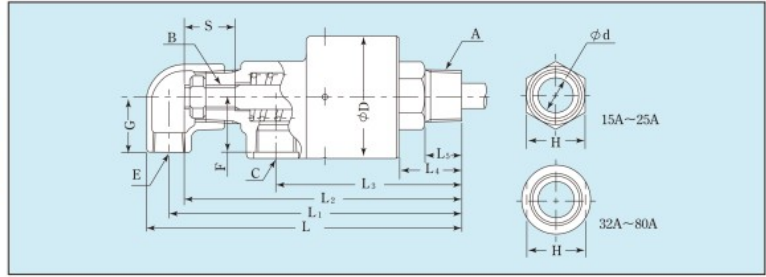

呼称寸法	型式番号	A	B	C	E	F	G	D	L	L1	L2	L3	L4	L5	d	H	内管 S
15A	3015	R1/2	G1/8	Rc1/2	Rc3/8	24	25	53	153	141	133	91	28	18	12.5	22	22
	3115	G1/2	G1/8	Rc1/2	Rc3/8	24	25	53	155	143	135	93	30	18	12.5	27	22
	3215	M22×1.5	G1/8	Rc1/2	Rc3/8	24	25	53	155	143	135	93	30	18	12.5	27	22
	3615	NPT1/2	G1/8	NPT1/2	NPT3/8	24	25	53	153	141	133	91	28	18	12.5	22	22
	3715	3/4-16UNF	G1/8	NPT1/2	NPT3/8	24	25	53	155	143	135	93	30	18	12.5	27	22
20A	3020	R3/4	G1/4	Rc1/2	Rc3/8	29	28	65	165	153	144	98	32	19	18	32	23
	3120	G3/4	G1/4	Rc1/2	Rc3/8	29	28	65	165	153	144	98	32	17	18	32	23
	3220	M26×1.5	G1/4	Rc1/2	Rc3/8	29	28	65	165	153	144	98	32	17	18	32	23
	3620	NPT3/4	G1/4	NPT1/2	NPT3/8	29	28	65	165	153	144	98	32	19	18	32	23
	3720	1-14UNS	G1/4	NPT1/2	NPT3/8	29	28	65	165	153	144	98	32	17	18	32	23
25A	3025	R1	G3/8	Rc3/4	Rc1/2	33	33	72	187	174	163	110	37	22	22	36	26
	3125	G1	G3/8	Rc3/4	Rc1/2	33	33	72	183	170	159	106	33	18	22	36	26
	3225	M35×1.5	G3/8	Rc3/4	Rc1/2	33	33	72	184	171	160	107	34	16	22	41	26
	3625	NPT1	G3/8	NPT3/4	NPT1/2	33	33	72	187	174	163	110	37	22	22	36	26
	3725	1 1/2-12UNF	G3/8	NPT3/4	NPT1/2	33	33	72	191	178	167	114	41	23	22	41	26
32A	3032	R1 1/4	G1/2	Rc1	Rc3/4	36	40	83	219	202	189	132	45	25	30	41	30
	3132	G1 1/4	G1/2	Rc1	Rc3/4	36	40	83	220	203	190	133	46	25	30	41	30
	3232	M42×1.5	G1/2	Rc1	Rc3/4	36	40	83	220	203	190	133	46	25	30	41	30
	3632	NPT1 1/4	G1/2	NPT1	NPT3/4	36	40	83	219	202	189	132	45	25	30	41	30
	3732	1 3/4-12UN	G1/2	NPT1	NPT3/4	36	40	83	220	203	190	133	46	25	30	41	30
40A	3040	R1 1/2	G3/4	Rc1	Rc3/4	39	43	89	226	209	196	137	47	25	35	46	32
	3140	G1 1/2	G3/4	Rc1	Rc3/4	39	43	89	227	210	197	138	48	25	35	46	32
	3240	M50×1.5	G3/4	Rc1	Rc3/4	39	43	89	227	210	197	138	48	25	35	46	32
	3640	NPT1 1/2	G3/4	NPT1	NPT3/4	39	43	89	226	209	196	137	47	25	35	46	32
	3740	2-12UN	G3/4	NPT1	NPT3/4	39	43	89	227	210	197	138	48	25	35	46	32
50A	3050	R2	G1	Rc1 1/2	Rc1	50	51	115	268	247	233	164	56	30	48	60	34
	3650	NPT2	G1	NPT1 1/2	NPT1	50	51	115	268	247	233	164	56	30	48	60	34
65A	3065	R2 1/2	G1 1/4	Rc2	Rc1 1/2	68	62	123	345	315	293	206	75	40	58	65	45
	3665	NPT2 1/2	G1 1/4	NPT2	NPT1 1/2	68	62	123	345	315	293	206	75	40	58	65	45
80A	3080	R3	G1 1/2	Rc2	Rc1 1/2	72	62	138	353	323	300	212	75	40	68	75	45
	3680	NPT3	G1 1/2	NPT2	NPT1 1/2	72	62	138	353	323	300	212	75	40	68	75	45

- Rネジ・Gネジ・Mネジ取付のものを示します
- NPTネジ・ユニファイ系ネジ取付のものを示します

平行ネジのロータには、銅板ガスケットが付属します。
 内管用ロックナットはジョイントに付属しています。
 内管は貴社にてご製作下さい。
 内管をご注文の場合は、寸法をご指示下さい。