

特徴 Feature

- 防水タイプ(Oリング・シートパッキン使用)
- 亜鉛合金がインサートされております。
- 耐酸・耐絶縁性を必要とする扉に最適
- 左右兼用型
- Waterproof (using O-ring and sheet packing)
- Zinc alloy is inserted.
- Suitable for doors that require acid-resistance and insulation.
- For both left-hand and right-hand use.

仕様

- 材質: ABS樹脂
- 標準色: N7(グレー) 5Y7/1(アイボリー)
- 鍵番号: 2001
- 付属品: 大ナット・ビスセット(止め金用)・キー2本

用途

- 隧道用配分電盤

納期

- 標準在庫品

備考

- ダブルOリングの完全防水タイプも製作します。
- 止め金は630~635ページの中からお選びください。
- マスターシステムの組込みが可能です。
- 常温でご使用ください。
- 施錠は錠前の構造上、鍵を押しながら回してください。
- 本製品の止め金取付け用ねじは、緩み防止のため「緩み防止剤」の塗布をお奨めします。
- 緩み防止剤など、溶剤を使用する際は十分に検証を行ってください。



Specifications

- Material: ABS resin
- Standard color: N7: Gray. 5Y7/1: Ivory
- Key No.: 2001
- Accessories: Large nut, screws for stopper plate, two keys


Specific use

Remarks


- Tunnel power/distribution boards
- Select stopper plate on page 630 to 635.
- Use this product in normal temperatures.
- Due to the structure of the lock, the key must be pushed in as it is turned in order to release the lock.
- It is recommended that thread-locking fluid be used to prevent loosening of the mounting screws for the catch.
- Be sure to test adequately when using a solvent such as thread-locking fluid.




パネル穴明け寸法
Panel drilling dimensions

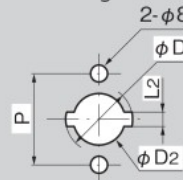

止め金
Stopper plate

 

止め金は630~635ページからお選びください。
Select stopper plate starting on page 630 to 635.

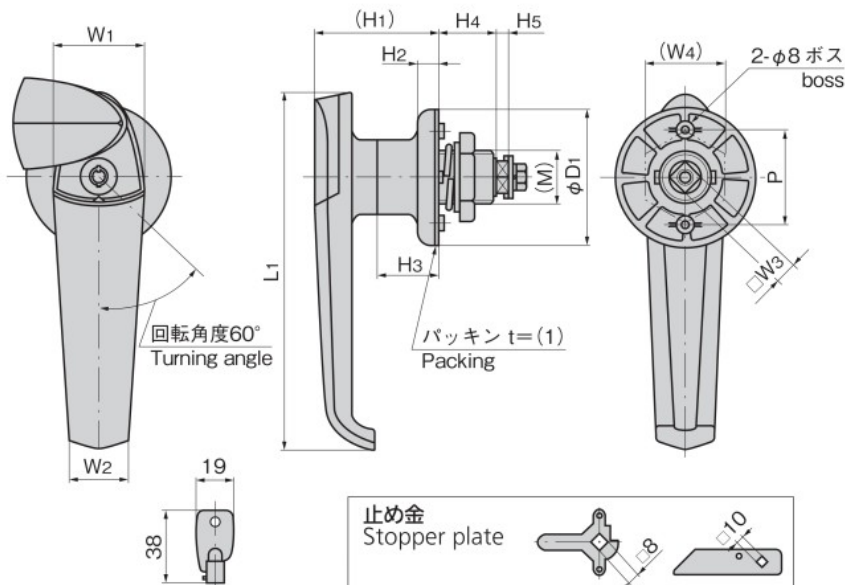

商品番号 Product No.	RoHS 10	備考 Remarks	L1	L2	W1	W2	W3	W4	H1	H2	H3	H4	H5	P	φD1	φD2	φD3	(M)	最大適用板厚 Max applicable panel thickness	製品質量(g) Mass	コード Code	単価	量販価格 数量	単価
AP-140-1-1-N7	●	鍵付き With lock																			00314			
AP-140-1-1-5Y7/1	●	鍵付き With lock	158	7	40	25	10	42	61	9	26	24	6	50	70	25	30	M24	9.5	520	01038			
AP-140-1-2-N7	●	鍵なし Without lock																			00316			
AP-140-1-2-5Y7/1	●	鍵なし Without lock																			01039			
AP-140-2-1-N7	●	鍵付き With lock																			00318			
AP-140-2-1-5Y7/1	●	鍵付き With lock	122	6	32	20	8	32	55	7	31	20	4	40	60	23	27	M22	7	330	01040			
AP-140-2-2-N7	●	鍵なし Without lock																			00320			
AP-140-2-2-5Y7/1	●	鍵なし Without lock																			01041			

●: RoHS10指令対応品 ▲: RoHS10指令に対応可能です。

※大量のご注文は更にお安くなります。