
 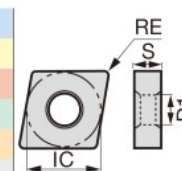
 
 
 
 



CN

[illegible]

用途	ブレーカ 記号	形 番	コーティング																サーメット		寸法 (mm)								
			T9205	T9215	T9225	T9235	T9105	T9115	T9125	T9135	T6120	T6130	AH630	AH645	T515	AH110	AH120	AH725	AH8015	GH330		NS9530			RE	IC	S	D	
仕上げ 切削		SS CNMG090404E-SS										●	●												0.4	9.525	4.76	3.8	
		CNMG090408E-SS											●	●												0.8	9.525	4.76	3.8
		CNMG120404-SS									●	●	●	●			●			●						0.4	12.7	4.76	5.1
		CNMG120408-SS									●	●	●	●			●			●						0.8	12.7	4.76	5.1
		CNMG120412-SS									●	●	●	●						●						1.2	12.7	4.76	5.1
中 切削	 	TM CNMG090304-TM		●	●			▲	▲																0.4	9.525	3.18	3.8	
		CNMG090308-TM		●	●	●		▲	▲	▲																0.8	9.525	3.18	3.8
		CNMG090404E-TM		●	●			▲	▲		●	●	●		●		●		●							0.4	9.525	4.76	3.8
		CNMG090408E-TM		●	●			▲	▲		●	●	●		●		●		●							0.8	9.525	4.76	3.8
		CNMG090412E-TM		●	●			▲	▲		●	●	●		●		●		●							1.2	9.525	4.76	3.8
		CNMG120404-TM	●	●	●	●	▲	▲	▲	▲	●	●	●	●	●		●		●							0.4	12.7	4.76	5.1
		CNMG120408-TM	●	●	●	●	▲	▲	▲	▲	●	●	●	●	●		●	●	●							0.8	12.7	4.76	5.1
		CNMG120412-TM	●	●	●	●	▲	▲	▲	▲	●	●	●	●	●	●	●		●							1.2	12.7	4.76	5.1
		CNMG120416-TM		●	●	●		▲	▲	▲	●	●	●	●	●		●		●							1.6	12.7	4.76	5.1
		CNMG160612-TM	●	●	●	●	▲	▲	▲	▲							●									1.2	15.875	6.35	6.3
		CNMG190608-TM	●	●	●	●	▲	▲	▲	▲							●									0.8	19.05	6.35	7.9
		CNMG190612-TM	●	●	●	●	▲	▲	▲	▲							●									1.2	19.05	6.35	7.9
仕上げ 中 切削	 	AM CNMG120408-AM		●	●			▲	▲																0.8	12.7	4.76	5.1	
		CNMG120412-AM		●	●			▲	▲																	1.2	12.7	4.76	5.1
		CNMG120416-AM		●	●			▲	▲																	1.6	12.7	4.76	5.1
仕上げ 中 切削	 	NM CNMG120408-NM	●	●	●	●	▲	▲	▲	▲									●						0.8	12.7	4.76	5.1	
		CNMG120412-NM		●	●	●		▲	▲	▲																1.2	12.7	4.76	5.1

●: 設定アイテム
▲: 将来廃止予定アイテム

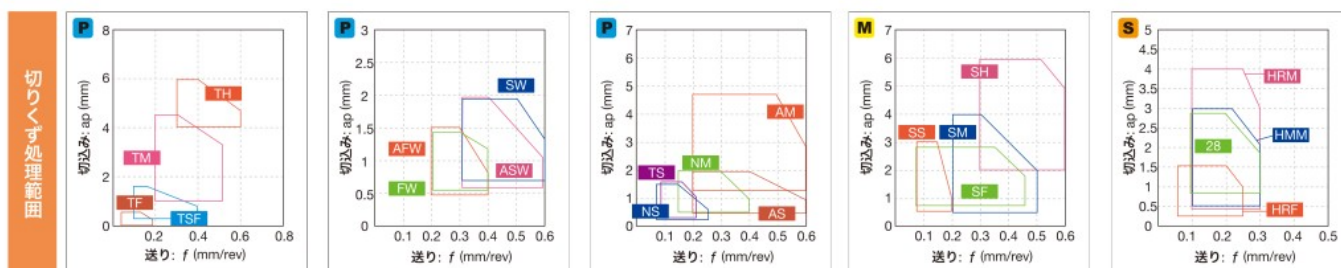

参照ページ： 外径ホルダ → **C014** - 内径ホルダ → **D019** - J series ホルダ → **G044**
 TungCap → **K008** - PINZBOHR® → **K180** - カートリッジ → **K199** -