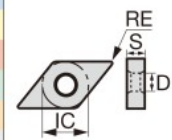
 
 
 



DN

 ひし形穴つき
55°

[illegible]

用途	ブレーカ 記号	形 番	コーティング								コーテッド サーメット		サーメット		超硬		寸法 (mm)					
			T9205	T9215	T9225	T9235	T9105	T9115	T9125	T9135	AH120	GH110	GT9530	AT9530	GT720	NS9530	NS520	TH10	RE	IC	S	D1
精密仕上げ切削	TF	DNMG150404-TF													●		●		0.4	12.7	4.76	5.16
		DNMG150408-TF													●				0.8	12.7	4.76	5.16
																						
																						
	01	DNGG110402-01													●				0.2	9.525	4.76	3.81
		DNGG110404-01													●	●			0.4	9.525	4.76	3.81
仕上げ切削		DNGG110408-01											●	●					0.8	9.525	4.76	3.81
		DNGG150402-01												●	●		●	0.2	12.7	4.76	5.16	
		DNGG150404-01												●	●		●	0.4	12.7	4.76	5.16	
		DNGG150408-01												●	●		●	0.8	12.7	4.76	5.16	
仕上げ切削	TSF	DNMG110404E-TSF		●	●			▲	▲			●	●		●				0.4	9.525	4.76	3.81
		DNMG110408E-TSF		●	●			▲	▲			●	●		●				0.8	9.525	4.76	3.81
		DNMG110412E-TSF		●	●			▲	▲			●	●		●				1.2	9.525	4.76	3.81
		DNMG150404-TSF	●	●	●	●	▲	▲	▲	▲	●		●	●	●				0.4	12.7	4.76	5.16
		DNMG150408-TSF	●	●	●	●	▲	▲	▲	▲	●		●	●	●				0.8	12.7	4.76	5.16
		DNMG150412-TSF	●	●	●	●	▲	▲	▲	▲	●								1.2	12.7	4.76	5.16
		DNMG150604-TSF		●	●			▲	▲			●	●		●				0.4	12.7	6.35	5.16
		DNMG150608-TSF	●	●	●	●	▲	▲	▲	▲		●	●		●				0.8	12.7	6.35	5.16
		DNMG150612-TSF	●	●	●	●	▲	▲	▲	▲									1.2	12.7	6.35	5.16
(ワイパー) 仕上げ切削	FW	DNMG110404E-FW		●				▲											0.4	9.525	4.76	3.81
		DNMG110408E-FW		●				▲											0.8	9.525	4.76	3.81
		DNMG150404-FW		●				▲											0.4	12.7	4.76	5.16
		DNMG150408-FW		●				▲											0.8	12.7	4.76	5.16
		DNMG150604-FW		●				▲											0.4	12.7	6.35	5.16
		DNMG150608-FW		●				▲											0.8	12.7	6.35	5.16
	※ワイパー仕様																					

●：設定アイテム
▲：将来廃止予定アイテム

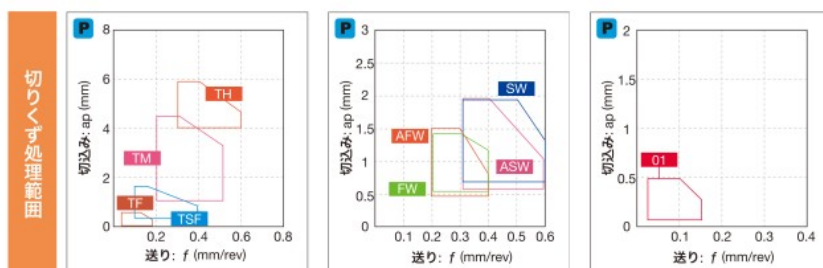

参照ページ： 外径ホルダ → **C035 -** 内径ホルダ → **D050 -**
J series ホルダ → **G046** TungCap → **C043, K012 -**