


# インサート ネガティブタイプ

- : 連続加工
- : 軽断続加工
- ※ : 強断続加工

## DN

ひし形穴つき  
55°

	P 鋼	M ステンレス	K 鋳鉄	N 非鉄金属	S 難削材	H 高硬度材	T9205	T9215	T9225	T9235	T9105	T9115	T9125	T9135	T6120	T6130	AH630	AH645	AH110	AH120	GH330	GT9530	コーテッド サーメット	サーメット	超硬	RE	IC	S	D1		
●	●	●	●				●	○	○	○	○	○	○	○						○	○				●						
○		○															○	○	○	○	○	○									
※																															
																											○	○	○	○	

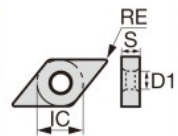

用途	ブレード 記号	形番	コーティング																			GT9530	コーテッド サーメット	NS9530	サーメット	超硬	寸法 (mm)										
			T9205	T9215	T9225	T9235	T9105	T9115	T9125	T9135	T6120	T6130	AH630	AH645	AH110	AH120	GH330	RE	IC	S	D1																
仕上げ 切削		<b>SS</b> DNMG110404E-SS															●	●									●					0.4	9.525	4.76	3.81		
		DNMG110408E-SS																●	●														0.8	9.525	4.76	3.81	
		DNMG150404-SS													●	●	●	●					●										0.4	12.7	4.76	5.16	
		DNMG150408-SS													●	●	●	●					●			●							0.8	12.7	4.76	5.16	
		DNMG150412-SS													●	●	●	●															1.2	12.7	4.76	5.16	
		DNMG150604-SS													●	●	●	●					●	●									0.4	12.7	6.35	5.16	
		DNMG150608-SS													●	●	●	●					●	●									0.8	12.7	6.35	5.16	
		DNMG150612-SS													●	●	●	●															1.2	12.7	6.35	5.16	
中 切削	 0.2	<b>TM</b> DNMG110404E-TM	●	●								▲	▲																				0.4	9.525	4.76	3.81	
		DNMG110408E-TM	●	●									▲	▲																				0.8	9.525	4.76	3.81
		DNMG110412E-TM	●	●									▲	▲																				1.2	9.525	4.76	3.81
		DNMG110404-TM	●	●	●								▲	▲	▲																			0.4	9.525	4.76	3.81
		DNMG110408-TM	●	●	●								▲	▲	▲																			0.8	9.525	4.76	3.81
		DNMG150404-TM	●	●	●	●				▲	▲	▲	▲	▲									●											0.4	12.7	4.76	5.16
		DNMG150408-TM	●	●	●	●				▲	▲	▲	▲	▲									●											0.8	12.7	4.76	5.16
		DNMG150412-TM	●	●	●	●				▲	▲	▲	▲	▲									●	●										1.2	12.7	4.76	5.16
		DNMG150416-TM	●	●						▲	▲																							1.6	12.7	4.76	5.16
		DNMG150604-TM	●	●	●	●				▲	▲	▲	▲	▲									●											0.4	12.7	6.35	5.16
		DNMG150608-TM	●	●	●	●				▲	▲	▲	▲	▲									●											0.8	12.7	6.35	5.16
DNMG150612-TM	●	●	●	●				▲	▲	▲	▲	▲									●											1.2	12.7	6.35	5.16		
DNMG150616-TM	●	●	●	●				▲	▲	▲	▲	▲																				1.6	12.7	6.35	5.16		
仕上げ 中 切削	 0.25	<b>AM</b> DNMG150408-AM	●	●								▲	▲																			0.8	12.7	4.76	5.16		
		DNMG150412-AM	●	●									▲	▲																			1.2	12.7	4.76	5.16	
		DNMG150416-AM	●	●									▲	▲																				1.6	12.7	4.76	5.16
		DNMG150608-AM	●	●									▲	▲																				0.8	12.7	6.35	5.16
		DNMG150612-AM	●	●									▲	▲																				1.2	12.7	6.35	5.16
		DNMG150616-AM	●	●									▲	▲																				1.6	12.7	6.35	5.16
中 切削	 1.2	<b>NM</b> DNMG150408-NM	●	●	●							▲	▲	▲								●		●								0.8	12.7	4.76	5.16		
		DNMG150412-NM	●	●	●								▲	▲	▲								●		●								1.2	12.7	4.76	5.16	
		DNMG150608-NM																					●		●								0.8	12.7	6.35	5.16	

- : 設定アイテム
- ▲ : 将来廃止予定アイテム

参照ページ： 外径ホルダ → C035 - 内径ホルダ → D050 -  
J series ホルダ → G046 TungCap → C043, K012 -