

インサート ネガティブタイプ


● : 連続加工
● : 軽断続加工
※ : 強断続加工

DN

ひし形穴つき
55°




P	鋼	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
M	ステンレス	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
K	鋳鉄	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
N	非鉄金属	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
S	難削材	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
H	高硬度材	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

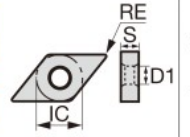

用途	ブレーカ 記号	形番	コーティング														コート サマセット	サーメット	超硬	寸法 (mm)							
			T9205	T9215	T9225	T9235	T9105	T9115	T9125	T9135	T515	T5105	T5115	T5125	AH110	AH120	GT9530	AT9530	NS9530	NS520	TH10	RE	IC	S	D1		
仕上げ／中切削	TQ	DNMG150404-TQ			●												●	●	●			0.4	12.7	4.76	5.16		
		DNMG150408-TQ			●													●	●	●			0.8	12.7	4.76	5.16	
	ZM	DNMG110408E-ZM		●	●					▲	▲												0.8	9.525	4.76	3.81	
		DNMG150408-ZM		●	●	●				▲	▲	▲					●		●				0.8	12.7	4.76	5.16	
		DNMG150412-ZM		●	●	●				▲	▲	▲											1.2	12.7	4.76	5.16	
中切削	DM	DNMG150408-DM		●	●	●			▲	▲	▲											0.8	12.7	4.76	5.16		
		DNMG150412-DM		●	●	●	●		▲	▲	▲	▲											1.2	12.7	4.76	5.16	
		DNMG150604-DM				●					▲												0.4	12.7	6.35	5.16	
		DNMG150608-DM				●	●	●			▲	▲	▲										0.8	12.7	6.35	5.16	
		DNMG150612-DM				●	●	●	●		▲	▲	▲	▲									1.2	12.7	6.35	5.16	
全周		DNMG110404			●	●				▲	▲					●		●				0.4	9.525	4.76	3.81		
		DNMG110408		●	●	●	●		▲	▲	▲	▲					●		●				0.8	9.525	4.76	3.81	
		DNMG150404			●	●	●			▲	▲	▲					●		●		●		0.4	12.7	4.76	5.16	
		DNMG150408		●	●	●	●		▲	▲	▲	▲	●	●	●	●	●		●		●		0.8	12.7	4.76	5.16	
		DNMG150412		●	●	●	●		▲	▲	▲	▲	●	●	●	●	●		●		●		1.2	12.7	4.76	5.16	
		DNMG150416			●	●				▲	▲													1.6	12.7	4.76	5.16
		DNMG150604					●			▲	▲												0.4	12.7	6.35	5.16	
		DNMG150608					●	●	●		▲	▲	▲	▲	●	●	●						0.8	12.7	6.35	5.16	
		DNMG150612					●	●	●	●	▲	▲	▲	▲	●	●	●						1.2	12.7	6.35	5.16	
DNMG150616					●	●			▲	▲												1.6	12.7	6.35	5.16		
仕上げ／中切削	27	DNMG150404-27			●					▲								●				0.4	12.7	4.76	5.16		
		DNMG150408-27			●	●				▲	▲								●				0.8	12.7	4.76	5.16	
		DNMG150412-27			●					▲													1.2	12.7	4.76	5.16	

● : 設定アイテム
▲ : 将来廃止予定アイテム

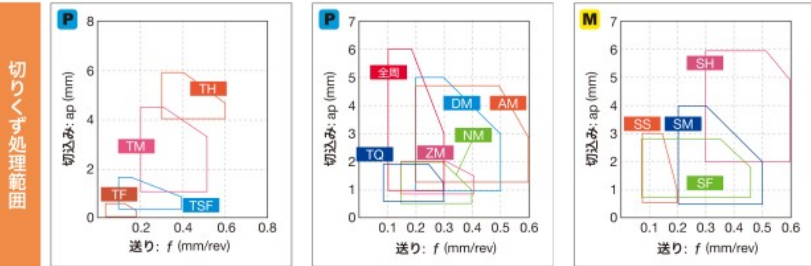

参照ページ: 外径ホルダ → C035 - 内径ホルダ → D050 -
J series ホルダ → G046 TungCap → C043, K012 -

材質
A
B
C
D
E
F
G
H
I
J
K
L
M
インサート
外径用ホルダ
内径用ホルダ
ねじ切り工具
突切り溝入れ
小型旋盤用工具
フライス工具
エンドミル
穴あけ工具
ツインシステム
ユーザガイド
索引