

インサート ネガティブタイプ


● : 連続加工
 ● : 軽断続加工
 ☆ : 強断続加工

材種
 インサート
 外径用ホルダ
 内径用ホルダ
 ねじ切り工具
 突切り溝入れ
 小型旋盤用工具
 フライス工具
 エンドミル
 穴あけ工具
 ツインシステム
 ユーザガイド
 索引

DN


ひし形穴つき
 55°

P	銅	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
M	ステンレス					●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
K	鋳鉄					●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
N	非鉄金属																				
S	難削材																				
H	高硬度材																				

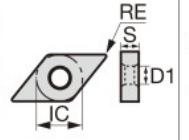

用途	プレカ記号	形番	コーティング											サーメット	超硬	寸法 (mm)						
			T9225	T9235	T9125	T9135	T6130	AH630	AH645	AH120	AH8005	AH8015	AH905			GH110	GH330	NS9530	TH10	RE	IC	S
中切削		P DNGG150402R-P															●	0.2	12.7	4.76	5.16	
		DNGG150402L-P																●	0.2	12.7	4.76	5.16
		DNGG150404R-P																●	0.4	12.7	4.76	5.16
		DNGG150404L-P																●	0.4	12.7	4.76	5.16
		DNGG150408R-P																●	0.8	12.7	4.76	5.16
		DNGG150408L-P																●	0.8	12.7	4.76	5.16
仕上げ・中切削		HRM DNMG150404-HRM									●	●						0.4	12.7	4.76	5.16	
		DNMG150408-HRM									●	●							0.8	12.7	4.76	5.16
		DNMG150412-HRM										●	●						1.2	12.7	4.76	5.16
		DNMG150604-HRM										●	●						0.4	12.7	6.35	5.16
		DNMG150608-HRM										●	●						0.8	12.7	6.35	5.16
		DNMG150612-HRM											●	●					1.2	12.7	6.35	5.16
中切削		HMM DNMG150404-HMM															●	0.4	12.7	4.76	5.16	
		DNMG150408-HMM																●	0.8	12.7	4.76	5.16
		DNMG150412-HMM																●	1.2	12.7	4.76	5.16
		SA DNMG150404-SA																●	0.4	12.7	4.76	5.16
		DNMG150408-SA																●	0.8	12.7	4.76	5.16
		DNMG150604-SA																●	0.4	12.7	6.35	5.16
中切削		S DNMG150404R-S	●	●	▲	▲	●	●	●								●	0.4	12.7	4.76	5.16	
		DNMG150404L-S	●	●	▲	▲	●	●	●									●	0.4	12.7	4.76	5.16
		DNMG150408R-S	●	●	▲	▲	●	●	●									●	0.8	12.7	4.76	5.16
		DNMG150408L-S	●	●	▲	▲	●	●	●									●	0.8	12.7	4.76	5.16
		DNMG150604R-S	●	●	▲	▲	●	●	●									●	0.4	12.7	6.35	5.16
		DNMG150604L-S	●	●	▲	▲	●	●	●									●	0.4	12.7	6.35	5.16
		DNMG150608R-S	●	●	▲	▲	●	●	●									●	0.8	12.7	6.35	5.16
		DNMG150608L-S	●	●	▲	▲	●	●	●									●	0.8	12.7	6.35	5.16

● : 設定アイテム
 ▲ : 将来廃止予定アイテム

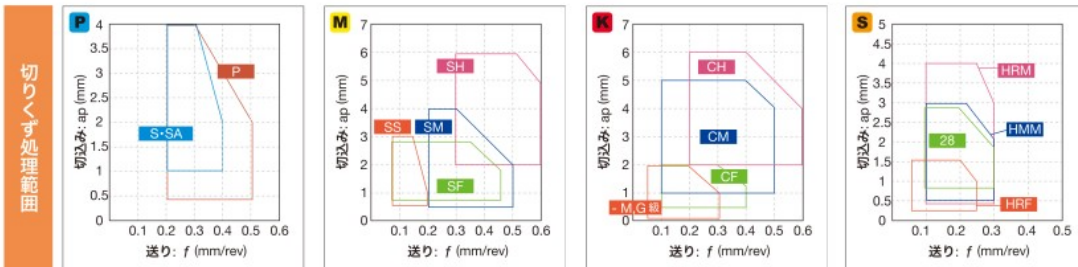

参照ページ: 外径ホルダ → C040 - 内径ホルダ → D050 -
 J series ホルダ → G046 TungCap → C043, K012 -