


インサート ネガティブタイプ

●: 連続加工
●: 軽断続加工
✳: 強断続加工

SN


正方形穴つき
90°

材料	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
P 鋼	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
M ステンレス	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
K 鋳鉄	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
N 非鉄金属	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
S 難削材	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
H 高硬度材	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

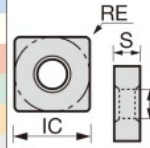

用途	ブレーカ 記号	形番	コーティング										寸法 (mm)								
			T9205	T9215	T9225	T9235	T9115	T9125	T9135	T6130	AH630	AH645	T5105	T5115	T5125	RE	IC	S	D1		
重切削 (片面ブレーカ)	TUS	SNMM190612-TUS	●	●	●	●	▲	▲	▲												
		SNMM190616-TUS	●	●	●	●	▲	▲	▲												
		SNMM190624-TUS	●	●	●	●	▲	▲	▲												
		SNMM250724-TUS	●	●	●	●	▲	▲	▲												
		SNMM250732-TUS	●	●	●	●	▲	▲													
		SNMM250924-TUS	●	●	●	●	▲	▲	▲												
		SNMM250932-TUS	●	●	●	●	▲	▲													
		57	SNMM120408-57	●	●	●	●	▲	▲												
中々重切削 (片面ブレーカ)		SNMM150616-57		●																	
		SNMM190612-57		●																	
		65	SNMM190612-65		●				▲												
		SNMM310924-65		●					▲												
中々重切削	SH	SNMG120408-SH								●	●	●									
		SNMG120412-SH								●	●	●									
		SNMG150612-SH								●	●	●									
		SNMG150616-SH								●	●	●									
		SNMG190612-SH								●	●	●									
		SNMG190616-SH								●	●	●									
		CH	SNMG120408-CH										●	●	●						
	SNMG120412-CH											●	●	●							
	SNMG120416-CH											●	●	●							

●: 設定アイテム
▲: 将来廃止予定アイテム

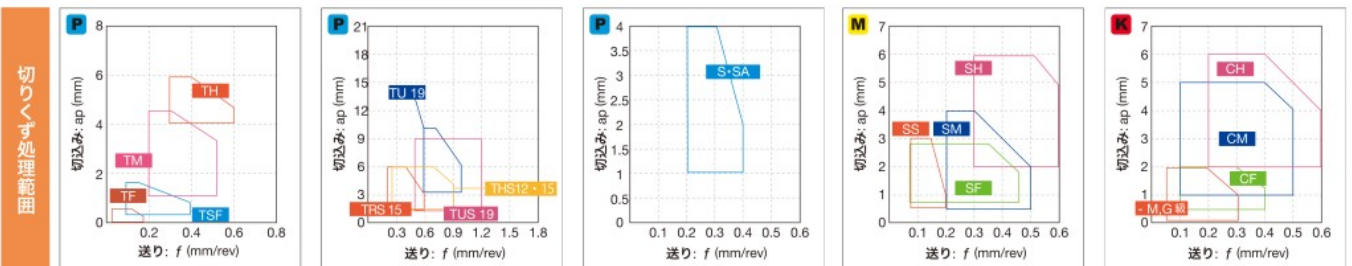

参照ページ: 外径ホルダ → C091 - 内径ホルダ → D038 - カートリッジ → K197