


# インサート ネガティブタイプ

●: 連続加工  
●: 軽断続加工  
✳: 強断続加工

## TN



材料	T9205	T9215	T9225	T9235	T9115	T9125	T9135	T6130	AH630	AH645	T515	T5105	T5115	T5125	AH120	AH725	GH330	NS9530	
P 鋼	●	●	●	●	✳	●	●	✳	✳	✳									●
M ステンレス		●	●						●	●									●
K 鋳鉄	●	●	●			●					●	●	●	●	●	●			●
N 非鉄金属																			
S 難削材																			●
H 高硬度材																			

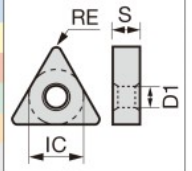

PCD/CBN

用途	ブレード記号	形番	コーティング														サーメット	寸法 (mm)						
			T9205	T9215	T9225	T9235	T9115	T9125	T9135	T6130	AH630	AH645	T515	T5105	T5115	T5125	AH120	AH725	GH330	NS9530	RE	IC	S	D1
中切削		<b>S</b> TNMG160404R-S	●	●	●	▲	▲	▲	●	●	●						●	●	●	0.4	9.525	4.76	3.81	
		TNMG160404L-S		●	●		▲	▲	●	●	●							●	●	●	0.4	9.525	4.76	3.81
		TNMG160408R-S		●	●		▲	▲	●	●	●							●	●	●	0.8	9.525	4.76	3.81
		TNMG160408L-S		●	●		▲	▲	●	●	●							●	●	●	0.8	9.525	4.76	3.81
		TNMG220404R-S		●	●		▲	▲	●	●	●							●	●	●	0.4	12.7	4.76	5.16
		TNMG220404L-S		●	●		▲	▲	●	●	●							●	●	●	0.4	12.7	4.76	5.16
		TNMG220408R-S		●	●		▲	▲	●	●	●							●	●	●	0.8	12.7	4.76	5.16
		TNMG220408L-S		●	●		▲	▲	●	●	●							●	●	●	0.8	12.7	4.76	5.16
中〜重切削		<b>TH</b> TNMG220408-TH	●	●	●	▲	▲	▲								●				0.8	12.7	4.76	5.16	
		TNMG220412-TH	●	●	●	▲	▲	▲													1.2	12.7	4.76	5.16
		<b>THS</b> TNMG220408-THS	●	●	●	▲	▲	▲													0.8	12.7	4.76	5.16
		TNMG220412-THS	●	●	●	▲	▲	▲													1.2	12.7	4.76	5.16
		<b>CH</b> TNMG160404-CH											●	●	●	●					0.4	9.525	4.76	3.81
		TNMG160408-CH											●	●	●	●					0.8	9.525	4.76	3.81
中〜重切削 (片面ブレード)		TNMG160412-CH									●	●	●	●					1.2	9.525	4.76	3.81		
		<b>T</b> TNMG220408-CH											●	●	●					0.8	12.7	4.76	5.16	
		TNMG220412-CH											●	●	●					1.2	12.7	4.76	5.16	
		TNMG220416-CH											●	●	●					1.6	12.7	4.76	5.16	
		<b>57</b> TNMM160408-57		●				▲													0.8	9.525	4.76	3.81
		TNMM220408-57		●				▲													0.8	12.7	4.76	5.16
TNMM220412-57		●				▲													1.2	12.7	4.76	5.16		

●: 設定アイテム  
▲: 将来廃止予定アイテム

参照ページ: 外径ホルダ → C025 - 内径ホルダ → D044 - J series ホルダ → G045 -  
カートリッジ → K193 -