


TP

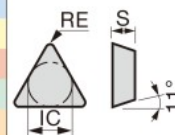


三角形穴なし
60° ポジ11°

[illegible]

用途	ブレーカ 記号	形 番	コーティング						サーメット		超硬		寸法 (mm)				
			T9215	T9225	T9115	T9125	T5115	AH725	NS9530		TH10			RE	IC	S	D1
仕上げ・中切削	PS  	TPMR110304-PS	●		▲									0.4	6.35	3.18	-
		TPMR110308-PS	●		▲									0.8	6.35	3.18	-
		TPMR160304-PS	●		▲									0.4	9.525	3.18	-
		TPMR160308-PS	●		▲									0.8	9.525	3.18	-
仕上げ・中切削	23  	TPMR110304-23	●	●	▲	▲		●					0.4	6.35	3.18	-	
		TPMR110308-23		●		▲		●		●			0.8	6.35	3.18	-	
		TPMR160304-23	●	●	▲	▲		●		●			0.4	9.525	3.18	-	
		TPMR160308-23		●		▲		●					0.8	9.525	3.18	-	
中切削	24  	TPMR110304-24		●		▲		●					0.4	6.35	3.18	-	
		TPMR110308-24		●		▲		●					0.8	6.35	3.18	-	
		TPMR160304-24	●	●	▲	▲		●					0.4	9.525	3.18	-	
		TPMR160308-24	●	●	▲	▲		●					0.8	9.525	3.18	-	
仕上げ・中切削	CM  	TPMR110304-CM					●						0.4	6.35	3.18	-	
		TPMR110308-CM					●						0.8	6.35	3.18	-	
		TPMR160304-CM					●						0.4	9.525	3.18	-	
		TPMR160308-CM					●						0.8	9.525	3.18	-	
		TPMR160312-CM					●						1.2	9.525	3.18	-	

●: 設定アイテム
▲: 将来廃止予定アイテム

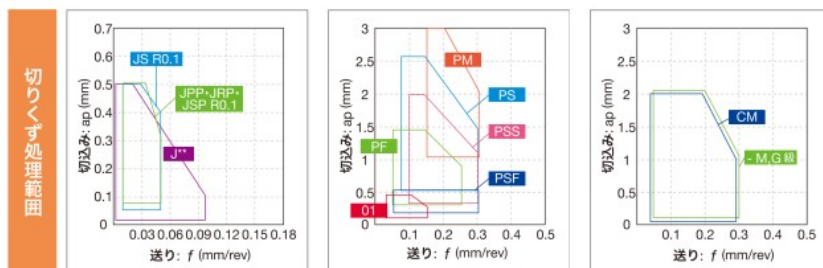

※代表的な R0.1 の切りくず処理範囲を示す

参照ページ: 内径ホルダ → **D042** - カートリッジ → **K193** -