


DMC 高精度加工ヘッド

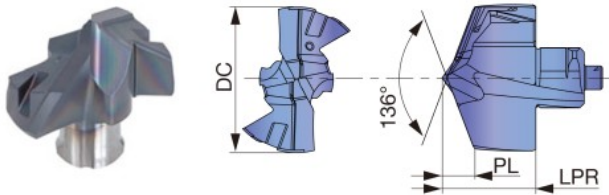

形番	DC	在庫 AH9130	LPR	PL	ポケット サイズ	ボディ
DMC100	10	●	6.67	2.09	10	TID*100*
DMC101	10.1	●	6.67	2.11	10	TID*100*
DMC102	10.2	●	6.67	2.13	10	TID*100*
DMC103	10.3	●	6.67	2.15	10	TID*100*
DMC104	10.4	●	6.67	2.17	10	TID*100*
DMC105	10.5	●	6.67	2.19	10	TID*105*
DMC106	10.6	●	6.67	2.21	10	TID*105*
DMC107	10.7	●	6.67	2.23	10	TID*105*
DMC108	10.8	●	6.67	2.25	10	TID*105*
DMC109	10.9	●	6.67	2.27	10	TID*105*
DMC110	11	●	7.1	2.32	11	TID*110*
DMC111	11.1	●	7.1	2.34	11	TID*110*
DMC112	11.2	●	7.1	2.36	11	TID*110*
DMC113	11.3	●	7.1	2.38	11	TID*110*
DMC114	11.4	●	7.1	2.40	11	TID*110*
DMC115	11.5	●	7.1	2.42	11	TID*115*
DMC116	11.6	●	7.1	2.44	11	TID*115*
DMC117	11.7	●	7.1	2.46	11	TID*115*
DMC118	11.8	●	7.1	2.48	11	TID*115*
DMC119	11.9	●	7.1	2.50	11	TID*115*
DMC120	12	●	7.43	2.45	12	TID*120*
DMC121	12.1	●	7.43	2.47	12	TID*120*
DMC122	12.2	●	7.43	2.49	12	TID*120*
DMC123	12.3	●	7.43	2.51	12	TID*120*
DMC124	12.4	●	7.43	2.53	12	TID*120*
DMC125	12.5	●	7.43	2.55	12	TID*125*
DMC126	12.6	●	7.43	2.57	12	TID*125*
DMC127	12.7	●	7.43	2.59	12	TID*125*
DMC128	12.8	●	7.43	2.61	12	TID*125*
DMC129	12.9	●	7.43	2.63	12	TID*125*
DMC130	13	●	8.15	2.71	13	TID*130*
DMC131	13.1	●	8.15	2.73	13	TID*130*
DMC132	13.2	●	8.15	2.75	13	TID*130*
DMC133	13.3	●	8.15	2.77	13	TID*130*
DMC134	13.4	●	8.15	2.79	13	TID*130*
DMC135	13.5	●	8.15	2.81	13	TID*135*
DMC136	13.6	●	8.15	2.83	13	TID*135*
DMC137	13.7	●	8.15	2.85	13	TID*135*
DMC138	13.8	●	8.15	2.87	13	TID*135*
DMC139	13.9	●	8.15	2.89	13	TID*135*
DMC140	14	●	8.76	2.93	14	TID*140*
DMC141	14.1	●	8.76	2.95	14	TID*140*
DMC142	14.2	●	8.76	2.97	14	TID*140*
DMC143	14.3	●	8.76	2.99	14	TID*140*
DMC144	14.4	●	8.76	3.01	14	TID*140*
DMC145	14.5	●	8.76	3.03	14	TID*145*
DMC146	14.6	●	8.76	3.05	14	TID*145*
DMC147	14.7	●	8.76	3.07	14	TID*145*
DMC148	14.8	●	8.76	3.09	14	TID*145*
DMC149	14.9	●	8.76	3.11	14	TID*145*
DMC150	15	●	9.44	3.18	15	TID*150*
DMC151	15.1	●	9.44	3.20	15	TID*150*
DMC152	15.2	●	9.44	3.22	15	TID*150*
DMC153	15.3	●	9.44	3.24	15	TID*150*
DMC154	15.4	●	9.44	3.26	15	TID*150*

形番	DC	在庫 AH9130	LPR	PL	ポケット サイズ	ボディ
DMC155	15.5	●	9.44	3.28	15	TID*150*
DMC156	15.6	●	9.44	3.30	15	TID*150*
DMC157	15.7	●	9.44	3.32	15	TID*150*
DMC158	15.8	●	9.44	3.34	15	TID*150*
DMC159	15.9	●	9.44	3.36	15	TID*150*
DMC160	16	●	10.07	3.39	16	TID*160*
DMC161	16.1	●	10.07	3.41	16	TID*160*
DMC162	16.2	●	10.07	3.43	16	TID*160*
DMC163	16.3	●	10.07	3.45	16	TID*160*
DMC164	16.4	●	10.07	3.47	16	TID*160*
DMC165	16.5	●	10.07	3.49	16	TID*160*
DMC166	16.6	●	10.07	3.51	16	TID*160*
DMC167	16.7	●	10.07	3.53	16	TID*160*
DMC168	16.8	●	10.07	3.55	16	TID*160*
DMC169	16.9	●	10.07	3.57	16	TID*160*
DMC170	17	●	10.68	3.57	17	TID*170*
DMC171	17.1	●	10.68	3.59	17	TID*170*
DMC172	17.2	●	10.68	3.61	17	TID*170*
DMC173	17.3	●	10.68	3.63	17	TID*170*
DMC174	17.4	●	10.68	3.65	17	TID*170*
DMC175	17.5	●	10.68	3.67	17	TID*170*
DMC176	17.6	●	10.68	3.69	17	TID*170*
DMC177	17.7	●	10.68	3.71	17	TID*170*
DMC178	17.8	●	10.68	3.73	17	TID*170*
DMC179	17.9	●	10.68	3.75	17	TID*170*
DMC180	18	●	11.35	3.78	18	TID*180*
DMC181	18.1	●	11.35	3.80	18	TID*180*
DMC182	18.2	●	11.35	3.82	18	TID*180*
DMC183	18.3	●	11.35	3.84	18	TID*180*
DMC184	18.4	●	11.35	3.86	18	TID*180*
DMC185	18.5	●	11.35	3.88	18	TID*180*
DMC186	18.6	●	11.35	3.90	18	TID*180*
DMC187	18.7	●	11.35	3.92	18	TID*180*
DMC188	18.8	●	11.35	3.94	18	TID*180*
DMC189	18.9	●	11.35	3.96	18	TID*180*
DMC190	19	●	11.91	3.99	19	TID*190*
DMC191	19.1	●	11.91	4.01	19	TID*190*
DMC192	19.2	●	11.91	4.03	19	TID*190*
DMC193	19.3	●	11.91	4.05	19	TID*190*
DMC194	19.4	●	11.91	4.07	19	TID*190*
DMC195	19.5	●	11.91	4.09	19	TID*190*
DMC196	19.6	●	11.91	4.11	19	TID*190*
DMC197	19.7	●	11.91	4.13	19	TID*190*
DMC198	19.8	●	11.91	4.15	19	TID*190*
DMC199	19.9	●	11.91	4.17	19	TID*190*

工具径	ヘッド径公差
φ10 - φ17.9	+0.018 / 0
φ18 - φ19.9	+0.021 / 0

● : 設定アイテム
φ10 - φ19.9 = 1 ケース 2 個入り

材種
インサート
外径用ホルダ
内径用ホルダ
ねじ切り工具
突切り溝入れ
小型旋盤用工具
フライス工具
エンドミル
穴あけ工具
ツインシステム
ユーザガイド
索引

